

CSA, ULI

RIGID PVC CONDUIT FITTINGS - KRALOY

ISSUE DATE:

DATE D'EMISSION: 2007 08 30


EXPANSION JOINTS

SUPERCEDES:

REPLACE:

2002 01 15

2

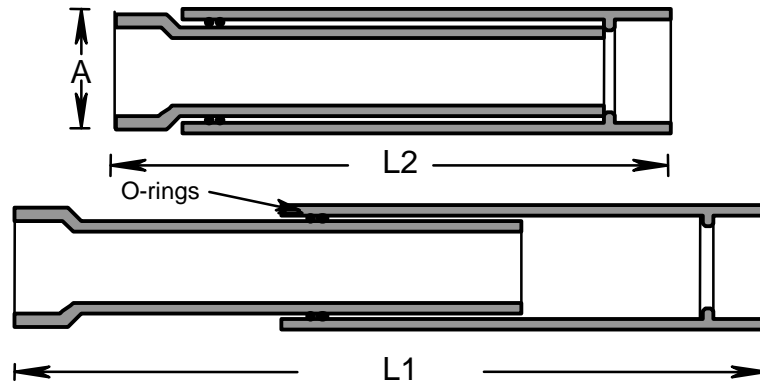

PRODUCT CODE	PART NUMBER	NOMINAL SIZE		A		L1		L2	
		(in)	(mm)	(in)	(mm)	(in)	(mm)	(in)	(mm)
078328	EJ05	1/2	16	1.080	27	12.000	305	8.000	203
078329	EJ07	3/4	21	1.300	33	12.000	305	8.000	203
078330	EJ10	1	27	1.590	40	12.500	318	8.500	216
078331	EJ12	1 1/4	35	2.000	51	13.000	330	9.000	229
078332	EJ15	1 1/2	41	2.230	57	13.000	330	9.000	229
078333	EJ20	2	53	2.720	69	13.250	337	9.250	235
078334	EJ25	2 1/2	63	4.000	102	22.250	565	14.250	362
078336	EJ30	3	78	4.000	102	22.250	565	14.250	362
078337	EJ35	3 1/2	91	5.000	127	22.900	565	14.900	378
078338	EJ40	4	103	5.000	127	22.900	565	14.900	378
078499*	EJ12*	1 1/4	35	2.000	51	13.000	330	9.000	229

PRODUCT CODE	PART NUMBER	NOMINAL SIZE		O-RINGS	REDUCER
		(in)	(mm)	CODE	CODE
078328	EJ05	1/2	16	077284	097554
078329	EJ07	3/4	21	077284	
078330	EJ10	1	27	077285	
078331	EJ12	1 1/4	35	077286	
078332	EJ15	1 1/2	41	077287	
078333	EJ20	2	53	077288	
078334	EJ25	2 1/2	63	077291	097558
078336	EJ30	3	78	077291	
078337	EJ35	3 1/2	91	077290	097991
078338	EJ40	4	103	077290	
078499*	EJ12*	1 1/4	35		

\* INSIDE SLEEVE ONLY

CSA, ULI

RIGID PVC CONDUIT FITTINGS - KRALOY

ISSUE DATE:


DATE D'EMISSION: 2007 08 30

EXPANSION JOINTS

SUPERCEDES:

REPLACE: 2002 01 15

2

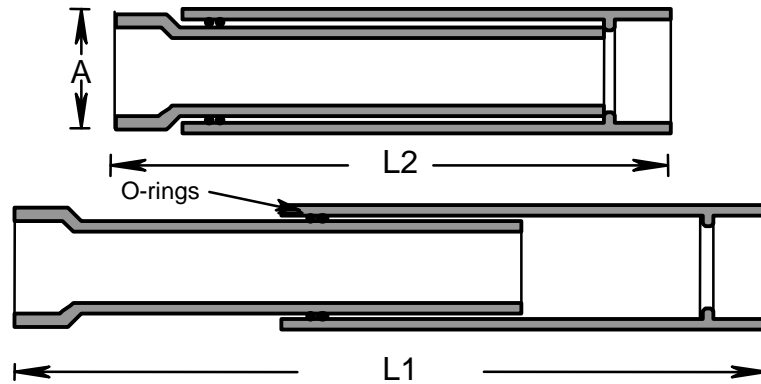

PRODUCT CODE	PART NUMBER	NOMINAL SIZE		A		L1		L2	
		(in)	(mm)	(in)	(mm)	(in)	(mm)	(in)	(mm)
078328	EJ05	1/2	16	1.080	27	12.000	305	8.000	203
078329	EJ07	3/4	21	1.300	33	12.000	305	8.000	203
078330	EJ10	1	27	1.590	40	12.500	318	8.500	216
078331	EJ12	1 1/4	35	2.000	51	13.000	330	9.000	229
078332	EJ15	1 1/2	41	2.230	57	13.000	330	9.000	229
078333	EJ20	2	53	2.720	69	13.250	337	9.250	235
078334	EJ25	2 1/2	63	4.000	102	22.250	565	14.250	362
078336	EJ30	3	78	4.000	102	22.250	565	14.250	362
078337	EJ35	3 1/2	91	5.000	127	22.900	565	14.900	378
078338	EJ40	4	103	5.000	127	22.900	565	14.900	378
078499*	EJ12*	1 1/4	35	2.000	51	13.000	330	9.000	229

PRODUCT CODE	PART NUMBER	NOMINAL SIZE		O-RINGS	REDUCER
		(in)	(mm)	CODE	CODE
078328	EJ05	1/2	16	077284	097554
078329	EJ07	3/4	21	077284	
078330	EJ10	1	27	077285	
078331	EJ12	1 1/4	35	077286	
078332	EJ15	1 1/2	41	077287	
078333	EJ20	2	53	077288	
078334	EJ25	2 1/2	63	077291	097558
078336	EJ30	3	78	077291	
078337	EJ35	3 1/2	91	077290	097991
078338	EJ40	4	103	077290	
078499*	EJ12*	1 1/4	35		

\* INSIDE SLEEVE ONLY