







GE  
Lighting

## 13390 - 15T6

### GE appliance 15 watt T6 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Indicator Lights are designed for home appliances and many small fixtures requiring a candleabra base.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 2000 hours
- T6 shape with candelabra base for use in appliances

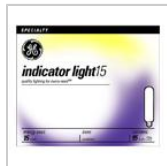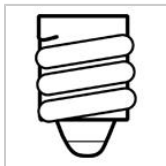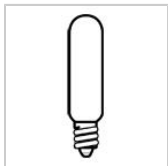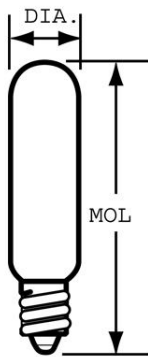

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	2000.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Standard

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	107.0
Nominal Initial Lumens per Watt	7

### ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	3.0600 in(77.7 mm)
Bulb Diameter (DIA)	0.750 in(19.0 mm)
Light Center Length (LCL)	1.560 in(39.6 mm)

### PRODUCT INFORMATION

Product Code	13390
Description	15T6
Standard Package	Case
Standard Package GTIN	10043168133903
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168133906







GE  
Lighting

## 13390 - 15T6

### GE appliance 15 watt T6 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Indicator Lights are designed for home appliances and many small fixtures requiring a candleabra base.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 2000 hours
- T6 shape with candelabra base for use in appliances

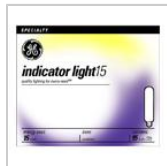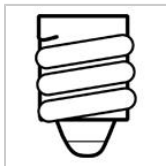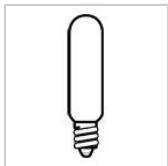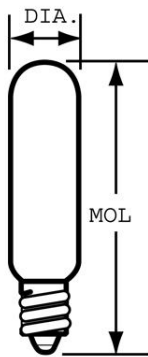

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	2000.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Standard

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	107.0
Nominal Initial Lumens per Watt	7

### ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	3.0600 in(77.7 mm)
Bulb Diameter (DIA)	0.750 in(19.0 mm)
Light Center Length (LCL)	1.560 in(39.6 mm)

### PRODUCT INFORMATION

Product Code	13390
Description	15T6
Standard Package	Case
Standard Package GTIN	10043168133903
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168133906