
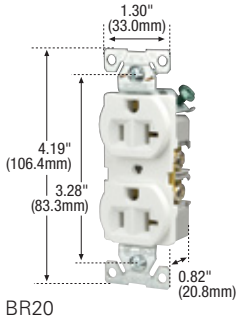



Commercial grade straight blade receptacles

Product description


2-pole, 3-wire grounding
 15A, 125V/AC
 20A, 125V/AC
 NEMA 5-15R, 5-20R

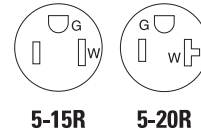


BR20

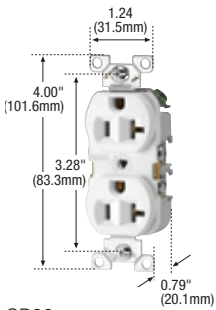

CR20

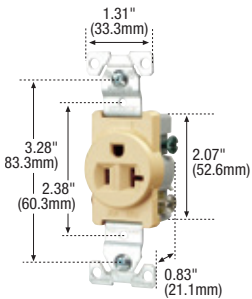

1877

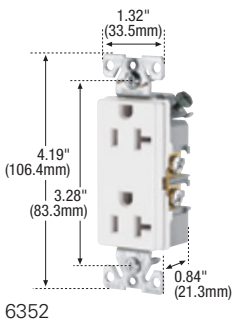

6352

Commercial grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	125	5-15R		Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ BR15__	•	•	•
				Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR15__	•	•	•
				Single receptacle, side wire	B, BK, LA, V, W	□ 817__*	•	•	•
20	125	5-20R		Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□ BR20__	•	•	•
				Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR20__	•	•	•
				Single receptacle, side wire	A, B, BK, LA, V, W	□ 1877__*	•	•	•

* Not Fed Spec

Decorator commercial grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	125	5-15R		Duplex receptacle, back & side wire	B, BK, GY, LA, V, W	□ 6252__†	•	•	•
				Single receptacle, back & side wire	V, W	□ 6250__*	•	•	•
20	125	5-20R		Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ 6352__†	•	•	•
				Single receptacle, back & side wire	B, V, W	□ 6350__*†	•	•	•

† Not NOM cert, * UL Listed & CSA certified

Accessories for construction grade 5-15 & 5-20 receptacles

Description	Color suffix	Catalog no.		
2-Gang standard size duplex receptacle wallplate	A, B, BK, GY, LA, RD, V, W	□ 5150__	•	•
1-Gang mid-size single receptacle wallplate, 1.4" hole	A, B, BK, GY, LA, RD, V, W	□ PJ7__	•	•



5150B



PJ7GY

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)

A	B	BK	GY	LA	RD	V	W
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Red)	(Ivory)	(White)

Specification information: Commercial receptacles: A-33

Compliances, specifications and availability are subject to change without notice.

Build-to-spec customizable devices - Page A-6



Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32


Commercial grade straight blade receptacles

Product description


2-pole, 3-wire grounding
 15A, 125V/AC
 20A, 125V/AC
 NEMA 5-15R, 5-20R

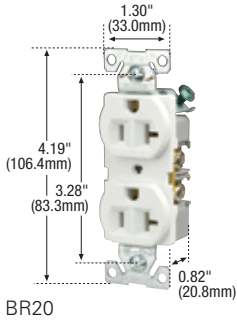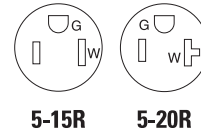


BR20

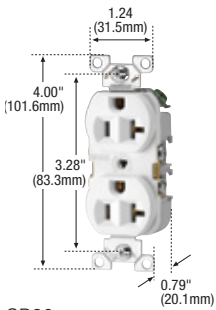

CR20

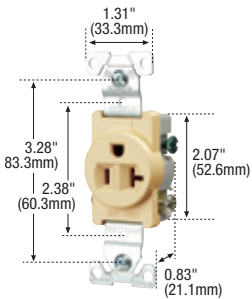

1877

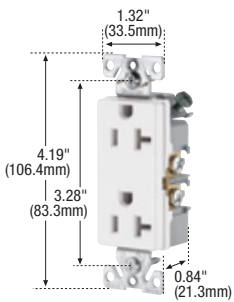

6352

Commercial grade receptacles



Rating		NEMA	Description	Color suffix	Catalog no.	
A	V/AC					
15	125	5-15R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ BR15__	• • •
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR15__	• • •
			Single receptacle, side wire	B, BK, LA, V, W	□ 817__*	• • •
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□ BR20__	• • •
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR20__	• • •
			Single receptacle, side wire	A, B, BK, LA, V, W	□ 1877__*	• • •

* Not Fed Spec

Decorator commercial grade receptacles



Rating		NEMA	Description	Color suffix	Catalog no.	
A	V/AC					
15	125	5-15R	Duplex receptacle, back & side wire	B, BK, GY, LA, V, W	□ 6252__†	• • •
			Single receptacle, back & side wire	V, W	□ 6250__*	• • •
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ 6352__†	• • •
			Single receptacle, back & side wire	B, V, W	□ 6350__*†	• • •

† Not NOM cert, * UL Listed & CSA certified

Accessories for construction grade 5-15 & 5-20 receptacles

Description	Color suffix	Catalog no.	
2-Gang standard size duplex receptacle wallplate	A, B, BK, GY, LA, RD, V, W	□ 5150__	• •
1-Gang mid-size single receptacle wallplate, 1.4" hole	A, B, BK, GY, LA, RD, V, W	□ PJ7__	•



5150B



PJ7GY

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)



Specification information: Commercial receptacles: A-33

Compliances, specifications and availability are subject to change without notice.

Build-to-spec customizable devices - Page A-6

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32