





GE  
Lighting

### 16069 - 200A/CL-1 12PK

GE crystal clear 200 watt A21 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- 2900K soft white light appearance
- A21 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- Lasts 0.7 years based on 3 hours per day usage
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- 3780 lumens providing strong, vibrant™ light

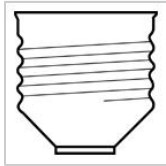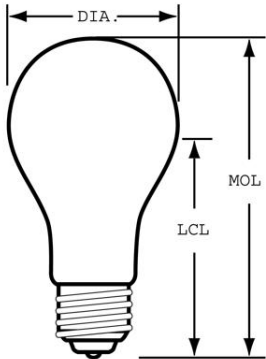

#### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	3780.0
Color Temperature	2900.0 K
Nominal Initial Lumens per Watt	18

#### ELECTRICAL CHARACTERISTICS

Wattage	200.0
Voltage	120.0

#### DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	2.625 in(66.7 mm)
Light Center Length (LCL)	4.060 in(103.1 mm)

#### PRODUCT INFORMATION

Product Code	16069
Description	200A/CL-1 12PK
Standard Package	Case
Standard Package GTIN	00043168160698
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168904568





GE  
Lighting

### 16069 - 200A/CL-1 12PK

GE crystal clear 200 watt A21 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- 2900K soft white light appearance
- A21 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- Lasts 0.7 years based on 3 hours per day usage
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- 3780 lumens providing strong, vibrant™ light

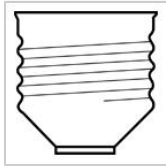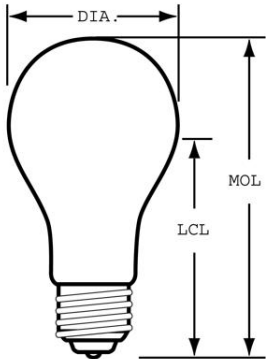

#### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	3780.0
Color Temperature	2900.0 K
Nominal Initial Lumens per Watt	18

#### ELECTRICAL CHARACTERISTICS

Wattage	200.0
Voltage	120.0

#### DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	2.625 in(66.7 mm)
Light Center Length (LCL)	4.060 in(103.1 mm)

#### PRODUCT INFORMATION

Product Code	16069
Description	200A/CL-1 12PK
Standard Package	Case
Standard Package GTIN	00043168160698
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168904568