




2500W

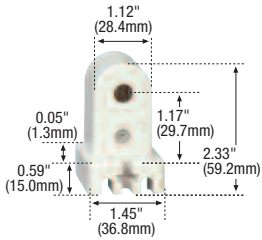


2503W

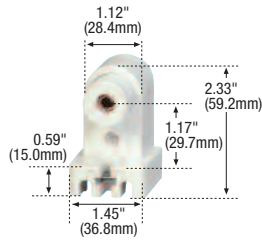

2504W

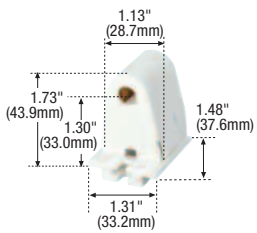

2506W

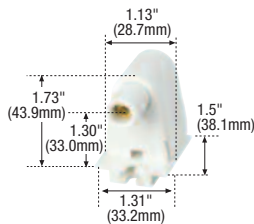

2507W

Fluorescent Lampholders

Recessed Double Contact
Slimline
660W, 600V/AC
660W, 1000V/AC

Recessed Double Contact

FEATURES

- For replacement use in fluorescent lighting fixtures as well as enclosed outdoor signs.
- Recessed double-contact (2500, 2501) lampholders can be used for flush or surface mounting.
- Captive pal nut for easy mounting.
- Push-in wire terminals feature release slots.
- Molded of durable white thermoset plastic.

Recessed Fluorescent Lampholders



Rating	W	V/AC	Product Type	Color	Catalog No.
660	600		Plunger, Push Wire Cap, Screw Switch	White	<input type="checkbox"/> 2501W
			Stationary, Push Wire Cap, Screw Switch	White	<input type="checkbox"/> 2500W

For panel cutout dimensional data, see O-Technical Reference

Slimline

FEATURES

- For replacement use in fluorescent lighting fixtures as well as enclosed outdoor signs.
- Plunger lampholders feature non-sticking, spring-loaded plunger to hold lamp securely.
- Captive pal nut for easy mounting.
- Push-in wire terminals feature release slots.

Slimline Fluorescent Lampholders



Rating	W	V/AC	Product Type	Color	Catalog No.
660	600		Stationary, Push Wire Cap, Slide-On Switch	White	<input type="checkbox"/> 2506W
			Stationary, Push Wire Cap, Screw Switch	White	<input type="checkbox"/> 2503W
660	1000		Plunger, Push Wire Cap, Slide-On Switch	White	<input type="checkbox"/> 2507W*
			Plunger, Push Wire Cap, Screw Switch	White	<input type="checkbox"/> 2504W*

For panel cutout dimensional data, see O-Technical Reference

* Not CSA or NOM certified