




GE  
Lighting

**15787 - 25BC 25PK**

GE B10

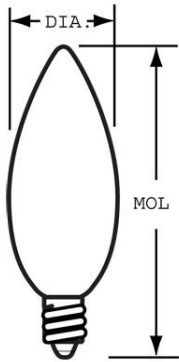

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - Decorative
Bulb	B10
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Chandelier

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	220.0
Color Temperature	2500.0 K

**ELECTRICAL CHARACTERISTICS**

Wattage	25.0
Voltage	120.0
Burn Position	Horizontal $\pm 15^\circ$ or Base Down
Estimated Energy Cost per Year	3.01

**DIMENSIONS**

Maximum Overall Length (MOL)	3.7500 in(95.2 mm)
Bulb Diameter (DIA)	1.250 in(31.8 mm)

**PRODUCT INFORMATION**


Product Code	15787
Description	25BC 25PK
Standard Package	Master
Standard Package GTIN	10043168157879
Standard Package Quantity	200
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	200
UPC	043168157872



GE  
Lighting

**15787 - 25BC 25PK**

GE B10

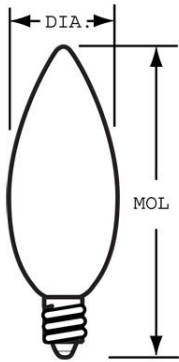

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - Decorative
Bulb	B10
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Chandelier

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	220.0
Color Temperature	2500.0 K

**ELECTRICAL CHARACTERISTICS**

Wattage	25.0
Voltage	120.0
Burn Position	Horizontal $\pm 15^\circ$ or Base Down
Estimated Energy Cost per Year	3.01

**DIMENSIONS**

Maximum Overall Length (MOL)	3.7500 in(95.2 mm)
Bulb Diameter (DIA)	1.250 in(31.8 mm)

**PRODUCT INFORMATION**

Product Code	15787
Description	25BC 25PK
Standard Package	Master
Standard Package GTIN	10043168157879
Standard Package Quantity	200
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	200
UPC	043168157872