

| CAT# | A     | B   |
|------|-------|-----|
| 301  | 1.053 | .37 |
| 302  | 1.327 | .37 |
| 303  | 1.584 | .47 |
| 304  | 1.952 | .50 |
| 305  | 2.201 | .52 |
| 306  | 2.693 | .52 |
| 307  | 3.235 | .85 |
| 308  | 3.855 | .85 |
| 309  | 4.359 | .85 |
| 310  | 5.011 | .85 |

|       |       |      |
|-------|-------|------|
| 301M  | 1.223 | .48  |
| 302M  | 1.498 | .49  |
| 303M  | 1.818 | .56  |
| 304M  | 2.423 | .61  |
| 305M  | 2.512 | .68  |
| 306M  | 3.053 | .68  |
| 307M  | 3.624 | .85  |
| 308M  | 4.172 | .91  |
| 309M  | 4.767 | 1.00 |
| 310M  | 5.321 | 1.06 |
| 310AM | 6.15  | 1.30 |
| 310BM | 7.19  | 1.30 |

|        |       |       |
|--------|-------|-------|
| 301CB  | 1.053 | .37   |
| 302CB  | 1.327 | .37   |
| 303CB  | 1.584 | .37   |
| 304CB  | 1.952 | .50   |
| 305CB  | 2.201 | .52   |
| 306CB  | 2.093 | .52   |
| 307CB  | 3.235 | .85   |
| 308CB  | 3.855 | .85   |
| 309CB  | 4.359 | .85   |
| 310CB  | 5.011 | .85   |
| 310ACB | 6.15  | 1.30  |
| 310BCB | 7.25  | 1.125 |

## RIGID CONDUIT BUSHINGS

### ZINC DIE CAST

| TOPAZ CAT # | UPC#  | SIZE   | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|--------|----------|-----------|----------|
| 301         | 12530 | 1/2"   | 100      | 1000      | 30       |
| 302         | 12540 | 3/4"   | 100      | 1000      | 50       |
| 303         | 12550 | 1"     | 50       | 500       | 30       |
| 304         | 12560 | 1 1/4" | 25       | 250       | 25       |
| 305         | 12570 | 1 1/2" | 25       | 250       | 38       |
| 306         | 12580 | 2"     | 25       | 100       | 17       |
| 307         | 12590 | 2 1/2" | 10       | 100       | 36       |
| 308         | 12600 | 3"     | —        | 10        | 5        |
| 309         | 12610 | 3 1/2" | —        | 10        | 6        |
| 310         | 12620 | 4"     | —        | 10        | 7        |



### MALLEABLE IRON

|       |       |        |     |      |    |
|-------|-------|--------|-----|------|----|
| 301M  | 12630 | 1/2"   | 100 | 1000 | 50 |
| 302M  | 12640 | 3/4"   | 50  | 500  | 30 |
| 303M  | 12650 | 1"     | 50  | 500  | 24 |
| 304M  | 12660 | 1 1/4" | 25  | 250  | 30 |
| 305M  | 12670 | 1 1/2" | —   | 25   | 22 |
| 306M  | 12680 | 2"     | —   | 25   | 35 |
| 307M  | 12690 | 2 1/2" | —   | 15   | 20 |
| 308M  | 12700 | 3"     | —   | 10   | 10 |
| 309M  | 12710 | 3 1/2" | —   | 10   | 13 |
| 310M  | 12720 | 4"     | —   | 10   | 20 |
| 310AM | 12622 | 5"     | —   | 10   | 25 |
| 310BM | 12623 | 6"     | —   | 10   | 35 |




## RIGID CAPPED BUSHINGS

### STEEL CAP

### ZINC DIE CAST

| TOPAZ CAT # | UPC#  | SIZE   | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|--------|----------|-----------|----------|
| 301CB       | 12531 | 1/2"   | 100      | 1000      | 5        |
| 302CB       | 12541 | 3/4"   | 100      | 1000      | 7        |
| 303CB       | 12551 | 1"     | 50       | 500       | 11       |
| 304CB       | 12561 | 1 1/4" | 25       | 250       | 17       |
| 305CB       | 12571 | 1 1/2" | 25       | 250       | 21       |
| 306CB       | 12581 | 2"     | 25       | 1000      | 34       |
| 307CB       | 12591 | 2 1/2" | 10       | 100       | 48       |
| 308CB       | 12601 | 3"     | 10       | 100       | 61       |
| 309CB       | 12611 | 3 1/2" | —        | 10        | 70       |
| 310CB       | 12631 | 4"     | —        | 10        | 125      |
| 310ACB      | 12621 | 5"     | —        | 10        | 78       |
| 310BCB      | 85152 | 6"     | —        | 10        | 85       |



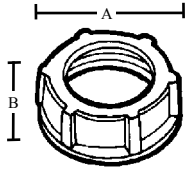

| CAT# | A     | B   |
|------|-------|-----|
| 301  | 1.053 | .37 |
| 302  | 1.327 | .37 |
| 303  | 1.584 | .47 |
| 304  | 1.952 | .50 |
| 305  | 2.201 | .52 |
| 306  | 2.693 | .52 |
| 307  | 3.235 | .85 |
| 308  | 3.855 | .85 |
| 309  | 4.359 | .85 |
| 310  | 5.011 | .85 |

|       |       |      |
|-------|-------|------|
| 301M  | 1.223 | .48  |
| 302M  | 1.498 | .49  |
| 303M  | 1.818 | .56  |
| 304M  | 2.423 | .61  |
| 305M  | 2.512 | .68  |
| 306M  | 3.053 | .68  |
| 307M  | 3.624 | .85  |
| 308M  | 4.172 | .91  |
| 309M  | 4.767 | 1.00 |
| 310M  | 5.321 | 1.06 |
| 310AM | 6.15  | 1.30 |
| 310BM | 7.19  | 1.30 |

|        |       |       |
|--------|-------|-------|
| 301CB  | 1.053 | .37   |
| 302CB  | 1.327 | .37   |
| 303CB  | 1.584 | .37   |
| 304CB  | 1.952 | .50   |
| 305CB  | 2.201 | .52   |
| 306CB  | 2.093 | .52   |
| 307CB  | 3.235 | .85   |
| 308CB  | 3.855 | .85   |
| 309CB  | 4.359 | .85   |
| 310CB  | 5.011 | .85   |
| 310ACB | 6.15  | 1.30  |
| 310BCB | 7.25  | 1.125 |

## RIGID CONDUIT BUSHINGS

### ZINC DIE CAST

| TOPAZ CAT # | UPC#  | SIZE   | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|--------|----------|-----------|----------|
| 301         | 12530 | 1/2"   | 100      | 1000      | 30       |
| 302         | 12540 | 3/4"   | 100      | 1000      | 50       |
| 303         | 12550 | 1"     | 50       | 500       | 30       |
| 304         | 12560 | 1 1/4" | 25       | 250       | 25       |
| 305         | 12570 | 1 1/2" | 25       | 250       | 38       |
| 306         | 12580 | 2"     | 25       | 100       | 17       |
| 307         | 12590 | 2 1/2" | 10       | 100       | 36       |
| 308         | 12600 | 3"     | —        | 10        | 5        |
| 309         | 12610 | 3 1/2" | —        | 10        | 6        |
| 310         | 12620 | 4"     | —        | 10        | 7        |



### MALLEABLE IRON

|       |       |        |     |      |    |
|-------|-------|--------|-----|------|----|
| 301M  | 12630 | 1/2"   | 100 | 1000 | 50 |
| 302M  | 12640 | 3/4"   | 50  | 500  | 30 |
| 303M  | 12650 | 1"     | 50  | 500  | 24 |
| 304M  | 12660 | 1 1/4" | 25  | 250  | 30 |
| 305M  | 12670 | 1 1/2" | —   | 25   | 22 |
| 306M  | 12680 | 2"     | —   | 25   | 35 |
| 307M  | 12690 | 2 1/2" | —   | 15   | 20 |
| 308M  | 12700 | 3"     | —   | 10   | 10 |
| 309M  | 12710 | 3 1/2" | —   | 10   | 13 |
| 310M  | 12720 | 4"     | —   | 10   | 20 |
| 310AM | 12622 | 5"     | —   | 10   | 25 |
| 310BM | 12623 | 6"     | —   | 10   | 35 |



## RIGID CAPPED BUSHINGS

### STEEL CAP

### ZINC DIE CAST

| TOPAZ CAT # | UPC#  | SIZE   | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|--------|----------|-----------|----------|
| 301CB       | 12531 | 1/2"   | 100      | 1000      | 5        |
| 302CB       | 12541 | 3/4"   | 100      | 1000      | 7        |
| 303CB       | 12551 | 1"     | 50       | 500       | 11       |
| 304CB       | 12561 | 1 1/4" | 25       | 250       | 17       |
| 305CB       | 12571 | 1 1/2" | 25       | 250       | 21       |
| 306CB       | 12581 | 2"     | 25       | 1000      | 34       |
| 307CB       | 12591 | 2 1/2" | 10       | 100       | 48       |
| 308CB       | 12601 | 3"     | 10       | 100       | 61       |
| 309CB       | 12611 | 3 1/2" | —        | 10        | 70       |
| 310CB       | 12631 | 4"     | —        | 10        | 125      |
| 310ACB      | 12621 | 5"     | —        | 10        | 78       |
| 310BCB      | 85152 | 6"     | —        | 10        | 85       |

