

DESCRIPTION

Coilex® Baffle trim in the 6" trim family for use in recessed downlighting.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

Black or white phenolic coilex baffle with separate metal ring. Uses coil spring retention. Trim available in a variety of finishes.

Lamp Listings - Incandescent

H7T	65W BR30, 75W R30, 75W PAR30
H7TCP	
H7RT	65W BR30, 75W R30, 75W PAR30, 75W PAR30L

H7ICAT	45W PAR38, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L
H7ICT	
H7RICAT	
H7RICT	


H7UICAT	65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W PAR38, 90W BR40, 100W, R40
H7UICT	

Lamp Listings - GU24


H724ICAT	CF15/R30/GU24
H724ICATL	
H724RICAT	CF13/GU24 (spiral)
H724RICATL	

Lamp Listings - Incandescent

H27ICAT	50W PAR30, 65W BR30, 75W PAR30L
H27ICT	
H27RICAT	
H27RICT	
H27RT	65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H27T	

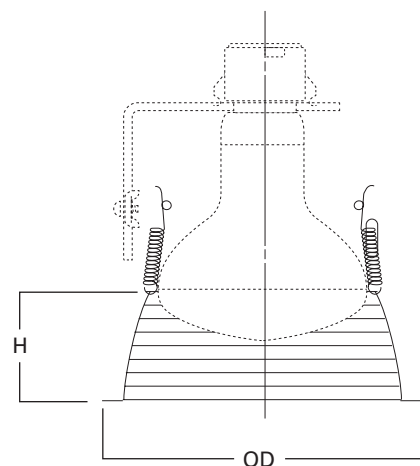


310W, P, SN, TBZ
Height: 3-1/16" [78mm]
Outside Diameter: 7-1/4" [184mm]

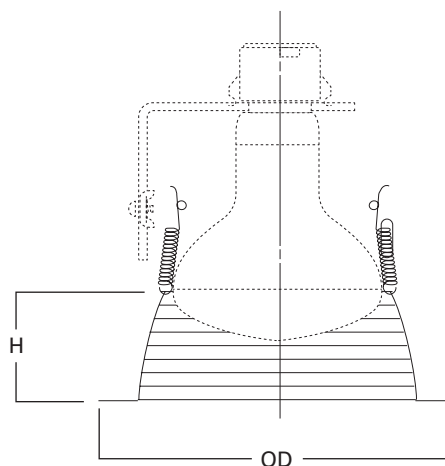

310WG, PG
Height: 3-1/16" [78mm]
Outside Diameter: 8" [203mm]

ORDERING INFORMATION


Trim	Finish	Accessories
310 = 6" Coilex baffle	W = White trim ring with white baffle P = Black trim ring with black baffle SN = Satin nickel trim ring with black baffle TBZ = Tuscan bronze trim ring with black baffle	OT403P = 6" Oversize trim ring - white Designer/Replacement Trim Rings TRM6P = 6" White metal TRM6C = 6" Chrome TRM6SN = 6" Satin nickel TRM6TBZ = 6" Tuscan bronze TRM6MB = 6" Black metal TRM7MB = 6" Black plastic

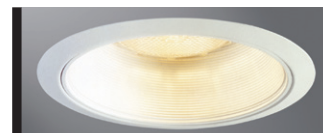

310W
White Trim, White Baffle



310P
White Trim, Black Baffle

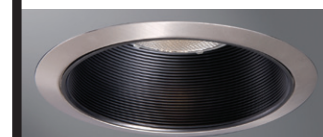

310SN
Satin Nickel Trim, Black Baffle



310TBZ
Tuscan Bronze Trim, Black Baffle

310

6-Inch Coilex® Baffle

DESCRIPTION

Coilex® Baffle trim in the 6" trim family for use in recessed downlighting.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

Black or white phenolic coilex baffle with separate metal ring. Uses coil spring retention. Trim available in a variety of finishes.

Lamp Listings - Incandescent

H7T	65W BR30, 75W R30, 75W PAR30
H7TCP	
H7RT	65W BR30, 75W R30, 75W PAR30, 75W PAR30L

H7ICAT	45W PAR38, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L
H7ICT	
H7RICAT	
H7RICT	


H7UICAT	65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W PAR38, 90W BR40, 100W, R40
H7UICT	

Lamp Listings - GU24


H724ICAT	CF15/R30/GU24
H724ICATL	
H724RICAT	CF13/GU24 (spiral)
H724RICATL	

Lamp Listings - Incandescent

H27ICAT	50W PAR30, 65W BR30, 75W PAR30L
H27ICT	
H27RICAT	
H27RICT	
H27RT	65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H27T	

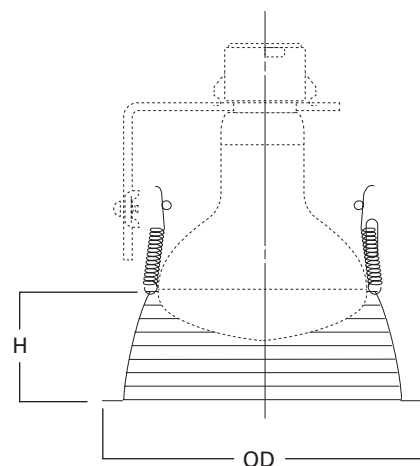


310W, P, SN, TBZ
Height: 3-1/16" [78mm]
Outside Diameter: 7-1/4" [184mm]

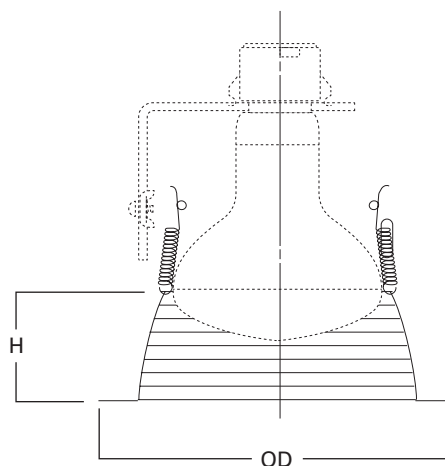

310WG, PG
Height: 3-1/16" [78mm]
Outside Diameter: 8" [203mm]

ORDERING INFORMATION


Trim	Finish	Accessories
310 = 6" Coilex baffle	W = White trim ring with white baffle P = Black trim ring with black baffle SN = Satin nickel trim ring with black baffle TBZ = Tuscan bronze trim ring with black baffle	OT403P = 6" Oversize trim ring - white Designer/Replacement Trim Rings TRM6P = 6" White metal TRM6C = 6" Chrome TRM6SN = 6" Satin nickel TRM6TBZ = 6" Tuscan bronze TRM6MB = 6" Black metal TRM7MB = 6" Black plastic

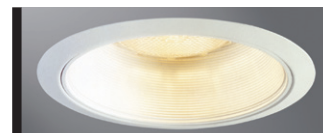

310W
White Trim, White Baffle



310P
White Trim, Black Baffle

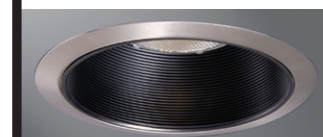

310SN
Satin Nickel Trim, Black Baffle



310TBZ
Tuscan Bronze Trim, Black Baffle

310

6-Inch Coilex® Baffle