



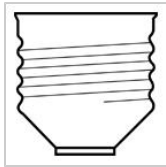

GE  
Lighting

**15199 - 40A15**

GE A15

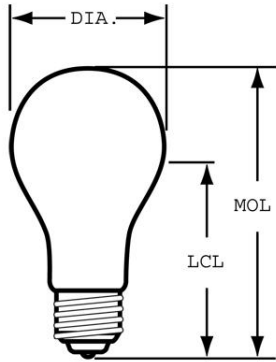

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Ceiling Fan

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

**ELECTRICAL CHARACTERISTICS**

Wattage	40.0
Voltage	120.0
Estimated Energy Cost per Year	4.82

**DIMENSIONS**

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

**PRODUCT INFORMATION**



Product Code	15199
Description	40A15
Standard Package	Case
Standard Package GTIN	00043168151993
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	120
UPC	043168910088



GE  
Lighting

**15199 - 40A15**

GE A15

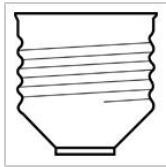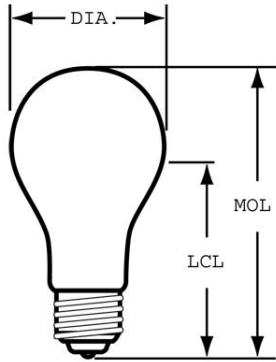

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Ceiling Fan

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

**ELECTRICAL CHARACTERISTICS**

Wattage	40.0
Voltage	120.0
Estimated Energy Cost per Year	4.82

**DIMENSIONS**

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

**PRODUCT INFORMATION**

Product Code	15199
Description	40A15
Standard Package	Case
Standard Package GTIN	00043168151993
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	120
UPC	043168910088