



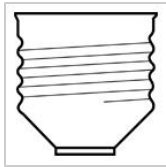

GE
Lighting

15199 - 40A15

GE A15

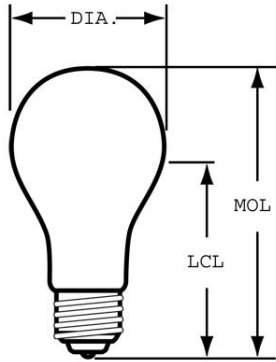

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

ELECTRICAL CHARACTERISTICS

Wattage	40.0
Voltage	120.0
Estimated Energy Cost per Year	4.82

DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

PRODUCT INFORMATION



Product Code	15199
Description	40A15
Standard Package	Case
Standard Package GTIN	00043168151993
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	120
UPC	043168910088



GE
Lighting

15199 - 40A15

GE A15

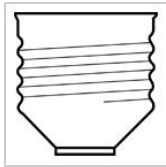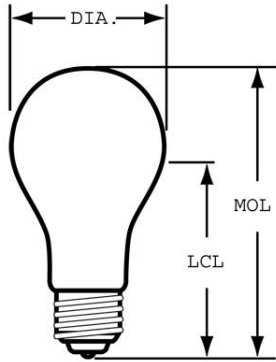

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

ELECTRICAL CHARACTERISTICS

Wattage	40.0
Voltage	120.0
Estimated Energy Cost per Year	4.82

DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

PRODUCT INFORMATION

Product Code	15199
Description	40A15
Standard Package	Case
Standard Package GTIN	00043168151993
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	2
No Of Items Per Standard Package	120
UPC	043168910088