






GE  
Lighting

## 27495 - 40A15/F/CD

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

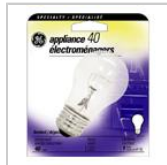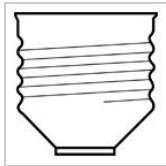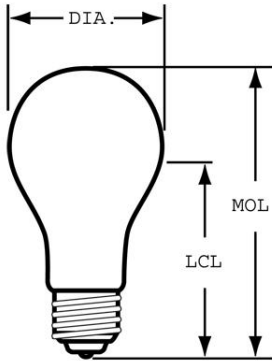

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Frost
Rated Life (NOM)	1500.0 h
Bulb Material	Soft glass
Primary Application	Standard;Ceiling Fan

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	355.0
Color Temperature (NOM)	2600.0 K
Nominal Initial Lumens per Watt (NOM)	8.875

### ELECTRICAL CHARACTERISTICS

Wattage (NOM)	40.0
Voltage (NOM)	120.0
Burn Position	Universal burning position

### DIMENSIONS

Maximum Overall Length (MOL) (NOM)	3.500 in(88.9 mm)
Bulb Diameter (DIA) (NOM)	1.875 in(47.6 mm)
Light Center Length (LCL) (NOM)	2.370 in(60.2 mm)

### PRODUCT INFORMATION

Product Code	27495
Description	40A15/F/CD
Standard Package	BUNDLE
Standard Package GTIN	30043168274952
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168274951






GE  
Lighting

## 27495 - 40A15/F/CD

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

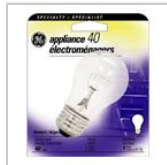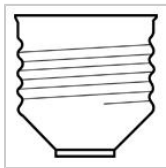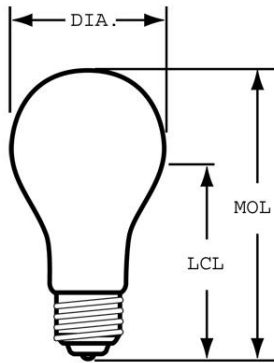

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Frost
Rated Life (NOM)	1500.0 h
Bulb Material	Soft glass
Primary Application	Standard;Ceiling Fan

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	355.0
Color Temperature (NOM)	2600.0 K
Nominal Initial Lumens per Watt (NOM)	8.875

### ELECTRICAL CHARACTERISTICS

Wattage (NOM)	40.0
Voltage (NOM)	120.0
Burn Position	Universal burning position

### DIMENSIONS

Maximum Overall Length (MOL) (NOM)	3.500 in(88.9 mm)
Bulb Diameter (DIA) (NOM)	1.875 in(47.6 mm)
Light Center Length (LCL) (NOM)	2.370 in(60.2 mm)

### PRODUCT INFORMATION

Product Code	27495
Description	40A15/F/CD
Standard Package	BUNDLE
Standard Package GTIN	30043168274952
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168274951