




GE
Lighting

25781 - 40R16/CD

GE soft white 40 watt R16 floodlight 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- Replace ordinary light bulbs with GE Flood and Spotlight in all your track and recessed lighting fixtures.
- 2500K soft white light appearance
- Estimated yearly energy costs \$4.82 based on 3 hours per day \$0.11 per kWh
- GE soft white indoor spotlights provide warm, pleasing everyday light without harsh glares and shadows. These bulbs' funnel shape and reflective coating help direct light where it is needed better than a standard incandescent bulb
- Lasts 1.4 years based on 3 hours per day usage
- 280 lumens providing subtle, reassuring™ light
- R16 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting

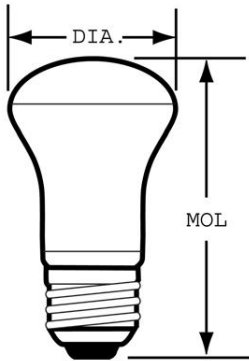

GENERAL CHARACTERISTICS

| | |
|---------------------|--------------------------|
| Lamp Type | Incandescent - Reflector |
| Bulb | R16 |
| Base | Medium Screw (E26) |
| Filament | CC-6 |
| Rated Life | 1500.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Indoor Spotlight |

PHOTOMETRIC CHARACTERISTICS

| | |
|-------------------|----------|
| Initial Lumens | 225.0 |
| Color Temperature | 2500.0 K |

ELECTRICAL CHARACTERISTICS


| | |
|---------|-------|
| Wattage | 40.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 3.3700 in(85.6 mm) |
| Bulb Diameter (DIA) | 2.000 in(50.8 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 25781 |
| Description | 40R16/CD |
| Standard Package | BUNDLE |
| Standard Package GTIN | 30043168257818 |
| Standard Package Quantity | 30 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 30 |
| UPC | 043168257817 |

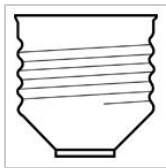

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.




GE
Lighting

25781 - 40R16/CD

GE soft white 40 watt R16 floodlight 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- Replace ordinary light bulbs with GE Flood and Spotlight in all your track and recessed lighting fixtures.
- 2500K soft white light appearance
- Estimated yearly energy costs \$4.82 based on 3 hours per day \$0.11 per kWh
- GE soft white indoor spotlights provide warm, pleasing everyday light without harsh glares and shadows. These bulbs' funnel shape and reflective coating help direct light where it is needed better than a standard incandescent bulb
- Lasts 1.4 years based on 3 hours per day usage
- 280 lumens providing subtle, reassuring™ light
- R16 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting

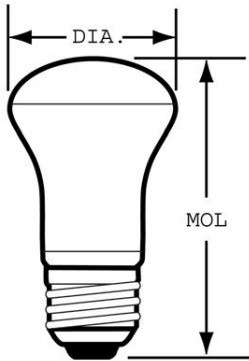

GENERAL CHARACTERISTICS

| | |
|---------------------|--------------------------|
| Lamp Type | Incandescent - Reflector |
| Bulb | R16 |
| Base | Medium Screw (E26) |
| Filament | CC-6 |
| Rated Life | 1500.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Indoor Spotlight |

PHOTOMETRIC CHARACTERISTICS

| | |
|-------------------|----------|
| Initial Lumens | 225.0 |
| Color Temperature | 2500.0 K |

ELECTRICAL CHARACTERISTICS


| | |
|---------|-------|
| Wattage | 40.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 3.3700 in(85.6 mm) |
| Bulb Diameter (DIA) | 2.000 in(50.8 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 25781 |
| Description | 40R16/CD |
| Standard Package | BUNDLE |
| Standard Package GTIN | 30043168257818 |
| Standard Package Quantity | 30 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 30 |
| UPC | 043168257817 |

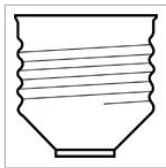

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.