

## Commercial grade straight blade plugs & connectors

### Product description


2-pole, 3-wire grounding  
20A, 125V/AC  
NEMA 5-20




5-20P



5-20R

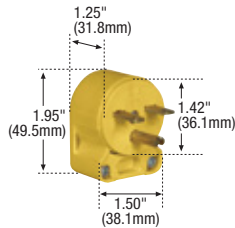

4866AN

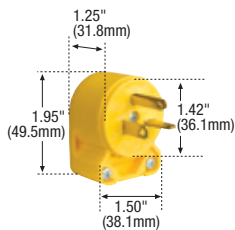

4509AN



4229

### Commercial grade plugs & connectors



| Rating<br>A | V/AC | NEMA | Description         | Cord<br>diameter        | Color | Plug<br>catalog no. | Connector<br>catalog no. |   |   |
|-------------|------|------|---------------------|-------------------------|-------|---------------------|--------------------------|---|---|
| 20          | 125  | 5-20 | Vinyl straight body | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4409*             | □ 4228*                  | • | • |
|             |      |      | Vinyl angled body   | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4409AN            | —                        | • | • |

\* UL and CSA Listed Only

## Commercial grade straight blade plugs & connectors

### Product description

2-pole, 2-wire grounding  
15A, 250V/AC  
NEMA 6-15



6-15P



6-15R

### Commercial grade plugs & connectors



| Rating<br>A | V/AC | NEMA | Description         | Cord<br>diameter        | Color | Plug<br>catalog no. | Connector<br>catalog no. |   |   |
|-------------|------|------|---------------------|-------------------------|-------|---------------------|--------------------------|---|---|
| 15          | 250  | 6-15 | Vinyl straight body | 0.25-0.66" (6.3-16.6mm) | Y     | —                   | □ 4227*                  | • | • |
|             |      |      | Vinyl angled body   | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4866AN            | —                        | • | • |

\* UL and CSA Listed Only

## Commercial grade straight blade plugs & connectors

### Product description

2-pole, 2-wire grounding  
20A, 250V/AC  
NEMA 6-20



6-20P



6-20R

### Commercial grade plugs & connectors



| Rating<br>A | V/AC | Vinyl<br>NEMA | Description         | Cord<br>diameter        | Color | Plug<br>catalog no. | Connector<br>catalog no. |   |   |
|-------------|------|---------------|---------------------|-------------------------|-------|---------------------|--------------------------|---|---|
| 20          | 250  | 6-20          | Vinyl straight body | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4509*             | □ 4229 <sup>†</sup>      | • | • |
|             |      |               | Vinyl angled body   | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4509AN            | —                        | • | • |

<sup>†</sup> Not NOM cert, \* UL Listed Only

### Color information:

Y (Yellow)



(Yellow)

**Commercial grade dimensional information:** B-17

**Specification information:**  
Commercial grade plugs & connectors: B-26

**Compliances, specifications and availability are subject to change without notice.**

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32

## Commercial grade straight blade plugs & connectors

### Product description


2-pole, 3-wire grounding  
20A, 125V/AC  
NEMA 5-20



5-20P



5-20R

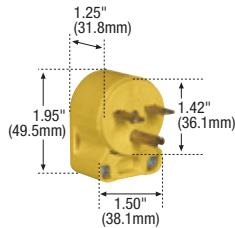

4866AN

### Commercial grade plugs & connectors



| Rating A | V/AC | NEMA | Description         | Cord diameter           | Color | Plug catalog no. | Connector catalog no. |   |   |
|----------|------|------|---------------------|-------------------------|-------|------------------|-----------------------|---|---|
| 20       | 125  | 5-20 | Vinyl straight body | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4409*          | □ 4228*               | • | • |
|          |      |      | Vinyl angled body   | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4409AN         | —                     | • | • |

\* UL and CSA Listed Only

## Commercial grade straight blade plugs & connectors

### Product description


2-pole, 2-wire grounding  
15A, 250V/AC  
NEMA 6-15



6-15P



6-15R

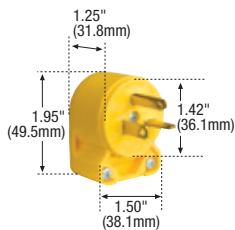

4509AN

### Commercial grade plugs & connectors



| Rating A | V/AC | NEMA | Description         | Cord diameter           | Color | Plug catalog no. | Connector catalog no. |   |   |
|----------|------|------|---------------------|-------------------------|-------|------------------|-----------------------|---|---|
| 15       | 250  | 6-15 | Vinyl straight body | 0.25-0.66" (6.3-16.6mm) | Y     | —                | □ 4227*               | • | • |
|          |      |      | Vinyl angled body   | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4866AN         | —                     | • | • |

\* UL and CSA Listed Only

## Commercial grade straight blade plugs & connectors

### Product description

2-pole, 2-wire grounding  
20A, 250V/AC  
NEMA 6-20



6-20P



6-20R



4229

### Commercial grade plugs & connectors



| Rating A | V/AC | Vinyl NEMA | Description         | Cord diameter           | Color | Plug catalog no. | Connector catalog no. |   |   |
|----------|------|------------|---------------------|-------------------------|-------|------------------|-----------------------|---|---|
| 20       | 250  | 6-20       | Vinyl straight body | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4509*          | □ 4229 <sup>†</sup>   | • | • |
|          |      |            | Vinyl angled body   | 0.25-0.66" (6.3-16.6mm) | Y     | □ 4509AN         | —                     | • | • |

<sup>†</sup> Not NOM cert, \* UL Listed Only

### Color information:

Y (Yellow)



(Yellow)

**Commercial grade dimensional information:** B-17

**Specification information:**  
Commercial grade plugs & connectors: B-26

**Compliances, specifications and availability are subject to change without notice.**

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32