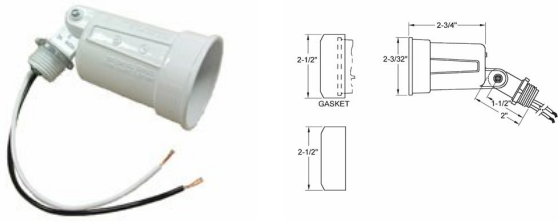


**LAMP HOLDERS****Traditional Lampholder
75-150 Watt Par 38 Lamps****D23**

Catalog #: 5606-1

APPLICATIONS

For general outdoor lighting in wet, damp or dry locations
 May be used with BELL® cluster covers and boxes

PRODUCT FEATURES

Rugged die cast construction
 State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
 Locking swivel knuckle assures positive lamp positioning and provides pin-point directional aiming
 Extra long wire leads for easy hook-up
 Porcelain socket
 Inside Gasket
 Multi-lingual instructions in each package
 1/2 in. locknut
 N/A

UL LISTED

Standard 1598

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Color: White

PRODUCT MEASUREMENTS

Wt. Ea. (Lbs.): 0.464

PACKAGING


Package Type: Shrink
 Std. Pkg.: 30
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 46.40
 Ship Carton Length (in.): 16.19
 Ship Carton Width (in.): 4.25
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 13.92
 Pallet Qty: 4500.00
 UPC Number: 050169560617
 I2of5: 50050169560612



LAMP HOLDERS

**Traditional Lampholder
75-150 Watt Par 38 Lamps**

D23

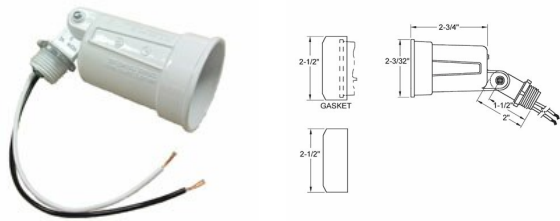

Catalog #: 5606-1

APPLICATIONS

For general outdoor lighting in wet, damp or dry locations
May be used with BELL® cluster covers and boxes

PRODUCT FEATURES

- Rugged die cast construction
- State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
- Locking swivel knuckle assures positive lamp positioning and provides pin-point directional aiming
- Extra long wire leads for easy hook-up
- Porcelain socket
- Inside Gasket
- Multi-lingual instructions in each package
- 1/2 in. locknut
- N/A

UL LISTED

Standard 1598

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Color: White

PRODUCT MEASUREMENTS

Wt. Ea. (Lbs.): 0.464

PACKAGING

Package Type:	Shrink
Std. Pkg.:	30
Product UPC-A Labeled:	Yes
Weight (Lbs. Per/C):	46.40
Ship Carton Length (in.):	16.19
Ship Carton Width (in.):	4.25
Ship Carton Height (in.):	8.50
Ctn Weight (Lbs.):	13.92
Pallet Qty:	4500.00
UPC Number:	050169560617
I2of5:	50050169560612