



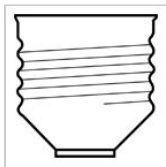

GE
Lighting

46855 - 65R30/FL

GE BR30

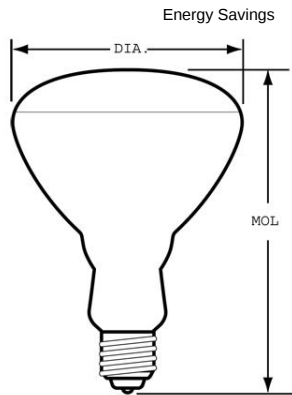

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	BR30
Base	Medium Screw (E26)
Filament	CC-6
Rated Life	2000.0 hrs
Life in Years	1.8

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	670.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	11

ELECTRICAL CHARACTERISTICS

Wattage	65.0
Voltage	130.0
Estimated Energy Cost per Year	7.83

DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)

PRODUCT INFORMATION



Product Code	46855
Description	65R30/FL
Standard Package	BUNDLE
Standard Package GTIN	00043168468558
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168142632



GE
Lighting

46855 - 65R30/FL

GE BR30

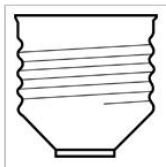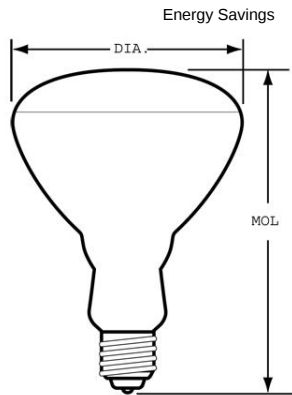

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	BR30
Base	Medium Screw (E26)
Filament	CC-6
Rated Life	2000.0 hrs
Life in Years	1.8

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	670.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	11

ELECTRICAL CHARACTERISTICS

Wattage	65.0
Voltage	130.0
Estimated Energy Cost per Year	7.83

DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)

PRODUCT INFORMATION

Product Code	46855
Description	65R30/FL
Standard Package	BUNDLE
Standard Package GTIN	00043168468558
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168142632