

Plenum Electronic Wire

Plenum Unshielded Electronic Wire

Part Number	Description	AWG	Cond	UL Type	Weight (Nom.)	Outside Dia. (Nom.)	Packaging	Jacket Color
72302	22/2 stranded BC (7/30)	22	2	CMP CL3P	10 lbs	0.109"	1,000' Box (46)	Natural (23)
72304	22/4 stranded BC (7/30)	22	4	CMP CL3P	15 lbs	0.127"	1,000' Box (46)	Natural (23)
72306	22/6 stranded BC (7/30)	22	6	CMP CL3P	22 lbs	0.150"	1,000' Box (46)	Natural (23)
72308	22/8 stranded BC (7/30)	22	8	CMP CL3P	27 lbs	0.163"	1,000' Reel (06)	Natural (23)
72310	22/10 stranded BC (7/30)	22	10	CMP CL3P	37 lbs	0.198"	1,000' Reel (06)	Natural (23)
72312	22/12 stranded BC (7/30)	22	12	CMP CL3P	43 lbs	0.203"	1,000' Reel (06)	Natural (23)
71902	18/2 stranded BC (7/0.0152)	18	2	CMP CL3P	20 lbs	0.142"	1,000' Reel (06) 1,000' Box (46)	Natural (23)
71903	18/3 stranded BC (7/0.0152)	18	3	CMP CL3P	25 lbs	0.151"	1,000' Reel (06) 1,000' Box (46)	Natural (23)
71904	18/4 stranded BC (7/0.0152)	18	4	CMP CL3P	33 lbs	0.166"	1,000' Reel (06) 1,000' Box (46)	Natural (23)
71906	18/6 stranded BC (7/0.0152)	18	6	CMP CL3P	48 lbs	0.205"	1,000' Reel (06)	Natural (23)
71908	18/8 stranded BC (7/0.0152)	18	8	CMP CL3P	61 lbs	0.223"	1,000' Reel (06)	Natural (23)
71910	18/10 stranded BC (7/0.0152)	18	10	CMP CL3P	75 lbs	0.262"	1,000' Reel (06)	Natural (23)
71912	18/12 stranded BC (7/0.0152)	18	12	CMP CL3P	88 lbs	0.271"	1,000' Reel (06)	Natural (23)
71702	16/2 stranded BC (19/0.0117)	16	2	CMP CL3P	27 lbs	0.177"	1,000' Reel (06)	Natural (23)
71703	16/3 stranded BC (19/0.0117)	16	3	CMP CL3P	37 lbs	0.195"	1,000' Reel (06)	Natural (23)
71704	16/4 stranded BC (19/0.0117)	16	4	CMP CL3P	51 lbs	0.214"	1,000' Reel (06)	Natural (23)
71502	14/2 stranded BC (19/0.0147)	14	2	CMP CL3P	41 lbs	0.206"	1,000' Reel (06)	Natural (23)



71902



71904

Packaging Options

Coleman Cable offers four types of packaging options.


- Signa-Coil
- Reel-in-box
- Pull-out box (Rabbit pull)
- Reels

All provide fast and easy cable access. Kinks and twists are eliminated. You get tangle-free cable delivery each and every time. These durable, compact designs save on installation time while reducing waste and material costs. They can be easily stacked to save room.

* Not all options are available for each product



Coleman Cable Part Legend

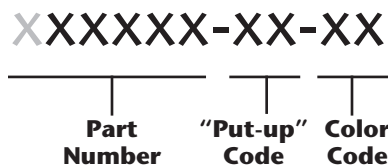

Put-ups	Code	Colors	Code		Code
Reel, 250 ft	04	White	01	Pink	11
Reel, 500 ft	05	Yellow	02	Purple	13
Reel, 1,000 ft	06	Orange	03	Clear	18
Reel-in-box, 1,000 ft	16	Red	04	Fluorescent	
RabbitPull™ Pull-Box, 500 ft	45	Green	05	Pink	21
RabbitPull™ Pull-Box, 1,000 ft	46	Blue	06	Ivory	22
SignaCoil™ 500 ft	55	Brown	07	Natural	23
SignaCoil™ 1,000 ft	56	Black	08	Beige	33
		Gray	09	Red Striped	
				CorraClad™	44



Plenum Electronic Wire

Plenum Unshielded Electronic Wire

Part Number	Description	AWG	Cond	UL Type	Weight (Nom.)	Outside Dia. (Nom.)	Packaging	Jacket Color
72302	22/2 stranded BC (7/30)	22	2	CMP CL3P	10 lbs	0.109"	1,000' Box (46)	Natural (23)
72304	22/4 stranded BC (7/30)	22	4	CMP CL3P	15 lbs	0.127"	1,000' Box (46)	Natural (23)
72306	22/6 stranded BC (7/30)	22	6	CMP CL3P	22 lbs	0.150"	1,000' Box (46)	Natural (23)
72308	22/8 stranded BC (7/30)	22	8	CMP CL3P	27 lbs	0.163"	1,000' Reel (06)	Natural (23)
72310	22/10 stranded BC (7/30)	22	10	CMP CL3P	37 lbs	0.198"	1,000' Reel (06)	Natural (23)
72312	22/12 stranded BC (7/30)	22	12	CMP CL3P	43 lbs	0.203"	1,000' Reel (06)	Natural (23)
71902	18/2 stranded BC (7/0.0152)	18	2	CMP CL3P	20 lbs	0.142"	1,000' Reel (06) 1,000' Box (46)	Natural (23)
71903	18/3 stranded BC (7/0.0152)	18	3	CMP CL3P	25 lbs	0.151"	1,000' Reel (06) 1,000' Box (46)	Natural (23)
71904	18/4 stranded BC (7/0.0152)	18	4	CMP CL3P	33 lbs	0.166"	1,000' Reel (06) 1,000' Box (46)	Natural (23)
71906	18/6 stranded BC (7/0.0152)	18	6	CMP CL3P	48 lbs	0.205"	1,000' Reel (06)	Natural (23)
71908	18/8 stranded BC (7/0.0152)	18	8	CMP CL3P	61 lbs	0.223"	1,000' Reel (06)	Natural (23)
71910	18/10 stranded BC (7/0.0152)	18	10	CMP CL3P	75 lbs	0.262"	1,000' Reel (06)	Natural (23)
71912	18/12 stranded BC (7/0.0152)	18	12	CMP CL3P	88 lbs	0.271"	1,000' Reel (06)	Natural (23)
71702	16/2 stranded BC (19/0.0117)	16	2	CMP CL3P	27 lbs	0.177"	1,000' Reel (06)	Natural (23)
71703	16/3 stranded BC (19/0.0117)	16	3	CMP CL3P	37 lbs	0.195"	1,000' Reel (06)	Natural (23)
71704	16/4 stranded BC (19/0.0117)	16	4	CMP CL3P	51 lbs	0.214"	1,000' Reel (06)	Natural (23)
71502	14/2 stranded BC (19/0.0147)	14	2	CMP CL3P	41 lbs	0.206"	1,000' Reel (06)	Natural (23)



71902



71904

Packaging Options

Coleman Cable offers four types of packaging options.

- Signa-Coil
- Reel-in-box
- Pull-out box (Rabbit pull)
- Reels

All provide fast and easy cable access. Kinks and twists are eliminated. You get tangle-free cable delivery each and every time. These durable, compact designs save on installation time while reducing waste and material costs. They can be easily stacked to save room.

* Not all options are available for each product



Coleman Cable Part Legend

XXXXXX-XX-XX



Put-ups

Put-ups	Code
Reel, 250 ft	04
Reel, 500 ft	05
Reel, 1,000 ft	06
Reel-in-box, 1,000 ft	16
RabbitPull™ Pull-Box, 500 ft	45
RabbitPull™ Pull-Box, 1,000 ft	46
SignaCoil™ 500 ft	55
SignaCoil™ 1,000 ft	56

Colors

Colors	Code	Colors	Code
White	01	Pink	11
Yellow	02	Purple	13
Orange	03	Clear	18
Red	04	Fluorescent	21
Green	05	Pink	21
Blue	06	Ivory	22
Brown	07	Natural	23
Black	08	Beige	33
Gray	09	Red Striped	44
		CorraClad™	44

