




Fluorescent Lampholders Medium & Tall Profile

Medium Profile - T8 & T12

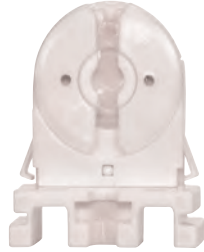

80-1252
Shunted for Instant Start Ballast Applications

80-1253
Rapid Start Applications
1 1/2" H x 1 1/4" W x 3/4" Dia.
660W-600V



80-1254
Rapid Start Applications
Slide-On Mounting, 20 Gauge Slots Upper & Lower

80-2127 w/Nut & Screw
80-1255, 80-1256
Shunted for Instant Start Ballast Applications
Slide-On Mounting, 20 Gauge Slots Upper & 18 Gauge Lower
1 5/8" H x 1 1/4" W x 3/4" Dia.
660W-600V



80-1245
Shunted for Instant Start Ballast Applications

80-1246
Rapid Start Applications, Tall Rotary Locking T8/T12
Used in Troffer and Wrap Fixtures for
Retro Fit Kits/Replacements Snap Wing Mounting
1 3/4" H x 1 1/8" W x 7/8" Dia.
Made from Urea 660W-600V



80-1257
Rapid Start Applications

80-1258
Shunted for Instant Start Ballast Applications
1 9/16" H x 1 1/4" W x 3/4" Dia.
660W-600V



80-1247
Tall Standard Twist-In Used in Strip Fixtures for
Rapid Start Applications, Slide-On Mounting
20 Gauge Slots Upper & Lower
2" H x 1 1/4" W x 3/4" Dia.
Made from Urea 660W-600V



80-1248
Tall Standard Twist-In Externally Shunted Used in Strip Fixtures for
Instant Start Ballasts, Slide-On Mounting
20 Gauge Slots Upper & 18 Gauge Lower
2" H x 1 1/4" W x 3/4" Dia.
Made from Urea 660W-600V


Instant - Shunted
Rapid - Not Shunted

SOCKETS & LAMP HOLDERS



Fluorescent Lampholders Medium & Tall Profile

Medium Profile - T8 & T12

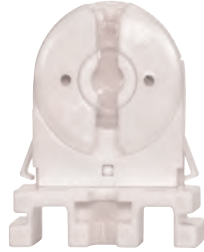

80-1252
Shunted for Instant Start Ballast Applications

80-1253
Rapid Start Applications
1 1/2" H x 1 1/4" W x 3/4" Dia.
660W-600V



80-1254
Rapid Start Applications
Slide-On Mounting, 20 Gauge Slots Upper & Lower

80-2127 w/Nut & Screw
80-1255, 80-1256
Shunted for Instant Start Ballast Applications
Slide-On Mounting, 20 Gauge Slots Upper & 18 Gauge Lower
1 5/8" H x 1 1/4" W x 3/4" Dia.
660W-600V



80-1245
Shunted for Instant Start Ballast Applications

80-1246
Rapid Start Applications, Tall Rotary Locking T8/T12
Used in Troffer and Wrap Fixtures for
Retro Fit Kits/Replacements Snap Wing Mounting
1 3/4" H x 1 1/8" W x 7/8" Dia.
Made from Urea 660W-600V



80-1257
Rapid Start Applications

80-1258
Shunted for Instant Start Ballast Applications
1 9/16" H x 1 1/4" W x 3/4" Dia.
660W-600V



80-1247
Tall Standard Twist-In Used in Strip Fixtures for
Rapid Start Applications, Slide-On Mounting
20 Gauge Slots Upper & Lower
2" H x 1 1/4" W x 3/4" Dia.
Made from Urea 660W-600V



80-1248
Tall Standard Twist-In Externally Shunted Used in Strip Fixtures for
Instant Start Ballasts, Slide-On Mounting
20 Gauge Slots Upper & 18 Gauge Lower
2" H x 1 1/4" W x 3/4" Dia.
Made from Urea 660W-600V

Instant - Shunted
Rapid - Not Shunted

SOCKETS & LAMP HOLDERS