


## 90° Zinc

### Images

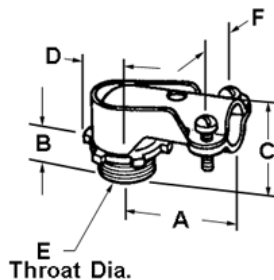

Throat Dia.

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-3/8

Dimension B in Inches: 5/8

Dimension C in Inches: 1-1/16

Dimension D in Inches: 1/2

Dimension E in Inches: .562

Dimension F in Inches: 15/16

### Application

90 Degree fitting with cover recommended cable types used for connecting flexible metal conduit to box or enclosure. 14/4 (.45" 0 min) to 10/4 (.625" 0 max). MC/MCI-A

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 801-DC2

**UPC Number:** 781747158017

**Description:** Connector, 90 Degrees, Zinc Die Cast, Flex Size 3/8 Inch

**Application:** 90 Degree fitting with cover recommended cable types used for connecting flexible metal conduit to box or enclosure. 14/4 (.45" 0 min) to 10/4 (.625" 0 max). MC/MCI-A

**Trade Size:** 1/2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 250

**Unit Qty:** 25