

# Eaton BRP20L200G

Catalog Number: BRP20L200G

Eaton Eaton Type BR 1-inch PON loadcenter, 200 A, MLO, 20 spaces, w/ ground bar

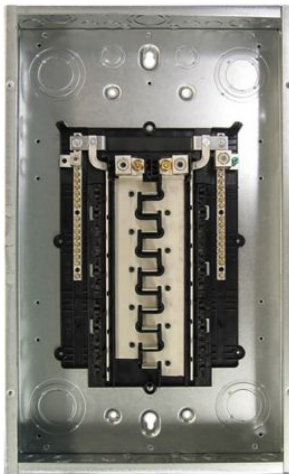


Photo is representative

## General specifications

Product Name	Catalog Number
Eaton BR main lug loadcenter	BRP20L200G
UPC	Product Length/Depth
786689053277	23 in
Product Height	Product Width
3.88 in	14.31 in
Product Weight	Warranty
21 lb	10 year
Certifications	
UL 50	
UL 67	

## defaultTaxonomyAttributeLabel

### Type

MLO

### Amperage Rating

200 A

### Bus material

Aluminum

### Cover

Cover included

### Number of circuits

40

### Number Of Poles

Single-pole

### Number of spaces

20

### Phase

Single-phase

### Used with

Type BR 1-inch breakers

### Voltage rating

120/240V

### Box size

X3

### Enclosure

NEMA 1

### Enclosure material

Metallic

### Interrupt rating

10 kAIC

### NEMA rating

NEMA 1

### Number of wires

Two hots, neutral and ground

## Resources

### Specifications and datasheets

Eaton Specification Sheet - BRP20L200G

### Warranty guides

Eaton type BR circuit breaker limited warranty June 2024



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://Eaton.com/socialmedia)