


Eaton BRP60B200

Catalog Number: BRP60B200

Plug-on neutral main circuit breaker loadcenter,200A,X10,Aluminum,Cover included,NEMA 1,Metallic,25kAIC,CSR2200,120 circuits,Single pole,60 spaces,Two hots, a neutral, and a ground,Single-phase,Gray,Combination,NEMA 1,Type BR 1-inch breaker

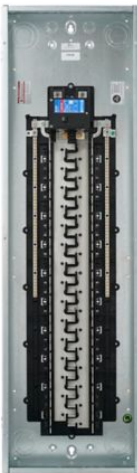

General specifications

Product Name	Catalog Number
Eaton BR main breaker loadcenter	BRP60B200
UPC	Product Length/Depth
786689053062	48 in
Product Height	Product Width
3.88 in	14.31 in
Product Weight	Warranty
42.8 lb	10 year
Certifications	
UL 67	
UL 50	

Product specifications

Type

Plug-on neutral main circuit breaker loadcenter

Amperage Rating

200 A

Bus material

Aluminum

Cover

Cover included

Main circuit breaker

CSR2200

Number of circuits

120

Number Of Poles

Single-pole

Number of spaces

60

Phase

Single-phase

Enclosure color

Gray

Mounting

Combination

Used with

Type BR 1-inch breakers

Voltage rating

120/240 V

Box size

X10

Enclosure

NEMA 1

Enclosure material

Metallic

Interrupt rating

25 kAIC

Resources

Brochures

[Loadcenters and Circuit Breakers](#)

Specifications and datasheets

[Eaton Specification Sheet - BRP60B200](#)

Warranty guides

[Eaton type BR circuit breaker limited warranty June 2024](#)

Number of wires

Two hots, neutral and ground

NEMA rating

NEMA 1



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)