


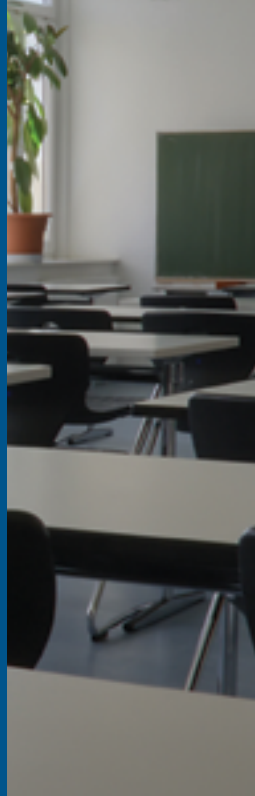

CSL Striplight

CCL Center-Lens Troffer

CWP Wrap Luminaire



Simple. Reliable. Convenient.

tradeSELECT®



- Simple fluorescent replacement
- Readily available in stock
- Affordably priced
- Utility rebate friendly
- User friendly with access to LED boards and drivers from below
- Choice of two LED color temperatures
- Familiar shapes, sizes, and appearances for simplicity of use

CSL Striplight

- 4,000 and 8,000 lumens
- Up to 112 lumens per watt
- 3500K or 4000K CCT
- 0-10V dimming, standard
- Fully assembled for quick installation
- Frosted acrylic lens
- Wide range of applications
- Surface mount
- Universal voltage (120-277V)
- 80+ CRI
- DesignLights Consortium® (DLC) qualified; see details at www.designlights.org

CCL Center-Lens Troffer

- 3,300 - 5,000 lumens
- Up to 118 lumens per watt
- 3500K or 4000K CCT
- 0-10V dimming, standard
- Fully assembled for quick installation
- Frosted acrylic lens
- Wide range of applications
- Recessed mount
- Universal voltage (120-277V)
- 80+ CRI
- IC Rated
- DesignLights Consortium® (DLC) qualified; see details at www.designlights.org

CWP Wrap Luminaire

- 4,000 lumens
- Up to 124 lumens per watt
- 3500K or 4000K CCT
- 0-10V dimming, standard
- Fully assembled for quick installation
- Frosted acrylic lens
- Wide range of applications
- Surface mount
- Universal Voltage (120-277V)
- 80+ CRI
- DesignLights Consortium® (DLC) qualified; see details at www.designlights.org

CSL ORDERING INFORMATION

Catalog Number	Description	Lumens	Watts	LPW	Qty on Pallet
CSL4-4035	4ft LED Striplight, 4,000 Lumens, 3500K, 0-10V dimming	4231	40.2	105	120
CSL4-4040	4ft LED Striplight, 4,000 Lumens, 4000K, 0-10V dimming	4517	40.2	112	120
CSL8-8035	8ft LED Striplight, 8,000 Lumens, 3500K, 0-10V dimming	8460	80.5	105	120
CSL8-8040	8ft LED Striplight, 8,000 Lumens, 4000K, 0-10V dimming	9036	80.5	112	120

CCL ORDERING INFORMATION

Catalog Number	Description	Lumens	Watts	LPW	Qty on Pallet
CCL22-3335	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K	3223	28.9	112	40
CCL22-3340	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K	3345	28.9	116	40
CCL24-5035	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K	5001	43.9	114	20
CCL24-5040	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K	5191	43.9	118	20

CWP ORDERING INFORMATION

Catalog Number	Description	Lumens	Watts	LPW	Qty on Pallet
CWP4-4035	4ft LED Wrap, 4,000 Lumens, 3500K, 0-10V dimming	4584	36.9	124	33
CWP4-4040	4ft LED Wrap, 4,000 Lumens, 4000K, 0-10V dimming	4584	36.9	124	33