

# DURAFLOOD 150


## LED FLOOD LIGHT (150 WATT)

400 MH Replacement



**480V**

Lumens	13,500
CCT	3000-3500K, 4000-4500K, 6000-6500K
CRI	> 75
Beam Angle	60°, 120°
Operating Voltage	100 - 277 VAC      180 - 528 VAC
Power Consumption	150W
Driver	Mean Well
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	16.73" x 12.79" x 9.44"
Weight	23.14 lbs

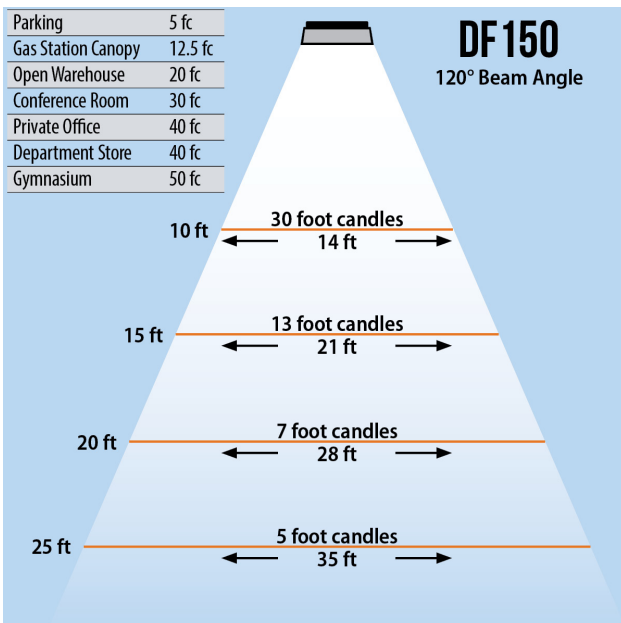

### ORDER CODE Example: DF150-BRZ-150W120D6K

Fixture	Finish	Beam Angle	CCT	Voltage
DF150- Trunnion	BRZ- Bronze	150W120-120°	6K- 6000K	___ - 240V
	GR- Gray		4K- 4000K	4V- 480V
	SS- Salt Spray		3K- 3000K	

Slipfitter Option, <b>Bronze</b>	SF-BRZ-180
Slipfitter Option, <b>Gray</b>	SF-GR-180

# DURAFLOOD 150



## LED FLOOD LIGHT (150 WATT)

400 MH Replacement




**480V**

Lumens	13,500
CCT	3000-3500K, 4000-4500K, 6000-6500K
CRI	> 75
Beam Angle	60°, 120°
Operating Voltage	100 - 277 VAC      180 - 528 VAC
Power Consumption	150W
Driver	Mean Well
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	16.73" x 12.79" x 9.44"
Weight	23.14 lbs

Parking	5 fc
Gas Station Canopy	12.5 fc
Open Warehouse	20 fc
Conference Room	30 fc
Private Office	40 fc
Department Store	40 fc
Gymnasium	50 fc

### DF150 120° Beam Angle

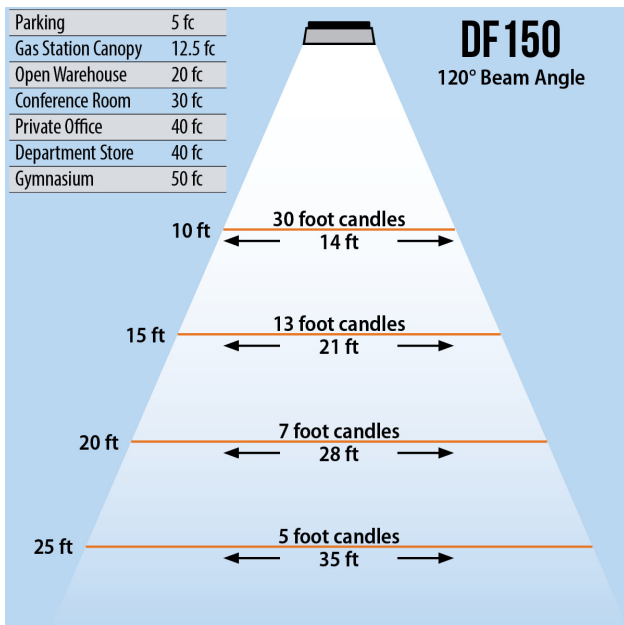

## ORDER CODE Example: DF150-BRZ-150W120D6K

Fixture	Finish	Beam Angle	CCT	Voltage
DF150- Trunnion	BRZ- Bronze	150W120-120°	6K- 6000K	___ - 240V
	GR- Gray		4K- 4000K	4V- 480V
	SS- Salt Spray		3K- 3000K	

Slipfitter Option, <b>Bronze</b>	SF-BRZ-180
Slipfitter Option, <b>Gray</b>	SF-GR-180