

**Description**

The E71CAT is a compact and efficient recessed housing optimized and listed for EISA compliant tungsten-halogen, CFL and LED lamps as well as incandescent. Housing is suitable for residential or light commercial applications. For installation in insulated ceilings\* and non-insulated ceilings with airtight code compliant construction. Use with a variety of trims and finishes to create different lighting effects or to match any decor. May be retrofit with compatible HALO LED lighting systems.

Catalog #		Type
Project		
Comments		Date
Prepared by		

**Specification Features**

**Housing**

- Single wall die-formed aluminum housing
- Housing features a precision rolled interlocking collar which maintains aperture geometry for greater assurance of installation results
- Integral Air-Tite gasket for code-required gasket between fixture and finished ceiling - seals aperture without need for additional caulk
- May be removed from the plaster frame to provide access to junction box

**Socket Plate**

- Rigid socket plate adjusts and locks without tools for various lamp sizes.
- Socket plate and bracket may be removed when using socket supporting trims

**Plaster Frame**

- Galvanized steel frame. Housing adjusts in plaster frame to accommodate up to 3/8" - 1" ceiling thickness
- (2) Regressed locking screws for securing hanger bars
- Integral Air-Tite gasket seals housing and meets code-required gasket between fixture and finished ceiling

**Includes:**

**Bar Hangers  
All Nail!™**

- Integral precisely positioned nail for engineered and natural framing
- Mini-foot leveling flange
- Integral T-Grid Clip, no accessory clips required

**q-Channel bars with Pass-N-Thru™**

- Unique inverted "q" interlocking channel for rigidity and stability
- Pass-N-Thru™ feature allows bars to cross-over for tool-less shortening in tight spaces

**Hinged junction box w/  
Slide-N-Side™**

- (3) Slide-N-Side™ Non-Metallic (NM) wire traps, allow wiring outside the box
- For 14-2, 14-3, 12-2, 12-3 U.S. and 14-2, 14-3, 12-2 Canadian
- (4) 1/2" conduit pry-outs
- Hinged door for easy access
- Box is repositionable 90° on frame to avoid obstructions

**Quick Connect™**

- (3) Push wire nuts included, for speed & reliability
- Clear caps for wire connection visibility

**cULus Listed**

- Compact 16 in<sup>3</sup> volume
- Listed for max. (10) No. 12 AWG or (14) No. 14 AWG 90° C splice conductors in box

**Air-Tite™ code compliant**

- Certified under ASTM E283
- Exclusive gasket seals aperture, frame & ceiling
- No additional caulk required

**Socket**

- Porcelain socket with nickel plated brass screw shell
- Snap-in springs secure socket to socket plate, and may be detached when using socket supporting trims

**Thermal Protector**

- Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping

**Trims**

- Halo Fit-All concept offers multiple trim options in a variety of design styles, and functional beam distributions to control beam angle and lumen delivery in accommodating various lamp types including Halogen, CFL and LED

**Compliance**

- cULus Listed 1598 Luminaire
- cULus Listed Damp Location
- cULus Listed for Wet Location, covered ceiling, with select trims
- cULus Listed for direct contact with insulation and combustible material\*
- Air-Tite code compliant. Certified under ASTM E283; not exceeding 2.0 cfm (0.944 L/s) air leakage rate tested at a 1.57 psf (75 Pa) pressure differential
- RoHS compliant

\*Not to be used in direct contact with spray foam insulation (Consult NEMA LSD57-2013)



**E71CAT**


**6" IC, Air-Tite,  
New Construction Housing**

**E26 Screw base housing**

**FOR USE IN INSULATED  
CEILINGS**

**FOR DIRECT CONTACT  
WITH INSULATION\***

**Dimensions**

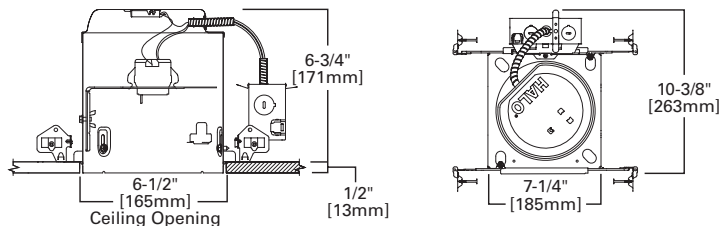

**Special Features**

- All-Nail!™ bar hangers
- q-Channel bars with Pass-N-Thru™
- Hinged J-Box with Slide-N-Side™
- Quick Connect™ push wire nuts
- Air-Tite™ code compliant

## Ordering Information







































Sample Number: E7ICAT 6110WB

Order housing, trim and lamp (by others) separately for a complete luminaire.

### Housing

E7ICAT = 6" insulated ceiling, airtight recessed housing, new construction, 120V

### Trims

	<p><b>Reflectors</b></p> <p><b>30 Reflector, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>30HAT</b>=Haze Reflector, White Trim <b>30RGAT</b>=Residential Gold Reflector, White Trim <b>30CAT</b>=Clear Specular Reflector, White Trim</p>		<p><b>312 Coilex® Baffle</b> OD: 7-1/4" [184mm]</p> <p><b>312W</b>=White Coilex Baffle and Trim <b>312P</b>=Black Coilex Baffle, White Trim</p>		<p><b>78 BR/PAR30 Eyeball 30° Tilt, Self-flange</b> OD: 8" [203mm]</p> <p><b>78P</b>=White Eyeball and Trim <b>78PAT</b>=White Eyeball and Trim, Air-Tite <b>78SN</b>=Satin Nickel Eyeball and Trim <b>78TBZ</b>=Tuscan Bronze Eyeball and Trim</p>
	<p><b>30SBAT Reflector, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>30SBAT</b>=Black Specular Reflector, Self-flange</p>		<p><b>353 Metal Baffle</b> OD: 7-1/4" [184mm]</p> <p><b>353SN</b>=Satin Nickel Baffle and Trim <b>353TBZ</b>=Tuscan Bronze Baffle and Trim</p>		<p><b>376 PAR30 Regressed Gimbal 30° Tilt, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>376W</b>=White Baffle and Trim <b>376P</b>=Black Baffle and White Trim</p>
	<p><b>404 Specular Reflector</b> OD: 7-1/4" [184mm]</p> <p><b>404C</b>=Clear Specular Reflector, White Trim <b>404H</b>=Haze Reflector, White Trim <b>404SN</b>=Satin Nickel Reflector and Trim <b>404TBZ</b>=Tuscan Bronze Reflector and Trim</p>		<p><b>6100 Tapered Metal Baffle with (2) Trim Rings</b> OD: 7-1/8" [181mm]</p> <p><b>6100WB</b>=White Baffle, Narrow and Wide White Trims (included) <b>6100BB</b>=Black Baffle, Narrow and Wide White Trims (included)</p>		<p><b>378 PAR30 Regressed Gimbal with Splay 25° Tilt, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>378P</b>=White Splay and Trim <b>378</b>=Clear Specular Splay and White Trim</p>
	<p><b>426 Reflector Cone</b> OD: 7-1/4" [184mm]</p> <p><b>426</b>=Clear Specular Reflector Cone, White Trim <b>426MB</b>=Black Specular Reflector Cone, White Trim <b>426H</b>=Haze Reflector Cone, White Trim <b>426SN</b>=Satin Nickel Reflector Cone and Trim <b>426TBZ</b>=Tuscan Bronze Reflector Cone and Trim</p>		<p><b>6101 Straight Metal Baffle with (2) Trim Rings</b> OD: 7-1/8" [181mm]</p> <p><b>6101WB</b>=White Baffle, Narrow and Wide White Trims (included) <b>6101BB</b>=Black Baffle, Narrow and Wide White Trims (included)</p>		<p><b>420 BR/PAR30 Regressed Eyeball 30° Tilt, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>420W</b>=White Eyeball, Baffle and Trim <b>420P</b>=White Eyeball, Black Baffle, White Trim</p>
	<p><b>429 Dayform White Cone</b> OD: 7-1/4" [184mm]</p> <p><b>429P</b>=White Reflector and Trim</p>		<p><b>6102 Tapered Metal Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6102WB</b>=White Baffle and Trim <b>6102BB</b>=Black Baffle, White Trim</p>		<p><b>478 PAR38 Adjustable Regressed Gimbal with Splay 25° Tilt, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>478P</b>=White Splay and Trim</p>
	<p><b>4041 White Reflector, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>4041P</b>=White Reflector and Trim</p>		<p><b>6103 Straight Metal Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6103WB</b>=White Baffle and Trim <b>6103BB</b>=Black Baffle, White Trim</p>		<p><b>6130 BR/PAR30 Eyeball 35° Tilt, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6130WH</b>=White Eyeball and Trim</p>
	<p><b>4261 White Reflector Cone, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>4261P</b>=White Reflector and Trim</p>		<p><b>6108 Coilex® Straight Plastic Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6108WB</b>=White Plastic Straight Coilex Baffle, White Trim <b>6108BB</b>=Black Plastic Straight Coilex Baffle, White Trim <b>6108BKBB</b>=Black Plastic Straight Coilex Baffle, Black Trim</p>		<p><b>6170 PAR38 Gimbal 25° Tilt, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6170WH</b>=White Gimbal and Trim <b>6170BK</b>=Black Gimbal and Trim <b>6170SN</b>=Satin Nickel Gimbal and Trim <b>6170TBZ</b>=Tuscan Bronze Gimbal and Trim</p>
	<p><b>6106 Straight Reflector Cone, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6106SC</b>=Specular Reflector, White Trim</p>		<p><b>6109 Coilex® Tapered Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6109WB</b>=White Tapered Coilex Baffle, White Trim <b>6109BB</b>=Black Tapered Coilex Baffle, White Trim <b>6109BKBB</b>=Black Tapered Coilex Baffle, Black Trim</p>		<p><b>6215 PAR30 Double Gimbal 35°-50° Tilt, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6215WH</b>=White Gimbal and Trim <b>6215BK</b>=Black Gimbal and Trim <b>6215SN</b>=Satin Nickel Gimbal and Trim <b>6215TBZ</b>=Tuscan Bronze Gimbal and Trim</p>
	<p><b>6107 Tapered Reflector, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6107SC</b>=Specular Reflector, White Trim</p>		<p><b>6110 Perftex Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6110WB</b>=White Perftex Baffle and Trim <b>6110BB</b>=Black Perftex Baffle, White Trim <b>6110BKBB</b>=Black Perftex Baffle and Trim</p>		<p><b>6222 Regressed PAR30 Adjustable 45° Tilt, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6222WB</b>=White Baffle and Trim <b>6222BB</b>=Black Baffle and Trim <b>6222SC</b>=Specular Clear Reflector, White Trim <b>6222H</b>=Haze Reflector, White Trim</p>
	<p><b>6120 Full Cone Reflector, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6120WH</b>=White Reflector and Trim <b>6120SN</b>=Satin Nickel Reflector and Trim <b>6120TBZ</b>=Tuscan Bronze Reflector and Trim</p>		<p><b>6125 Full Cone Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6125WB</b>=White Baffle and Trim <b>6125BB</b>=Black Baffle, White Trim <b>6125BKBB</b>=Black Baffle and Trim</p>		<p><b>Lenses &amp; Wet Location Showerlights</b></p> <p><b>170 Albalite Lens with Reflector</b> OD: 8" [203mm]</p> <p><b>170P</b>=Frosted Albalite Glass Lens, White Trim <b>170PS</b>=Frosted Albalite Glass Lens, White Plastic Trim, Showerlight, Air-Tite</p>
	<p><b>6121 Shallow Full Cone Reflector, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6121WH</b>=White Reflector and Trim</p>		<p><b>6126 Shallow Full Cone Baffle, Self-flange</b> OD: 7-3/4" [197mm]</p> <p><b>6126WB</b>=White Baffle and Trim <b>6126BB</b>=Black Baffle, White Trim</p>		<p><b>171 Drop Opal Lens with Reflector</b> OD: 8" [203mm]</p> <p><b>171P</b>=Drop Opal Glass Lens, White Trim <b>171PS</b>=Drop Opal Glass Lens, White Plastic Trim, Showerlight, Air-Tite</p>
	<p><b>Baffles</b></p> <p><b>30 Baffle, Self-flange</b> OD: 7-1/4" [184mm]</p> <p><b>30WAT</b>=White Baffle, Reflector and Trim <b>30WATH</b>=White Baffle, Clear Reflector and White Trim <b>30PAT</b>=Black Baffle, Clear Reflector and White Trim <b>30SNAT</b>=Satin Nickel Baffle, Reflector and Trim <b>30TBZAT</b>=Tuscan Bronze Baffle, Reflector and Trim</p>		<p><b>Adjustable - Eyeballs &amp; Gimbals</b></p> <p><b>74 PAR30 Eyeball 30° Tilt, Self-flange</b> OD: 8" [203mm]</p> <p><b>74P</b>=White Eyeball and Trim</p>		<p><b>172 Dome Lens with Reflector</b> OD: 7-3/4" [197mm]</p> <p><b>172PS</b>=Frosted Glass Dome, White Plastic Trim <b>172SNS</b>=Frosted Glass Dome, Satin Nickel Plastic Trim <b>172TBZS</b>=Frosted Glass Dome, Tuscan Bronze Plastic Trim</p>
	<p><b>310 Coilex® Baffle</b> OD: 7-1/4" [184mm]</p> <p><b>310W</b>=White Coilex Baffle and Trim <b>310P</b>=Black Coilex Baffle, White Trim <b>310SN</b>=Black Coilex Baffle, Satin Nickel Trim <b>310TBZ</b>=Black Coilex Baffle, Tuscan Bronze Trim</p>		<p><b>76 PAR38 Gimbal 30° Tilt, Self-flange</b> OD: 8" [203mm]</p> <p><b>76P</b>=White Gimbal and Trim</p>		

continued

\*Outdoor rated lamp only (purchase separately)

## Ordering Information

Sample Number: E7ICAT 6110WB

Order housing, trim and lamp (by others) separately for a complete luminaire.

### Housing

E7ICAT = 6" insulated ceiling, airtight recessed housing, new construction, 120V

### Trims

#### Lenses & Wet Location Showerlights



**173 Fresnel Lens with Reflector**

OD: 8" [203mm]

**173P**=Fresnel Glass Lens, White Trim

**173PS**=Fresnel Glass Lens, White Plastic Trim,  
Showerlight, Air-Tite



**6145 Open Wet Location, Shallow Reflector,**

**Self-flange - Showerlight\***

OD: 7-3/4" [197mm]

**6145WH**=White Reflector and Trim

**6145SN**=Satin Nickel Reflector and Trim

**6145TBZ**=Tuscan Bronze Reflector and Trim



**6146 Open Wet Location, Full Reflector,**

**Self-flange - Showerlight\***

OD: 7-3/4" [197mm]

**6146WH**=White Reflector and Trim

**6146SN**=Satin Nickel Reflector and Trim

**6146TBZ**=Tuscan Bronze Reflector and Trim



**6150 Frost Dome Glass Lens, Self-flange**

OD: 7-3/4" [197mm]

**6150WH**=Frost Dome Glass Lens with Reflector,  
White Plastic Trim

**6150SN**=Frost Dome Glass Lens with Reflector,  
Satin Nickel Plastic Trim

**6150TBZ**=Frost Dome Glass Lens with Reflector,  
Tuscan Bronze Plastic Trim



**6162 Drop Opal Plastic Lens, Self-flange -**

**Showerlight**

OD: 7-3/4" [197mm]

**6162WH**=Drop Opal Plastic Lens with Reflector,  
White Plastic Trim



**6230 Squirrel Frost Glass Lens,**

**Metal Trim - Showerlight**

OD: 7-1/4" [183mm]

**6230AH**=Frost Glass Lens, Aluminum Haze  
Squirrel Trim

**6230PN**=Frost Glass Lens, Polished Nickel  
Squirrel Trim

**6230SN**=Frost Glass Lens, Satin Nickel  
Squirrel Trim

**6230TBZ**=Frost Glass Lens, Tuscan Bronze  
Squirrel Trim



**6255 Soft Square, Frost Curve Glass Lens,**

**Self-flange - Showerlight**

OD: 7-1/4" [183mm]

**6255WH**=Frost Curve Glass Lens with Reflector,  
White Plastic Trim

**6255SN**=Frost Curve Glass Lens with Reflector,  
Satin Nickel Plastic Trim

**6255TBZ**=Frost Curve Glass Lens with Reflector,  
Tuscan Bronze Plastic Trim

#### Open, Splay & Wall Wash



**300 Open Trim with Fixed Socket Bracket,**

**Self-flange**

OD: 7-1/4" [183mm]

**300P**=Self-flange with White Open Trim

**300SN**=Self-flange with Satin Nickel Open Trim

**300TBZ**=Self-flange with Tuscan Bronze Open  
Trim



**327 White Splay Trim with Fixed Socket**

**Bracket, Self-flange**

OD: 7-3/4" [197mm]

**327P**=White Splay Trim with Socket Bracket



**328 White Splay Trim**

OD: 7-3/4" [197mm]

**328P**=White Splay Trim



**430 Wall Wash with Baffle & Full Reflector**

OD: 7-1/4" [183mm]

**430W**=White Baffle, with Upper Reflector,  
White Trim

**430P**=Black Baffle, with Upper Reflector,  
White Trim

\*Outdoor rated lamp only (purchase separately)

**Description**

The E71CAT is a compact and efficient recessed housing optimized and listed for EISA compliant tungsten-halogen, CFL and LED lamps as well as incandescent. Housing is suitable for residential or light commercial applications. For installation in insulated ceilings\* and non-insulated ceilings with airtight code compliant construction. Use with a variety of trims and finishes to create different lighting effects or to match any decor. May be retrofit with compatible HALO LED lighting systems.

Catalog #		Type
Project		
Comments		Date
Prepared by		

**Specification Features**

**Housing**

- Single wall die-formed aluminum housing
- Housing features a precision rolled interlocking collar which maintains aperture geometry for greater assurance of installation results
- Integral Air-Tite gasket for code-required gasket between fixture and finished ceiling - seals aperture without need for additional caulk
- May be removed from the plaster frame to provide access to junction box

**Socket Plate**

- Rigid socket plate adjusts and locks without tools for various lamp sizes.
- Socket plate and bracket may be removed when using socket supporting trims

**Plaster Frame**

- Galvanized steel frame. Housing adjusts in plaster frame to accommodate up to 3/8" - 1" ceiling thickness
- (2) Regressed locking screws for securing hanger bars
- Integral Air-Tite gasket seals housing and meets code-required gasket between fixture and finished ceiling

**Includes:**

**Bar Hangers  
All Nail!™**

- Integral precisely positioned nail for engineered and natural framing
- Mini-foot leveling flange
- Integral T-Grid Clip, no accessory clips required

**q-Channel bars with Pass-N-Thru™**

- Unique inverted "q" interlocking channel for rigidity and stability
- Pass-N-Thru™ feature allows bars to cross-over for tool-less shortening in tight spaces

**Hinged junction box w/  
Slide-N-Side™**

- (3) Slide-N-Side™ Non-Metallic (NM) wire traps, allow wiring outside the box
- For 14-2, 14-3, 12-2, 12-3 U.S. and 14-2, 14-3, 12-2 Canadian
- (4) 1/2" conduit pry-outs
- Hinged door for easy access
- Box is repositionable 90° on frame to avoid obstructions

**Quick Connect™**

- (3) Push wire nuts included, for speed & reliability
- Clear caps for wire connection visibility

**cULus Listed**

- Compact 16 in<sup>3</sup> volume
- Listed for max. (10) No. 12 AWG or (14) No. 14 AWG 90° C splice conductors in box

**Air-Tite™ code compliant**

- Certified under ASTM E283
- Exclusive gasket seals aperture, frame & ceiling
- No additional caulk required

**Socket**

- Porcelain socket with nickel plated brass screw shell
- Snap-in springs secure socket to socket plate, and may be detached when using socket supporting trims

**Thermal Protector**

- Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping

**Trims**

- Halo Fit-All concept offers multiple trim options in a variety of design styles, and functional beam distributions to control beam angle and lumen delivery in accommodating various lamp types including Halogen, CFL and LED

**Compliance**

- cULus Listed 1598 Luminaire
- cULus Listed Damp Location
- cULus Listed for Wet Location, covered ceiling, with select trims
- cULus Listed for direct contact with insulation and combustible material\*
- Air-Tite code compliant. Certified under ASTM E283; not exceeding 2.0 cfm (0.944 L/s) air leakage rate tested at a 1.57 psf (75 Pa) pressure differential
- RoHS compliant

\*Not to be used in direct contact with spray foam insulation (Consult NEMA LSD57-2013)



**E71CAT**


**6" IC, Air-Tite,  
New Construction Housing**

**E26 Screw base housing**

**FOR USE IN INSULATED  
CEILINGS**

**FOR DIRECT CONTACT  
WITH INSULATION\***

**Dimensions**

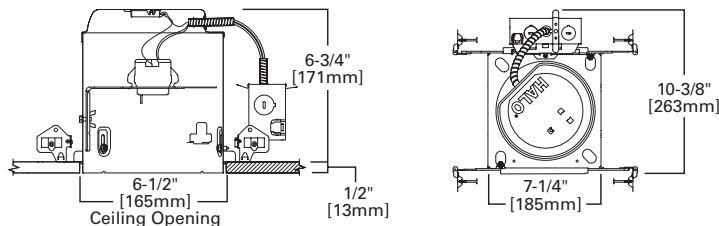

**Special Features**

- All-Nail!™ bar hangers
- q-Channel bars with Pass-N-Thru™
- Hinged J-Box with Slide-N-Side™
- Quick Connect™ push wire nuts
- Air-Tite™ code compliant



## Ordering Information







































Sample Number: E7ICAT 6110WB

Order housing, trim and lamp (by others) separately for a complete luminaire.

### Housing

E7ICAT = 6" insulated ceiling, airtight recessed housing, new construction, 120V

### Trims

	<p><b>Reflectors</b>  <b>30 Reflector, Self-flange</b>            OD: 7-1/4" [184mm]  <b>30HAT</b>=Haze Reflector, White Trim  <b>30RGAT</b>=Residential Gold Reflector, White Trim  <b>30CAT</b>=Clear Specular Reflector, White Trim</p>		<p><b>312 Coilex® Baffle</b>            OD: 7-1/4" [184mm]  <b>312W</b>=White Coilex Baffle and Trim  <b>312P</b>=Black Coilex Baffle, White Trim</p>		<p><b>78 BR/PAR30 Eyeball 30° Tilt, Self-flange</b>            OD: 8" [203mm]  <b>78P</b>=White Eyeball and Trim  <b>78PAT</b>=White Eyeball and Trim, Air-Tite  <b>78SN</b>=Satin Nickel Eyeball and Trim  <b>78TBZ</b>=Tuscan Bronze Eyeball and Trim</p>
	<p><b>30SBAT Reflector, Self-flange</b>            OD: 7-1/4" [184mm]  <b>30SBAT</b>=Black Specular Reflector, Self-flange</p>		<p><b>353 Metal Baffle</b>            OD: 7-1/4" [184mm]  <b>353SN</b>=Satin Nickel Baffle and Trim  <b>353TBZ</b>=Tuscan Bronze Baffle and Trim</p>		<p><b>376 PAR30 Regressed Gimbal 30° Tilt, Self-flange</b>            OD: 7-1/4" [184mm]  <b>376W</b>=White Baffle and Trim  <b>376P</b>=Black Baffle and White Trim</p>
	<p><b>404 Specular Reflector</b>            OD: 7-1/4" [184mm]  <b>404C</b>=Clear Specular Reflector, White Trim  <b>404H</b>=Haze Reflector, White Trim  <b>404SN</b>=Satin Nickel Reflector and Trim  <b>404TBZ</b>=Tuscan Bronze Reflector and Trim</p>		<p><b>6100 Tapered Metal Baffle with (2) Trim Rings</b>            OD: 7-1/8" [181mm]  <b>6100WB</b>=White Baffle, Narrow and Wide White Trims (included)  <b>6100BB</b>=Black Baffle, Narrow and Wide White Trims (included)</p>		<p><b>378 PAR30 Regressed Gimbal with Splay 25° Tilt, Self-flange</b>            OD: 7-1/4" [184mm]  <b>378P</b>=White Splay and Trim  <b>378C</b>=Clear Specular Splay and White Trim</p>
	<p><b>426 Reflector Cone</b>            OD: 7-1/4" [184mm]  <b>426C</b>=Clear Specular Reflector Cone, White Trim  <b>426MB</b>=Black Specular Reflector Cone, White Trim  <b>426H</b>=Haze Reflector Cone, White Trim  <b>426SN</b>=Satin Nickel Reflector Cone and Trim  <b>426TBZ</b>=Tuscan Bronze Reflector Cone and Trim</p>		<p><b>6101 Straight Metal Baffle with (2) Trim Rings</b>            OD: 7-1/8" [181mm]  <b>6101WB</b>=White Baffle, Narrow and Wide White Trims (included)  <b>6101BB</b>=Black Baffle, Narrow and Wide White Trims (included)</p>		<p><b>420 BR/PAR30 Regressed Eyeball 30° Tilt, Self-flange</b>            OD: 7-1/4" [184mm]  <b>420W</b>=White Eyeball, Baffle and Trim  <b>420P</b>=White Eyeball, Black Baffle, White Trim</p>
	<p><b>429 Dayform White Cone</b>            OD: 7-1/4" [184mm]  <b>429P</b>=White Reflector and Trim</p>		<p><b>6102 Tapered Metal Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6102WB</b>=White Baffle and Trim  <b>6102BB</b>=Black Baffle, White Trim</p>		<p><b>478 PAR38 Adjustable Regressed Gimbal with Splay 25° Tilt, Self-flange</b>            OD: 7-1/4" [184mm]  <b>478P</b>=White Splay and Trim</p>
	<p><b>4041 White Reflector, Self-flange</b>            OD: 7-1/4" [184mm]  <b>4041P</b>=White Reflector and Trim</p>		<p><b>6103 Straight Metal Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6103WB</b>=White Baffle and Trim  <b>6103BB</b>=Black Baffle, White Trim</p>		<p><b>6130 BR/PAR30 Eyeball 35° Tilt, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6130WH</b>=White Eyeball and Trim</p>
	<p><b>4261 White Reflector Cone, Self-flange</b>            OD: 7-1/4" [184mm]  <b>4261P</b>=White Reflector and Trim</p>		<p><b>6108 Coilex® Straight Plastic Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6108WB</b>=White Plastic Straight Coilex Baffle, White Trim  <b>6108BB</b>=Black Plastic Straight Coilex Baffle, White Trim  <b>6108BKBB</b>=Black Plastic Straight Coilex Baffle, Black Trim</p>		<p><b>6170 PAR38 Gimbal 25° Tilt, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6170WH</b>=White Gimbal and Trim  <b>6170BK</b>=Black Gimbal and Trim  <b>6170SN</b>=Satin Nickel Gimbal and Trim  <b>6170TBZ</b>=Tuscan Bronze Gimbal and Trim</p>
	<p><b>6106 Straight Reflector Cone, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6106SC</b>=Specular Reflector, White Trim</p>		<p><b>6109 Coilex® Tapered Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6109WB</b>=White Tapered Coilex Baffle, White Trim  <b>6109BB</b>=Black Tapered Coilex Baffle, White Trim  <b>6109BKBB</b>=Black Tapered Coilex Baffle, Black Trim</p>		<p><b>6215 PAR30 Double Gimbal 35°-50° Tilt, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6215WH</b>=White Gimbal and Trim  <b>6215BK</b>=Black Gimbal and Trim  <b>6215SN</b>=Satin Nickel Gimbal and Trim  <b>6215TBZ</b>=Tuscan Bronze Gimbal and Trim</p>
	<p><b>6107 Tapered Reflector, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6107SC</b>=Specular Reflector, White Trim</p>		<p><b>6110 Perftex Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6110WB</b>=White Perftex Baffle and Trim  <b>6110BB</b>=Black Perftex Baffle, White Trim  <b>6110BKBB</b>=Black Perftex Baffle and Trim</p>		<p><b>6222 Regressed PAR30 Adjustable 45° Tilt, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6222WB</b>=White Baffle and Trim  <b>6222BB</b>=Black Baffle and Trim  <b>6222SC</b>=Specular Clear Reflector, White Trim  <b>6222H</b>=Haze Reflector, White Trim</p>
	<p><b>6120 Full Cone Reflector, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6120WH</b>=White Reflector and Trim  <b>6120SN</b>=Satin Nickel Reflector and Trim  <b>6120TBZ</b>=Tuscan Bronze Reflector and Trim</p>		<p><b>6125 Full Cone Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6125WB</b>=White Baffle and Trim  <b>6125BB</b>=Black Baffle, White Trim  <b>6125BKBB</b>=Black Baffle and Trim</p>		<p><b>Lenses &amp; Wet Location Showerlights</b>  <b>170 Albalite Lens with Reflector</b>            OD: 8" [203mm]  <b>170P</b>=Frosted Albalite Glass Lens, White Trim  <b>170PS</b>=Frosted Albalite Glass Lens, White Plastic Trim, Showerlight, Air-Tite</p>
	<p><b>6121 Shallow Full Cone Reflector, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6121WH</b>=White Reflector and Trim</p>		<p><b>6126 Shallow Full Cone Baffle, Self-flange</b>            OD: 7-3/4" [197mm]  <b>6126WB</b>=White Baffle and Trim  <b>6126BB</b>=Black Baffle, White Trim</p>		<p><b>171 Drop Opal Lens with Reflector</b>            OD: 8" [203mm]  <b>171P</b>=Drop Opal Glass Lens, White Trim  <b>171PS</b>=Drop Opal Glass Lens, White Plastic Trim, Showerlight, Air-Tite</p>
	<p><b>Baffles</b>  <b>30 Baffle, Self-flange</b>            OD: 7-1/4" [184mm]  <b>30WAT</b>=White Baffle, Reflector and Trim  <b>30WATH</b>=White Baffle, Clear Reflector and White Trim  <b>30PAT</b>=Black Baffle, Clear Reflector and White Trim  <b>30SNAT</b>=Satin Nickel Baffle, Reflector and Trim  <b>30TBZAT</b>=Tuscan Bronze Baffle, Reflector and Trim</p>		<p><b>Adjustable - Eyeballs &amp; Gimbals</b>  <b>74 PAR30 Eyeball 30° Tilt, Self-flange</b>            OD: 8" [203mm]  <b>74P</b>=White Eyeball and Trim</p>		<p><b>172 Dome Lens with Reflector</b>            OD: 7-3/4" [197mm]  <b>172PS</b>=Frosted Glass Dome, White Plastic Trim  <b>172SNS</b>=Frosted Glass Dome, Satin Nickel Plastic Trim  <b>172TBZS</b>=Frosted Glass Dome, Tuscan Bronze Plastic Trim</p>
	<p><b>310 Coilex® Baffle</b>            OD: 7-1/4" [184mm]  <b>310W</b>=White Coilex Baffle and Trim  <b>310P</b>=Black Coilex Baffle, White Trim  <b>310SN</b>=Black Coilex Baffle, Satin Nickel Trim  <b>310TBZ</b>=Black Coilex Baffle, Tuscan Bronze Trim</p>		<p><b>76 PAR38 Gimbal 30° Tilt, Self-flange</b>            OD: 8" [203mm]  <b>76P</b>=White Gimbal and Trim</p>		

continued

\*Outdoor rated lamp only (purchase separately)

## Ordering Information

Sample Number: E7ICAT 6110WB

Order housing, trim and lamp (by others) separately for a complete luminaire.

### Housing

E7ICAT = 6" insulated ceiling, airtight recessed housing, new construction, 120V

### Trims

#### Lenses & Wet Location Showerlights



**173 Fresnel Lens with Reflector**

OD: 8" [203mm]

**173P**=Fresnel Glass Lens, White Trim

**173PS**=Fresnel Glass Lens, White Plastic Trim,  
Showerlight, Air-Tite



**6145 Open Wet Location, Shallow Reflector,**

**Self-flange - Showerlight\***

OD: 7-3/4" [197mm]

**6145WH**=White Reflector and Trim

**6145SN**=Satin Nickel Reflector and Trim

**6145TBZ**=Tuscan Bronze Reflector and Trim



**6146 Open Wet Location, Full Reflector,**

**Self-flange - Showerlight\***

OD: 7-3/4" [197mm]

**6146WH**=White Reflector and Trim

**6146SN**=Satin Nickel Reflector and Trim

**6146TBZ**=Tuscan Bronze Reflector and Trim



**6150 Frost Dome Glass Lens, Self-flange**

OD: 7-3/4" [197mm]

**6150WH**=Frost Dome Glass Lens with Reflector,  
White Plastic Trim

**6150SN**=Frost Dome Glass Lens with Reflector,  
Satin Nickel Plastic Trim

**6150TBZ**=Frost Dome Glass Lens with Reflector,  
Tuscan Bronze Plastic Trim



**6162 Drop Opal Plastic Lens, Self-flange -**

**Showerlight**

OD: 7-3/4" [197mm]

**6162WH**=Drop Opal Plastic Lens with Reflector,  
White Plastic Trim



**6230 Squirrel Frost Glass Lens,**

**Metal Trim - Showerlight**

OD: 7-1/4" [183mm]

**6230AH**=Frost Glass Lens, Aluminum Haze  
Squirrel Trim

**6230PN**=Frost Glass Lens, Polished Nickel  
Squirrel Trim

**6230SN**=Frost Glass Lens, Satin Nickel  
Squirrel Trim

**6230TBZ**=Frost Glass Lens, Tuscan Bronze  
Squirrel Trim



**6255 Soft Square, Frost Curve Glass Lens,**

**Self-flange - Showerlight**

OD: 7-1/4" [183mm]

**6255WH**=Frost Curve Glass Lens with Reflector,  
White Plastic Trim

**6255SN**=Frost Curve Glass Lens with Reflector,  
Satin Nickel Plastic Trim

**6255TBZ**=Frost Curve Glass Lens with Reflector,  
Tuscan Bronze Plastic Trim

#### Open, Splay & Wall Wash



**300 Open Trim with Fixed Socket Bracket,**

**Self-flange**

OD: 7-1/4" [183mm]

**300P**=Self-flange with White Open Trim

**300SN**=Self-flange with Satin Nickel Open Trim

**300TBZ**=Self-flange with Tuscan Bronze Open  
Trim



**327 White Splay Trim with Fixed Socket**

**Bracket, Self-flange**

OD: 7-3/4" [197mm]

**327P**=White Splay Trim with Socket Bracket



**328 White Splay Trim**

OD: 7-3/4" [197mm]

**328P**=White Splay Trim



**430 Wall Wash with Baffle & Full Reflector**

OD: 7-1/4" [183mm]

**430W**=White Baffle, with Upper Reflector,  
White Trim

**430P**=Black Baffle, with Upper Reflector,  
White Trim

\*Outdoor rated lamp only (purchase separately)