

Specifications

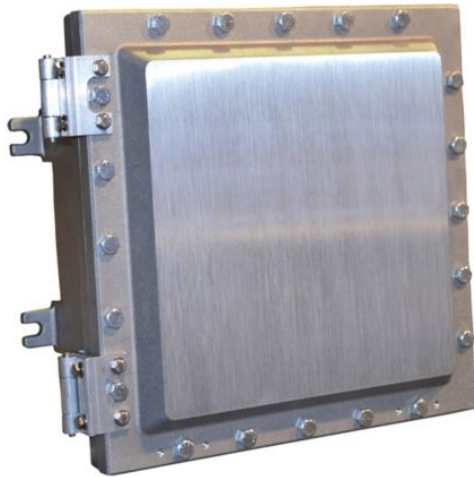


Photo is representative

Eaton ECP242408

Eaton Crouse-Hinds series ECP enclosure, Square cover, 9-7/16" depth, 24" x 24" x 8", Copper-free aluminum, Tap-in mounting feet

General specifications

PRODUCT NAME	Eaton Crouse-Hinds series ECP enclosure
CATALOG NUMBER	ECP242408
UPC	662276321984
PRODUCT LENGTH/DEPTH	29.33 in
PRODUCT HEIGHT	29.33 in
PRODUCT WIDTH	12.53 in
PRODUCT WEIGHT	279 lb



Powering Business Worldwide

Certifications and compliances

AREA CLASSIFICATION	Hazardous/Classified Locations
---------------------	--------------------------------

STANDARDS TYPE	NEC/CEC
----------------	---------

NEC HAZARDOUS RATING	Class I, Division 1 Class I, Division 2 Class II, Division 1 Class II, Division 2 Class III
----------------------	---

NEMA RATING	3 3R 4 7 9
-------------	------------------------

Product specifications

ENCLOSURE SIZE	24" x 24" x 8"
----------------	----------------

COVER TYPE	Square
------------	--------

DEPTH	9-7/16 in
-------	-----------

MATERIAL	Copper-free aluminum
----------	----------------------

SPECIAL FEATURES	Tap-in mounting feet
------------------	----------------------

Resources

3D CAD DRAWING PACKAGE	Eaton Crouse-Hinds ECP242408 3D drawing
------------------------	---

BROCHURES	Crouse-Hinds series ECP Enclosures Brochure
-----------	---

CATALOGS	Crouse-Hinds series ECP catalog page
----------	--

CERTIFICATION REPORTS	IECEX Certificate of Conformity ECP Explosionproof Enclosures UL certification Intertek EC-Type Examination Certificate
-----------------------	---

INSTALLATION INSTRUCTIONS	IF 1107 - Mounting Plate Kit IF 1639 - ECP Explosionproof Enclosures
---------------------------	---

SPECIFICATIONS AND DATASHEETS	ECP Enclosures Eaton Specification Sheet - ECP242408
-------------------------------	---

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights Reserved.

Follow us on social media to get the latest product and support information.



Specifications

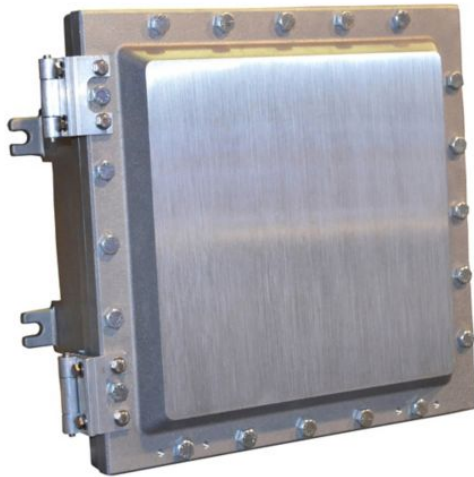


Photo is representative

Eaton ECP242408

Eaton Crouse-Hinds series ECP enclosure, Square cover, 9-7/16" depth, 24" x 24" x 8", Copper-free aluminum, Tap-in mounting feet

General specifications

PRODUCT NAME	Eaton Crouse-Hinds series ECP enclosure
CATALOG NUMBER	ECP242408
UPC	662276321984
PRODUCT LENGTH/DEPTH	29.33 in
PRODUCT HEIGHT	29.33 in
PRODUCT WIDTH	12.53 in
PRODUCT WEIGHT	279 lb



Powering Business Worldwide

Certifications and compliances

AREA CLASSIFICATION	Hazardous/Classified Locations
STANDARDS TYPE	NEC/CEC
NEC HAZARDOUS RATING	Class I, Division 1 Class I, Division 2 Class II, Division 1 Class II, Division 2 Class III
NEMA RATING	3 3R 4 7 9

Resources

3D CAD DRAWING PACKAGE	Eaton Crouse-Hinds ECP242408 3D drawing
BROCHURES	Crouse-Hinds series ECP Enclosures Brochure
CATALOGS	Crouse-Hinds series ECP catalog page
CERTIFICATION REPORTS	IECEX Certificate of Conformity ECP Explosionproof Enclosures UL certification Intertek EC-Type Examination Certificate
INSTALLATION INSTRUCTIONS	IF 1107 - Mounting Plate Kit IF 1639 - ECP Explosionproof Enclosures
SPECIFICATIONS AND DATASHEETS	ECP Enclosures Eaton Specification Sheet - ECP242408

Product specifications

ENCLOSURE SIZE	24" x 24" x 8"
COVER TYPE	Square
DEPTH	9-7/16 in
MATERIAL	Copper-free aluminum
SPECIAL FEATURES	Tap-in mounting feet

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

Follow us on social media to get the latest product and support information.



© 2025 Eaton. All Rights Reserved.