

Non-Metallic Insulating Bushings for EMT

NEW!
more on
reverse

Cable Protection at its Best



Easy installation on EMT!



EMT400S
4" Split Insulating Bushing
*Cable tie included

Arlington's non-metallic Insulating Bushings protect cable from abrasion when using EMT, Rigid, IMC or PVC rigid conduit – holding firmly in place as cable is pulled through.

When used for cable protection only these insulating bushings are a perfect substitution for costly fittings. Uses include power, computer data lines, cable TV, audio/video cables, phone, or alarm/security systems.

Try our new, convenient SPLIT bushings. They're perfect for easy installation on EMT, and other conduit when cables are already in place.

SPLIT bushings are available in 2", 2-1/2", 3", 3-1/2" and 4" trade sizes. Look for the 'S' suffix in the chart on reverse.

Arlington Insulating Bushings...

- Listed for use in environmental air handling spaces per 2014 NEC requirements 300-22(c)
- Meet 2014 NEC requirements for 300-15(c) protection
- UL/CSA Listed



Scan for info



Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517


800/233.4717

Fax 570/562.0646

www.aifittings.com

Insulating Bushings for EMT, Rigid, IMC, PVC

Listed for Environmental Air Handling Spaces

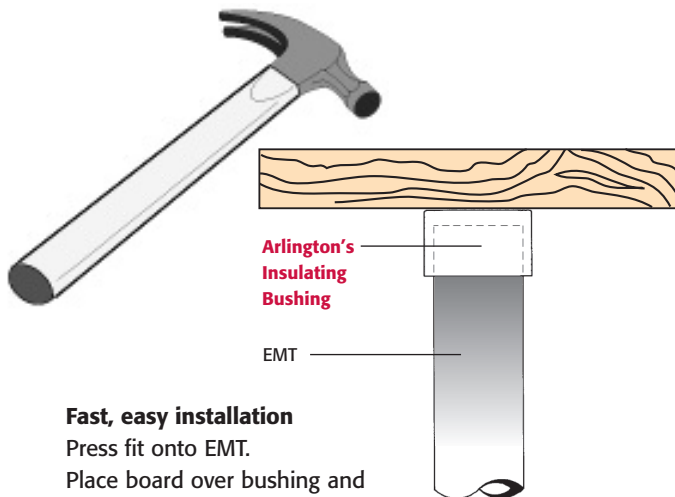


Fast, easy installation

Press fit onto EMT.

Place board over bushing and tap onto conduit for extra-firm hold.

Arlington's Insulating Bushings meet 2014 NEC requirements for 300-15(c) protection

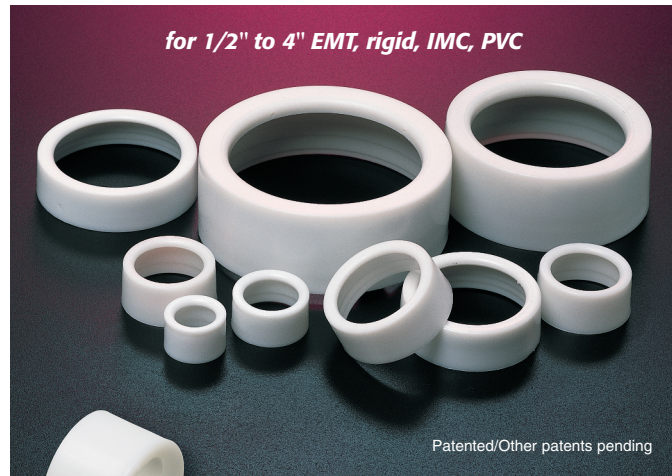

EMT50

1/2" Insulating Bushing for EMT

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	Trade Size	DESCRIPTION Insulating Bushings	UNIT PKG	STD PKG
EMT50	12200	1/2"	Press-fit Non-metallic Insulating Bushings for use with EMT	100	1000
EMT75	12205	3/4"		100	1000
EMT100	12220	1"		100	100
EMT125	12225	1-1/4"		100	100
EMT150	12230	1-1/2"		100	100
EMT200	12235	2"	Insulating Bushing w Split	50	50
EMT200S	15301	2"		50	50

These larger EMT Bushings can also be used with rigid, IMC, PVC conduit

EMT250	12240	2-1/2"	Insulating Bushing w Split	25	25
EMT300	12245	3"		25	25
EMT350	12250	3-1/2"		25	25
EMT400	12255	4"		25	25
EMT250S	12270	2-1/2"	Insulating Bushing w Split	25	25
EMT300S	12271	3"		25	25
EMT350S	12272	3-1/2"		25	25
EMT400S	22001	4"		25	25

SPLIT Insulating Bushings include cable tie



Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517

800/233.4717

Fax 570/562.0646

www.aifittings.com



Split Insulating Bushings

Scan for info



Distributed by

Patent pending
EMT400S/15M 0813 REV0314

Non-Metallic Insulating Bushings for EMT

NEW!
more on
reverse

Cable Protection at its Best



Easy installation on EMT!



EMT400S
4" Split Insulating Bushing
*Cable tie included

Arlington's non-metallic Insulating Bushings protect cable from abrasion when using EMT, Rigid, IMC or PVC rigid conduit – holding firmly in place as cable is pulled through.

When used for cable protection only these insulating bushings are a perfect substitution for costly fittings. Uses include power, computer data lines, cable TV, audio/video cables, phone, or alarm/security systems.

Try our new, convenient SPLIT bushings. They're perfect for easy installation on EMT, and other conduit when cables are already in place.

SPLIT bushings are available in 2", 2-1/2", 3", 3-1/2" and 4" trade sizes. Look for the 'S' suffix in the chart on reverse.

Arlington Insulating Bushings...

- Listed for use in environmental air handling spaces per 2014 NEC requirements 300-22(c)
- Meet 2014 NEC requirements for 300-15(c) protection
- UL/CSA Listed



Scan for info




Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com

Insulating Bushings for EMT, Rigid, IMC, PVC

Listed for Environmental Air Handling Spaces

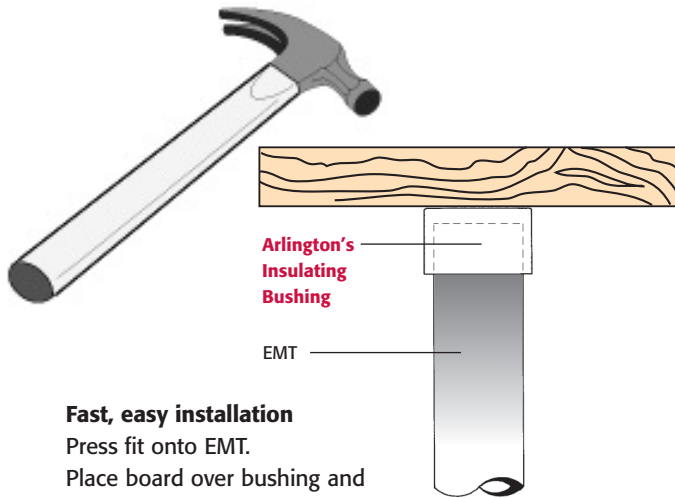


Fast, easy installation

Press fit onto EMT.

Place board over bushing and tap onto conduit for extra-firm hold.

Arlington's Insulating Bushings meet 2014 NEC requirements for 300-15(c) protection

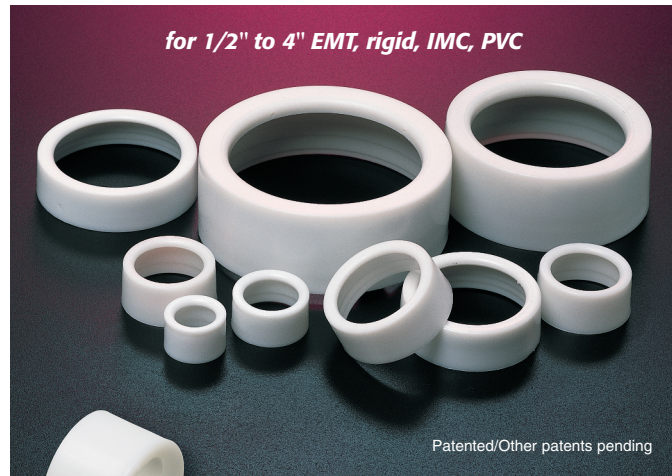

EMT50

1/2" Insulating Bushing for EMT

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	Trade Size	DESCRIPTION Insulating Bushings	UNIT PKG	STD PKG
EMT50	12200	1/2"	Press-fit Non-metallic Insulating Bushings for use with EMT	100	1000
EMT75	12205	3/4"		100	1000
EMT100	12220	1"		100	100
EMT125	12225	1-1/4"		100	100
EMT150	12230	1-1/2"		100	100
EMT200	12235	2"	Insulating Bushing w Split	50	50
EMT200S	15301	2"		50	50

These larger EMT Bushings can also be used with rigid, IMC, PVC conduit

EMT250	12240	2-1/2"	Insulating Bushing w Split	25	25
EMT300	12245	3"		25	25
EMT350	12250	3-1/2"		25	25
EMT400	12255	4"		25	25
EMT250S	12270	2-1/2"	Insulating Bushing w Split	25	25
EMT300S	12271	3"		25	25
EMT350S	12272	3-1/2"		25	25
EMT400S	22001	4"		25	25

SPLIT Insulating Bushings include cable tie



Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517

800/233.4717

Fax 570/562.0646

www.aifittings.com



Split Insulating Bushings

Scan for info



Distributed by

Patent pending
EMT400S/15M 0813 REV0314