




GE
Lighting

13764 - F84T12/CW 15PK

GE Cool White T12

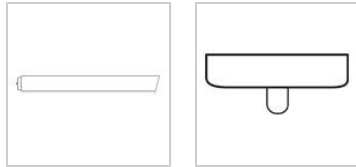

CAUTIONS & WARNINGS

Caution


- Lamp may shatter and cause injury if broken
 - Wear safety glasses and gloves when handling lamp.
 - Do not use excessive force when installing lamp.

Warning


- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.

GRAPHS & CHARTS

Graphs_Spectral Power Distribution

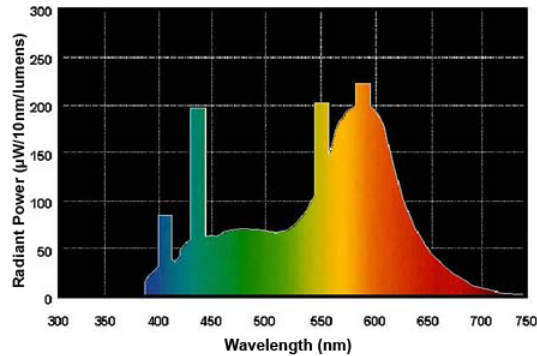

Graphs_Lumen Maintenance

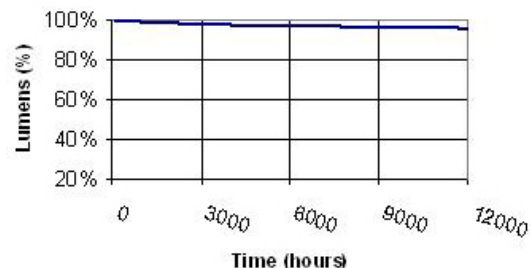

Graphs_Lamp Mortality

GENERAL CHARACTERISTICS

| | |
|----------------------------|-------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| Bulb | T12 |
| Base | Single Pin (Fa8) |
| Rated Life (NOM) | 12000.0 h |
| Bulb Material | Soda lime |
| Mercury Content (NOM) | 90.0 mg |
| Picograms of Mercury (NOM) | 1536.9 pg |
| Primary Application | Full Wattage |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 5300.0 |
| Mean Lumens (NOM) | 4880.0 |
| Nominal Initial Lumens per Watt (NOM) | 81.53846 |
| Color Temperature (NOM) | 4100.0 K |
| Color Rendering Index (CRI) (NOM) | 60.0 |

ELECTRICAL CHARACTERISTICS


| | |
|---|------|
| Wattage (NOM) | 65.0 |
| Cathode Resistance Ratio - Rh/ Rc (MIN) | 4.25 |
| Current Crest Factor (MAX) | 1.7 |

DIMENSIONS

| | |
|------------------------------------|----------------------|
| Maximum Overall Length (MOL) (NOM) | 84.000 in(2133.6 mm) |
| Nominal Length (NOM) | 84.000 in(2133.6 mm) |
| Bulb Diameter (DIA) (NOM) | 1.500 in(38.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 13764 |
| Description | F84T12/CW 15PK |
| Standard Package | Case |
| Standard Package GTIN | 10043168137642 |
| Standard Package Quantity | 15 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 15 |
| UPC | 043168137645 |

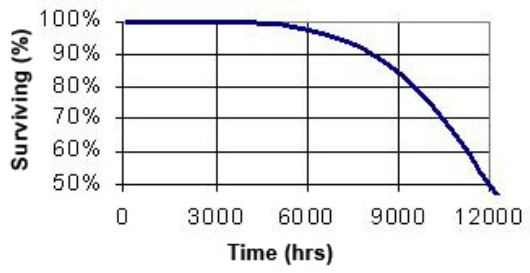




GE
Lighting

13764 - F84T12/CW 15PK

GE Cool White T12

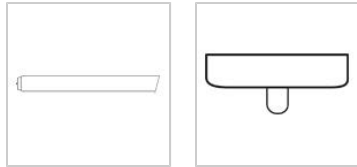

CAUTIONS & WARNINGS

Caution


- Lamp may shatter and cause injury if broken
 - Wear safety glasses and gloves when handling lamp.
 - Do not use excessive force when installing lamp.

Warning


- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.

GRAPHS & CHARTS

Graphs_Spectral Power Distribution

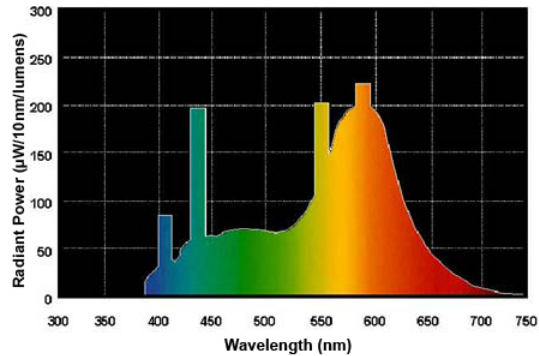

Graphs_Lumen Maintenance

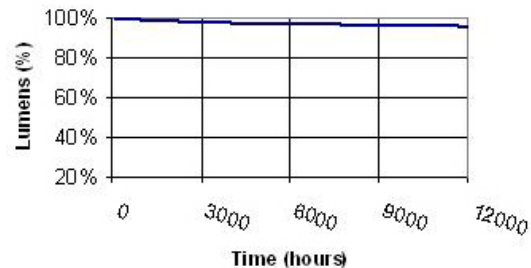

Graphs_Lamp Mortality

GENERAL CHARACTERISTICS

| | |
|----------------------------|-------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T12 |
| Base | Single Pin (Fa8) |
| Rated Life (NOM) | 12000.0 h |
| Bulb Material | Soda lime |
| Mercury Content (NOM) | 90.0 mg |
| Picograms of Mercury (NOM) | 1536.9 pg |
| Primary Application | Full Wattage |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 5300.0 |
| Mean Lumens (NOM) | 4880.0 |
| Nominal Initial Lumens per Watt (NOM) | 81.53846 |
| Color Temperature (NOM) | 4100.0 K |
| Color Rendering Index (CRI) (NOM) | 60.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---|------|
| Wattage (NOM) | 65.0 |
| Cathode Resistance Ratio - Rh/ Rc (MIN) | 4.25 |
| Current Crest Factor (MAX) | 1.7 |

DIMENSIONS

| | |
|------------------------------------|----------------------|
| Maximum Overall Length (MOL) (NOM) | 84.000 in(2133.6 mm) |
| Nominal Length (NOM) | 84.000 in(2133.6 mm) |
| Bulb Diameter (DIA) (NOM) | 1.500 in(38.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 13764 |
| Description | F84T12/CW 15PK |
| Standard Package | Case |
| Standard Package GTIN | 10043168137642 |
| Standard Package Quantity | 15 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 15 |
| UPC | 043168137645 |

