




GE
Lighting

66858 - F96T12XL/HL41/WM

F96T12XL/HL41/WM-CIRCLEVILLE C AND I SKUS IN PULP

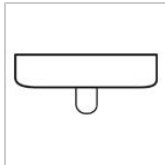

GENERAL CHARACTERISTICS

| | |
|----------------------------|-------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T12 |
| Base | Single Pin (Fa8) |
| Rated Life (NOM) | 12000.0 h |
| Bulb Material | Sodalime glass |
| Starting Temperature (MIN) | 15.0 °C |
| Mercury Content (NOM) | 15.0 mg |
| Picograms of Mercury (NOM) | 228.1022 pg |
| Primary Application | Energy Saving |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 5900.0 |
| Mean Lumens (NOM) | 5480.0 |
| Nominal Initial Lumens per Watt (NOM) | 98.33334 |
| Color Temperature (NOM) | 4100.0 K |
| Color Rendering Index (CRI) (NOM) | 80.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------------|------|
| Wattage (NOM) | 60.0 |
|---------------|------|

DIMENSIONS

| | |
|------------------------------------|----------------------|
| Maximum Overall Length (MOL) (NOM) | 96.000 in(2438.4 mm) |
| Nominal Length (NOM) | 96.000 in(2438.4 mm) |
| Bulb Diameter (DIA) (NOM) | 1.500 in(38.1 mm) |

PRODUCT INFORMATION


| | |
|----------------------------------|------------------|
| Product Code | 66858 |
| Description | F96T12XL/HL41/WM |
| Standard Package | Case |
| Standard Package GTIN | 10043168668580 |
| Standard Package Quantity | 15 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 15 |
| UPC | 043168668583 |



GE
Lighting

66858 - F96T12XL/HL41/WM

F96T12XL/HL41/WM-CIRCLEVILLE C AND I SKUS IN PULP

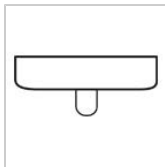

GENERAL CHARACTERISTICS

| | |
|----------------------------|-------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T12 |
| Base | Single Pin (Fa8) |
| Rated Life (NOM) | 12000.0 h |
| Bulb Material | Sodalime glass |
| Starting Temperature (MIN) | 15.0 °C |
| Mercury Content (NOM) | 15.0 mg |
| Picograms of Mercury (NOM) | 228.1022 pg |
| Primary Application | Energy Saving |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 5900.0 |
| Mean Lumens (NOM) | 5480.0 |
| Nominal Initial Lumens per Watt (NOM) | 98.33334 |
| Color Temperature (NOM) | 4100.0 K |
| Color Rendering Index (CRI) (NOM) | 80.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------------|------|
| Wattage (NOM) | 60.0 |
|---------------|------|

DIMENSIONS

| | |
|------------------------------------|----------------------|
| Maximum Overall Length (MOL) (NOM) | 96.000 in(2438.4 mm) |
| Nominal Length (NOM) | 96.000 in(2438.4 mm) |
| Bulb Diameter (DIA) (NOM) | 1.500 in(38.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|------------------|
| Product Code | 66858 |
| Description | F96T12XL/HL41/WM |
| Standard Package | Case |
| Standard Package GTIN | 10043168668580 |
| Standard Package Quantity | 15 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 15 |
| UPC | 043168668583 |