

# DROPIN™ Floor Box Kits

more on  
reverse

*FIVE MINUTE installation with SINGLE Hole Saw • Low Profile Covers*



## Fastest box installation!



1 Determine box location, avoiding structural framing members. Using a hole saw, cut 4-1/4" diameter opening through floor and subfloor.



2 Insert mounting bracket. Use indicator marks to align bracket for proper receptacle orientation. Tighten (3) wing screws to secure bracket to floor.



3 Pull cable. Install in box with supplied cable connector. Attach box to bracket with (3) #8 x 1/2" sheet metal screws (supplied) through the U-shaped cutouts in the box flange.



4 Wire receptacle. Install in box. Attach supplied gasket support plate to receptacle with #6 x 1/2" screw.

## Non-metallic Blank Covers



**Cover Installation**  
Install gasket. Attach metal or non-metallic blank cover to box with (3) #8 x 1/2" flathead machine screws. If using the in-use non-metallic cover, substitute colored in-use plate for the black gasket support plate.



Arlington's LISTED DROPIN™ Floor Box Kits are the fastest way to install a BOX nearly flush in an EXISTING floor.

**Designed for flush, neat installations and TIME-SAVINGS these floor boxes install with a SINGLE hole saw and sit just 1/8" off the floor!**

DROPIN box accommodates most 3.5" standard covers, but Arlington's round low profile covers seat flush into the non-metallic ring, reducing trip hazards.

- BRASS OR NICKEL-PLATED BRASS Metal Covers have two gasketed flip lids that keep water out and protect the box.



DROPIN kits are also available with NON-METALLIC Blank Covers. They're perfect for covering unused receptacles. To use the receptacle simply remove the blank cover.

- Five decorator colors: dark brown, light almond, gray, caramel, black – each with a matching non-metallic mounting bracket, gasket and carpet ring.



**Arlington®**

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717 • Fax 570/562.0646  
www.aifittings.com



# DROPIN™ Floor Box Kits



*Metal or Non-metallic Covers • FASTEST Installation in Existing Floor*



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION FINISH, COVER STYLE	UNIT PKG	STD PKG
<b>FLB4360MB</b>	00760	Round non-metallic box, Brass cover w flip lids	1	1
<b>FLB4360NL</b>	00761	Round non-metallic box, Nickel-plated Brass cover w flip lids	1	1

## DROPIN™ BOX KITS with METAL COVERS

<b>FLB4360MB</b>	00760	Round non-metallic box, Brass cover w flip lids	1	1
<b>FLB4360NL</b>	00761	Round non-metallic box, Nickel-plated Brass cover w flip lids	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

FLB4360MB and FLB4360NL DROPIN BOX Kits include non-metallic box, round 4" diameter metal cover with two flip lids, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	COLOR STYLE / COLOR	UNIT PKG	STD PKG
<b>FLB4360BR</b>	00763	Round non-metallic box	Blank, Dark Brown	1	1
<b>FLB4360LA</b>	00766	Round non-metallic box	Blank, Light Almond	1	1
<b>FLB4360GY</b>	00765	Round non-metallic box	Blank, Gray	1	1
<b>FLB4360CA</b>	00764	Round non-metallic box	Blank, Caramel	1	1
<b>FLB4360BL</b>	00762	Round non-metallic box	Blank, Black	1	1

## DROPIN™ BOX KITS with NON-METALLIC BLANK COVERS



<b>FLB4360BR</b>	00763	Round non-metallic box	Blank, Dark Brown	1	1
<b>FLB4360LA</b>	00766	Round non-metallic box	Blank, Light Almond	1	1
<b>FLB4360GY</b>	00765	Round non-metallic box	Blank, Gray	1	1
<b>FLB4360CA</b>	00764	Round non-metallic box	Blank, Caramel	1	1
<b>FLB4360BL</b>	00762	Round non-metallic box	Blank, Black	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

DROPIN BOX Kits with BLANK NON-METALLIC COVERS include non-metallic box, round 4" diameter non-metallic cover blank, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



COVERS, CARPET RINGS, GASKETS  
IN 5 COLORS

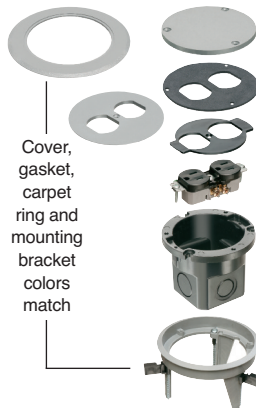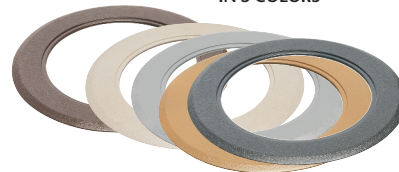

Cover, gasket, carpet ring and mounting bracket colors match



Distributed by



**Arlington®**

1 Stauffer Industrial Park  
Scranton, PA 18517

800/233.4717 • Fax 570/562.0646

www.aifittings.com

Patented FLB4360 0716 REV0916/15M UD\_0622



# DROPIN™ Floor Box Kits

more on  
reverse

*FIVE MINUTE installation with SINGLE Hole Saw • Low Profile Covers*



## Fastest box installation!



1 Determine box location, avoiding structural framing members. Using a hole saw, cut 4-1/4" diameter opening through floor and subfloor.



2 Insert mounting bracket. Use indicator marks to align bracket for proper receptacle orientation. Tighten (3) wing screws to secure bracket to floor.



3 Pull cable. Install in box with supplied cable connector. Attach box to bracket with (3) #8 x 1/2" sheet metal screws (supplied) through the U-shaped cutouts in the box flange.



4 Wire receptacle. Install in box. Attach supplied gasket support plate to receptacle with #6 x 1/2" screw.

## Non-metallic Blank Covers



**Cover Installation**  
Install gasket. Attach metal or non-metallic blank cover to box with (3) #8 x 1/2" flathead machine screws. If using the in-use non-metallic cover, substitute colored in-use plate for the black gasket support plate.



Arlington's LISTED DROPIN™ Floor Box Kits are the fastest way to install a BOX nearly flush in an EXISTING floor.

**Designed for flush, neat installations and TIME-SAVINGS** these floor boxes **install with a SINGLE hole saw and sit just 1/8" off the floor!**

DROPIN box accommodates most 3.5" standard covers, but Arlington's round **low profile** covers seat flush into the non-metallic ring, reducing trip hazards.

- BRASS OR NICKEL-PLATED BRASS **Metal Covers** have *two gasketed flip lids* that keep water out and protect the box.



DROPIN kits are also available with **NON-METALLIC Blank Covers**. They're perfect for covering unused receptacles. To use the receptacle simply remove the blank cover.

- Five decorator colors: dark brown, light almond, gray, caramel, black – each with a matching non-metallic mounting bracket, gasket and carpet ring.



**Arlington®**

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717 • Fax 570/562.0646  
www.aifittings.com



# DROPIN™ Floor Box Kits



*Metal or Non-metallic Covers • FASTEST Installation in Existing Floor*



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION FINISH, COVER STYLE	UNIT PKG	STD PKG
<b>FLB4360MB</b>	00760	Round non-metallic box, Brass cover w flip lids	1	1
<b>FLB4360NL</b>	00761	Round non-metallic box, Nickel-plated Brass cover w flip lids	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

 
**FLB4360MB and FLB4360NL DROPIN BOX Kits** include non-metallic box, round 4" diameter **metal cover** with two flip lids, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.




CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	COLOR STYLE / COLOR	UNIT PKG	STD PKG
<b>FLB4360BR</b>	00763	Round non-metallic box	Blank, Dark Brown	1	1
<b>FLB4360LA</b>	00766	Round non-metallic box	Blank, Light Almond	1	1
<b>FLB4360GY</b>	00765	Round non-metallic box	Blank, Gray	1	1
<b>FLB4360CA</b>	00764	Round non-metallic box	Blank, Caramel	1	1
<b>FLB4360BL</b>	00762	Round non-metallic box	Blank, Black	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

**DROPIN BOX Kits with BLANK NON-METALLIC COVERS** include non-metallic box, round 4" diameter **non-metallic cover blank**, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



COVERS, CARPET RINGS, GASKETS  
IN 5 COLORS

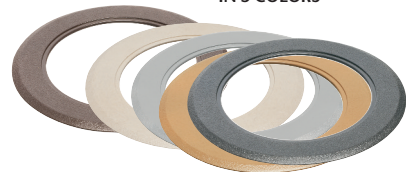

Cover, gasket, carpet ring and mounting bracket colors match



Distributed by



**Arlington®**

1 Stauffer Industrial Park  
Scranton, PA 18517

800/233.4717 • Fax 570/562.0646

www.aifittings.com

Patented FLB4360 0716 REV0916/15M UD\_0622