
 


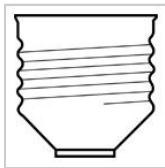

GE  
Lighting

### 80889 - FLE23HT3/2/XL827

GE Soft White Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant



#### GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	90.0 W
Rated Life	12000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	182 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1600.0
Mean Lumens	1280.0
Nominal Initial Lumens per Watt	69
Color Temperature	2700.0 K
Color Rendering Index (CRI)	82.0

#### ELECTRICAL CHARACTERISTICS

Wattage	23.0
Input Voltage	120.0 V

#### DIMENSIONS

Maximum Overall Length (MOL)	5.1000 in(129.5 mm)
Nominal Length	5.100 in(129.5 mm)

#### PRODUCT INFORMATION

Product Code	80889
Description	FLE23HT3/2/XL827
Standard Package	Case
Standard Package GTIN	10043168808894
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168808897

#### CAUTIONS & WARNINGS

##### Caution

- Lamp may shatter and cause injury if broken
  - Remove and install by grasping only plastic portion of the lamp.

##### Warning


 
- Risk of Electric Shock
  - Do not open - no user serviceable parts inside.
  - Do not use where directly exposed to water.



GE  
Lighting

**80889 - FLE23HT3/2/XL827**

GE Soft White Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

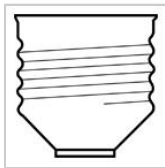

**GENERAL CHARACTERISTICS**

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	90.0 W
Rated Life	12000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	182 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	1600.0
Mean Lumens	1280.0
Nominal Initial Lumens per Watt	69
Color Temperature	2700.0 K
Color Rendering Index (CRI)	82.0

**ELECTRICAL CHARACTERISTICS**

Wattage	23.0
Input Voltage	120.0 V

**DIMENSIONS**

Maximum Overall Length (MOL)	5.1000 in(129.5 mm)
Nominal Length	5.100 in(129.5 mm)

**PRODUCT INFORMATION**

Product Code	80889
Description	FLE23HT3/2/XL827
Standard Package	Case
Standard Package GTIN	10043168808894
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168808897

**CAUTIONS & WARNINGS**

**Caution**

- Lamp may shatter and cause injury if broken
  - Remove and install by grasping only plastic portion of the lamp.

**Warning**

- Risk of Electric Shock
  - Do not open - no user serviceable parts inside.
  - Do not use where directly exposed to water.