



**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GAR1726  
 7818102342044  
 4-2/0CU 1 1/2IPS  
 Active

**Web Use**  
 BURNDY Product Line

Width (in)  
 Length (in)  
 Height (in)  
 Size (Hex) or Size (Bolt)  
 Size (Hex) or Size (Bolt) - in  
 B Length (in)  
 Width (Fraction)  
 Height (Fraction) (in)

**Dimensional**  
 3.25  
 1.56  
 4.00  
 3/8  
 0.38  
 2.31  
 3-1/4  
 4

**Product Description**

**General**

Mechanical Grounding Connector,  
 Cable to Rod or Pipe, 4 AWG  
 (Sol)-2/0 AWG (Str), 1-1/2" Pipe,  
 1-5/8" -1-7/8" Rod, Bright Dipped

**Other**

268

**Approvals / Certifications**

Type of U Bolt

UL Listed  
 CSA Certified  
 ROHS Compatible  
 UL Recognized  
 CULUS  
 Industry Standards  
 Rated for Direct Burial

Y  
 Y  
 Exempt  
 N  
 N  
 UL467  
 Y

**Conductor(s)**

Copper Tube Size (SCH40) - Range  
 Rod Size (Range)  
 Copper Solid Size (Range)  
 Copper Stranded (Range)  
 Rebar Size (Range)

1 1/2 IPS IPS  
 1 5/8 in-1 7/8 in  
 4 AWG-3/0 AWG  
 5 AWG-2/0 AWG  
 N/A

**Physical**

Type of Hardware  
 Installation Torque  
 Type of Plating  
 Plated (Yes or No)  
 Product Material

DURIUM® Silicon Bronze  
 240  
 Bright Dipped  
 N  
 Copper Alloy

**Documentation**

For further technical assistance, please contact us


**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

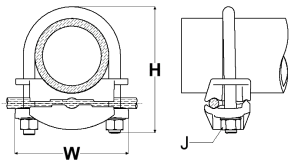

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GAR1726  
 7818102342044  
 4-2/0CU 1 1/2IPS  
 Active

**Web Use**  
 BURNDY Product Line

Width (in)  
 Length (in)  
 Height (in)  
 Size (Hex) or Size (Bolt)  
 Size (Hex) or Size (Bolt) - in  
 B Length (in)  
 Width (Fraction)  
 Height (Fraction) (in)

**Dimensional**  
 3.25  
 1.56  
 4.00  
 3/8  
 0.38  
 2.31  
 3-1/4  
 4

**Product Description**

**General**

Mechanical Grounding Connector,  
 Cable to Rod or Pipe, 4 AWG  
 (Sol)-2/0 AWG (Str), 1-1/2" Pipe,  
 1-5/8" -1-7/8" Rod, Bright Dipped

**Other**

268

**Approvals / Certifications**

Type of U Bolt

UL Listed  
 CSA Certified  
 ROHS Compatible  
 UL Recognized  
 CULUS  
 Industry Standards  
 Rated for Direct Burial

Y  
 Y  
 Exempt  
 N  
 N  
 UL467  
 Y

**Conductor(s)**

Copper Tube Size (SCH40) - Range  
 Rod Size (Range)  
 Copper Solid Size (Range)  
 Copper Stranded (Range)  
 Rebar Size (Range)

1 1/2 IPS IPS  
 1 5/8 in-1 7/8 in  
 4 AWG-3/0 AWG  
 5 AWG-2/0 AWG  
 N/A

**Physical**

Type of Hardware  
 Installation Torque  
 Type of Plating  
 Plated (Yes or No)  
 Product Material

DURIUMâ€ Silicon Bronze  
 240  
 Bright Dipped  
 N  
 Copper Alloy

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175