



BURNDY Catalog Number
UPC Number
Description
Status

GAR1826
 7818102350033
 4-2/0CU 2IPS
 Active

Web Use
 BURNDY Product Line

Dimensional

| | |
|--------------------------------|-------|
| Width (in) | 3.69 |
| Length (in) | 1.56 |
| Height (in) | 4.25 |
| Size (Hex) or Size (Bolt) | 3/8 |
| Size (Hex) or Size (Bolt) - in | 0.38 |
| B Length (in) | 2.75 |
| Width (Fraction) | 3-3/4 |
| Height (Fraction) (in) | 4-1/4 |

General

Product Description
 Mechanical Grounding Connector,
 Cable to Rod or Pipe, 4 AWG
 (Sol)-2/0 AWG (Str), 2" Pipe,
 2"-2-3/8" Rod, Bright Dipped

Other

Type of U Bolt 257

Approvals / Certifications

| | |
|-------------------------|--------|
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Exempt |
| UL Recognized | N |
| CULUS | N |
| Industry Standards | UL467 |
| Rated for Direct Burial | Y |

Conductor(s)

| | |
|----------------------------------|---------------|
| Copper Tube Size (SCH40) - Range | 2 IPS IPS |
| Rod Size (Range) | 2 in-2 3/8 in |
| Copper Solid Size (Range) | 4 AWG-3/0 AWG |
| Copper Stranded (Range) | 5 AWG-2/0 AWG |
| Rebar Size (Range) | N/A |

Physical

| | |
|---------------------|------------------------|
| Type of Hardware | DURIUM® Silicon Bronze |
| Installation Torque | 240 |
| Type of Plating | Bright Dipped |
| Plated (Yes or No) | N |
| Product Material | Copper Alloy |

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

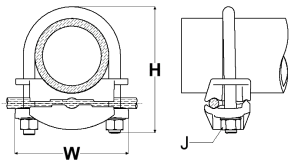

BURNDY Catalog Number
UPC Number
Description
Status

GAR1826
 7818102350033
 4-2/0CU 2IPS
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 3.69
 Length (in) 1.56
 Height (in) 4.25
 Size (Hex) or Size (Bolt) 3/8
 Size (Hex) or Size (Bolt) - in 0.38
 B Length (in) 2.75
 Width (Fraction) 3-3/4
 Height (Fraction) (in) 4-1/4

General

Product Description
 Mechanical Grounding Connector,
 Cable to Rod or Pipe, 4 AWG
 (Sol)-2/0 AWG (Str), 2" Pipe,
 2" -2-3/8" Rod, Bright Dipped

Other

Type of U Bolt 257

Approvals / Certifications

UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 UL Recognized N
 CULUS N
 Industry Standards UL467
 Rated for Direct Burial Y

Conductor(s)

Copper Tube Size (SCH40) - Range 2 IPS IPS
 Rod Size (Range) 2 in-2 3/8 in
 Copper Solid Size (Range) 4 AWG-3/0 AWG
 Copper Stranded (Range) 5 AWG-2/0 AWG
 Rebar Size (Range) N/A

Physical

Type of Hardware DURIUM® Silicon Bronze
 Installation Torque 240
 Type of Plating Bright Dipped
 Plated (Yes or No) N
 Product Material Copper Alloy

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175