

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

K2A29U  
 7818106001088  
 TWO:6STR-250 DUAL RATED  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in)	1.66
Length (in)	2.56
Bolt Hole Size (in)	0.38
Thickness	0.25
D - in	1.50
Pad Width (in)	1.66
N (in)	0.5

**General**

Number of Conductors	2
Number of Holes	1
Product Description	Aluminum Universal Terminal, 2 Conductor, 1 Hole, 6 AWG (Str)-250 kcmil, 3/8" Stud, 2 Screws, Al/Cu Rated, Tin Plated

**Conductor(s)**

Aluminum Size (Range)	6 STR- 250 kcmil
Copper Solid Size (Range)	N/A
Copper Stranded (Range)	6 AWG-250 kcmil

**Physical**

Installation Torque	275
Type of Plating	Tin
Connector Type	Terminal
Bolt Hole Size	3/8
Plated (Yes or No)	N
Product Material	Aluminum

**Approvals / Certifications**

Rated for Direct Burial	N
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
Industry Standards	UL468A-468B

**Documentation**

For further technical assistance, please contact us


**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

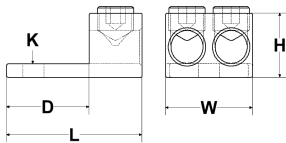

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

K2A29U  
 7818106001088  
 TWO:6STR-250 DUAL RATED  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in)	1.66
Length (in)	2.56
Bolt Hole Size (in)	0.38
Thickness	0.25
D - in	1.50
Pad Width (in)	1.66
N (in)	0.5

**General**

Number of Conductors	2
Number of Holes	1
Product Description	Aluminum Universal Terminal, 2 Conductor, 1 Hole, 6 AWG (Str)-250 kcmil, 3/8" Stud, 2 Screws, Al/Cu Rated, Tin Plated

**Conductor(s)**

Aluminum Size (Range)	6 STR- 250 kcmil
Copper Solid Size (Range)	N/A
Copper Stranded (Range)	6 AWG-250 kcmil

**Physical**

Installation Torque	275
Type of Plating	Tin
Connector Type	Terminal
Bolt Hole Size	3/8
Plated (Yes or No)	N
Product Material	Aluminum

**Approvals / Certifications**

Rated for Direct Burial	N
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
Industry Standards	UL468A-468B

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175