

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

KA34U  
 7818103702477  
 4STR-500 DUAL RATED  
 Active

**Web Use**  
 BURNDY Product Line

Dimensional	
Width (in)	1.51
Length (in)	2.81
Bolt Hole Size (in)	0.38
Thickness	0.31
D - in	1.50
Pad Width (in)	1.52
N (in)	0.88
General	
Number of Conductors	1
Number of Holes	1
Product Description	Aluminum Universal Terminal, 1 Hole, 4 AWG (Str)-500 kcmil, 3/8" Stud, 1 Screw, Al/Cu Rated, Tin Plated
Conductor(s)	
Aluminum Size (Range)	4 STR- 500 kcmil
Copper Solid Size (Range)	N/A
Copper Stranded (Range)	4 AWG-500 kcmil
Physical	
Installation Torque	500
Type of Plating	Tin
Connector Type	Terminal
Bolt Hole Size	3/8
Plated (Yes or No)	Y
Product Material	Aluminum
Approvals / Certifications	
Rated for Direct Burial	N
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
Industry Standards	UL468A-468B
Documentation	

For further technical assistance, please contact us


**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

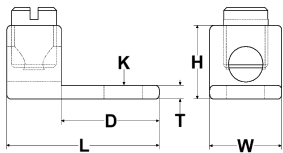

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

KA34U  
 7818103702477  
 4STR-500 DUAL RATED  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in) 1.51  
 Length (in) 2.81  
 Bolt Hole Size (in) 0.38  
 Thickness 0.31  
 D - in 1.50  
 Pad Width (in) 1.52  
 N (in) 0.88

**General**

Number of Conductors 1  
 Number of Holes 1  
 Product Description Aluminum Universal Terminal, 1 Hole, 4 AWG (Str)-500 kcmil, 3/8" Stud, 1 Screw, Al/Cu Rated, Tin Plated

**Conductor(s)**

Aluminum Size (Range) 4 STR- 500 kcmil  
 Copper Solid Size (Range) N/A  
 Copper Stranded (Range) 4 AWG-500 kcmil

**Physical**

Installation Torque 500  
 Type of Plating Tin  
 Connector Type Terminal  
 Bolt Hole Size 3/8  
 Plated (Yes or No) Y  
 Product Material Aluminum

**Approvals / Certifications**

Rated for Direct Burial N  
 UL Listed Y  
 CSA Certified Y  
 ROHS Compatible Exempt  
 Industry Standards UL468A-468B

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175