





Commercial Specification Grade Locking Devices

2 Pole, 3 Wire Grounding
 NEMA FSL1-30, 30A 28V/DC
 NEMA FSL2-30, 30A 120V
 NEMA L5-30, 30A 125V
 NEMA L6-30, 30A 250V
 NEMA L7-30, 30A 277V
 NEMA L8-30, 30A 480V
 NEMA L9-30, 30A 600V


30A 2 Pole, 3 Wire Commercial Specification Grade Receptacles

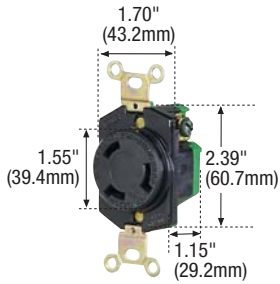


FSL130R

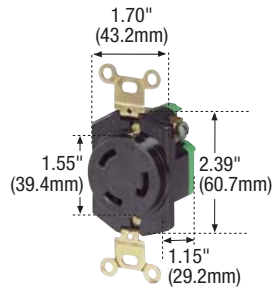

L530R

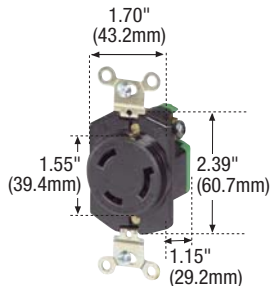

L930R

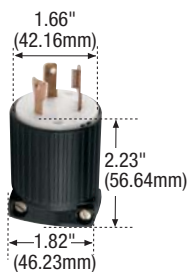

L530P



L530C

FEATURES

- Rugged nylon face and body.
- Clearly marked rating, NEMA configuration and approval listings on receptacle face.
- One piece brass contacts offer superior performance and minimum heat rise.
- Back wire terminal clamps for easy secure wiring.
- Combination head screws standard - slot/Phillips.

Commercial Specification Grade Receptacles

Rating	A	V/AC	NEMA	Description	Color	Catalog No.
	30	28V/DC	FSL1-30	Single	Black	FSL130R*
	30	120, 400HZ	FSL2-30	Single	Black	FSL230R*
	30	125	L5-30	Single	Black	L530R
	30	250	L6-30	Single	Black	L630R
	30	277	L7-30	Single	Black	L730R*
	30	480	L8-30	Single	Black	L830R*
	30	600	L9-30	Single	Black	L930R*

*Not NOM

30A 2 Pole, 3 Wire Commercial Grade Locking Plugs and Connectors

FEATURES

- Abuse resistant thermoplastic construction.
- Back wire Dead-Front design.
- External cable clamp provides firm strain relief.
- Back wire terminal clamps for easy secure wiring.
- Individual wiring compartments with tapered channel for easy insertion of wires.
- Triple combination head screws standard - slot/Phillips/Robertson for use in the U.S. and Canada.
- Clear cover over wiring compartments allow easy inspection of wiring terminations.
- Clearly marked rating, NEMA configuration and standard compliances on face of plug or connector.

Commercial Grade Locking Plugs and Connectors

Rating	A	V/AC	NEMA	Description/ Cord Diameter	Color	Plug	Catalog No. Connector
	30	125	L5-30	Straight: 0.25"-0.69" (6.35mm-17.5mm)	Black & White	L530P	L530C*
	30	250	L6-30	Straight: 0.25"-0.69" (6.35mm-17.5mm)	Black & White	L630P	L630C*

*Not Federal Spec.

NOTE: Weather Protective Covers from Cooper Wiring Devices that may be used with these products are described on pages E-71 in this section.



INDUSTRIAL
COMMERCIAL

E-35
LOCKING
DEVICES

TESTING & CODE COMPLIANCE

- Listed to UL 498 Receptacles (file no. E15058) Plugs & Connectors: (file no. E15012).
- UL Listed to Federal Spec. WC-596.
- CSA Certified to C22.2 no. 42. Receptacles: (file no. LR6914 (6233-01)). Plugs & Connectors: (file no. LR2081 (6221-01)).
- NOM Certified, except as noted.

MATERIAL CHARACTERISTICS

- Receptacles: Nylon.
- Plugs, Connectors: Polycarbonate.
- Meets flammability requirements per UL 94. V2 rated.
- Temperature Rating: Receptacles: -40°C to 70°C. Plugs & Connectors: -20°C to 60°C.