




GE  
Lighting

**68161 - LED10DR303V/830W**

GE LED Floodlight

- Energy-efficient LED lamps. Long life.

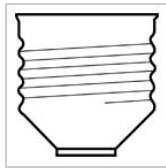

**GENERAL CHARACTERISTICS**

Lamp Type	Replacement Lamps - Directional
Bulb	BR30
Base	Medium Screw (E26)
Additional Info	Frosted, white, BR30
Bulb Shape	BR30
Color	White
Dimming Capability	Operates on dimming circuits. See GELighting.com/dimming for further information
Equivalent Wattage (NOM)	65.0 W
Lamp Type	LED-BR
Life in Years (NOM)	22.8
Rated Life (MIN)	25000.0 h
Rated Life (NOM)	25000.0 h

**PHOTOMETRIC CHARACTERISTICS**

Color Rendering Index (CRI) (NOM)	80.0
Color Temperature (NOM)	3000.0 K
Initial Lumens (NOM)	700.0
Lumens per Watt (Efficacy) (NOM)	70.0 lm
Nominal Initial Lumens per Watt (NOM)	70.0

**ELECTRICAL CHARACTERISTICS**

Estimated Energy Cost per Year (NOM)	1.2
Voltage (NOM)	120.0
Wattage (NOM)	10.0

**DIMENSIONS**

Bulb Diameter (DIA) (NOM)	3.750 in(95.2 mm)
Maximum Overall Length (MOL) (NOM)	5.370 in(136.4 mm)

**PRODUCT INFORMATION**

Product Code	68161
Description	LED10DR303V/830W
Standard Package	00-Case
Standard Package GTIN	10043168681619
Standard Package Quantity	6
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168681612




GE  
Lighting

**68161 - LED10DR303V/830W**

GE LED Floodlight

- Energy-efficient LED lamps. Long life.

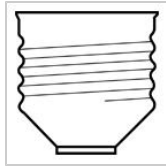

**GENERAL CHARACTERISTICS**

Lamp Type	Replacement Lamps - Directional
Bulb	BR30
Base	Medium Screw (E26)
Additional Info	Frosted, white, BR30
Bulb Shape	BR30
Color	White
Dimming Capability	Operates on dimming circuits. See GELighting.com/dimming for further information
Equivalent Wattage (NOM)	65.0 W
Lamp Type	LED-BR
Life in Years (NOM)	22.8
Rated Life (MIN)	25000.0 h
Rated Life (NOM)	25000.0 h

**PHOTOMETRIC CHARACTERISTICS**

Color Rendering Index (CRI) (NOM)	80.0
Color Temperature (NOM)	3000.0 K
Initial Lumens (NOM)	700.0
Lumens per Watt (Efficacy) (NOM)	70.0 lm
Nominal Initial Lumens per Watt (NOM)	70.0

**ELECTRICAL CHARACTERISTICS**

Estimated Energy Cost per Year (NOM)	1.2
Voltage (NOM)	120.0
Wattage (NOM)	10.0

**DIMENSIONS**

Bulb Diameter (DIA) (NOM)	3.750 in(95.2 mm)
Maximum Overall Length (MOL) (NOM)	5.370 in(136.4 mm)

**PRODUCT INFORMATION**

Product Code	68161
Description	LED10DR303V/830W
Standard Package	00-Case
Standard Package GTIN	10043168681619
Standard Package Quantity	6
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168681612