




GE
Lighting

68161 - LED10DR303V/830W

GE LED Floodlight

• Energy-efficient LED lamps. Long life.

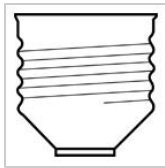

GENERAL CHARACTERISTICS

| | |
|--------------------------|--|
| Lamp Type | Replacement Lamps - Directional |
| Bulb | BR30 |
| Base | Medium Screw (E26) |
| Additional Info | Frosted, white, BR30 |
| Bulb Shape | BR30 |
| Color | White |
| Dimming Capability | Operates on dimming circuits. See GELighting.com/dimming for further information |
| Equivalent Wattage (NOM) | 65.0 W |
| Lamp Type | LED-BR |
| Life in Years (NOM) | 22.8 |
| Rated Life (MIN) | 25000.0 h |
| Rated Life (NOM) | 25000.0 h |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Color Rendering Index (CRI) (NOM) | 80.0 |
| Color Temperature (NOM) | 3000.0 K |
| Initial Lumens (NOM) | 700.0 |
| Lumens per Watt (Efficacy) (NOM) | 70.0 lm |
| Nominal Initial Lumens per Watt (NOM) | 70.0 |

ELECTRICAL CHARACTERISTICS

| | |
|--------------------------------------|-------|
| Estimated Energy Cost per Year (NOM) | 1.2 |
| Voltage (NOM) | 120.0 |
| Wattage (NOM) | 10.0 |

DIMENSIONS

| | |
|------------------------------------|--------------------|
| Bulb Diameter (DIA) (NOM) | 3.750 in(95.2 mm) |
| Maximum Overall Length (MOL) (NOM) | 5.370 in(136.4 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|------------------|
| Product Code | 68161 |
| Description | LED10DR303V/830W |
| Standard Package | 00-Case |
| Standard Package GTIN | 10043168681619 |
| Standard Package Quantity | 6 |
| Sales Unit | Layer |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 6 |
| UPC | 043168681612 |




GE
Lighting

68161 - LED10DR303V/830W

GE LED Floodlight

• Energy-efficient LED lamps. Long life.

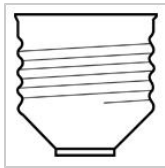

GENERAL CHARACTERISTICS

| | |
|--------------------------|--|
| Lamp Type | Replacement Lamps - Directional |
| Bulb | BR30 |
| Base | Medium Screw (E26) |
| Additional Info | Frosted, white, BR30 |
| Bulb Shape | BR30 |
| Color | White |
| Dimming Capability | Operates on dimming circuits. See GELighting.com/dimming for further information |
| Equivalent Wattage (NOM) | 65.0 W |
| Lamp Type | LED-BR |
| Life in Years (NOM) | 22.8 |
| Rated Life (MIN) | 25000.0 h |
| Rated Life (NOM) | 25000.0 h |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Color Rendering Index (CRI) (NOM) | 80.0 |
| Color Temperature (NOM) | 3000.0 K |
| Initial Lumens (NOM) | 700.0 |
| Lumens per Watt (Efficacy) (NOM) | 70.0 lm |
| Nominal Initial Lumens per Watt (NOM) | 70.0 |

ELECTRICAL CHARACTERISTICS

| | |
|--------------------------------------|-------|
| Estimated Energy Cost per Year (NOM) | 1.2 |
| Voltage (NOM) | 120.0 |
| Wattage (NOM) | 10.0 |

DIMENSIONS

| | |
|------------------------------------|--------------------|
| Bulb Diameter (DIA) (NOM) | 3.750 in(95.2 mm) |
| Maximum Overall Length (MOL) (NOM) | 5.370 in(136.4 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|------------------|
| Product Code | 68161 |
| Description | LED10DR303V/830W |
| Standard Package | 00-Case |
| Standard Package GTIN | 10043168681619 |
| Standard Package Quantity | 6 |
| Sales Unit | Layer |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 6 |
| UPC | 043168681612 |