




# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

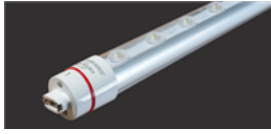

## LED16T836P2S865D 3' 16W Led Signhero 65K 360DEG BLST Bypass *Keystone Technologies*

Catalog Number	LED16T836P2S865D
Manufacturer	Keystone Technologies
Description	3 FT. Led Sign Tube, 6500K, Double Sided Output and Rotatable R17D End Caps, 16W, 120-277V Input
Weight per unit	0.2900 (lbs/each)
Product Category	Led Specialty Lamps & Modules

### Features

Ballast Type	N/A
beam angle	360 Deg
Circuit Type	N/A
Input Voltage	120-277V
ip rating	N/A
lumens	2000
Nominal Length	36 in
Nominal Size	N/A
Number of Lamps	N/A
Output Current	N/A
Output Voltage	N/A
Sensor Type	N/A
Wattage	16
Wire Type	N/A

### Material, Color, and Finish

Base Type	R17D
color rendering index (cri)	>80 Deg
color temperature	6500
housing color	N/A

### Descriptions

Construction	N/A
Description	3' 16W LED SIGNHERO 65K 360DEG BLST BYPASS
extra long description	Key KT-LED16T8-36P2S-865-D /G2 36"
Long Description	3 FT. LED SIGN TUBE, 6500K, DOUBLE SIDED OUTPUT AND ROTATABLE R17D END CAPS, 16W, 120-277V INPUT
Product Type	36", 16W, 2000 Lumens, 360' Beam Spread, Double Sided Lamp,



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

## Manufacturer Information

Brand	Keystone
GTIN	00843654132204
Manufacturers Part Number	KT-LED16T8-36P2S-865-D /G2
UPC	843654132204

## Taxonomies, Classifications, and Categories

Category Description	LED SPECIALTY LAMPS & MODULES
----------------------	-------------------------------

## Packaging

Carton	1
Package	9
Weight Per each	0.29

## Uses, Certifications, and Standards

Energy Star	N
-------------	---