




GE
Lighting

11332 - LED7DA19/827

GE LED A19 40w Replacement

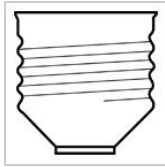

GENERAL CHARACTERISTICS

Lamp Type	Replacement Lamps - A-line
Bulb	A19
Base	Medium Screw (E26)
Additional Info	White, Omnidirectional
Bulb Shape	A-19
Color	White
Dimming Capability	Yes
Equivalent Wattage (NOM)	40.0 W
Lamp Type	A-19
Life in Years (NOM)	22.8
Rated Life (NOM)	25000.0 h

PHOTOMETRIC CHARACTERISTICS

Color Rendering Index (CRI) (NOM)	80.0
Color Temperature (NOM)	2700.0 K
Initial Lumens (NOM)	450.0
Nominal Initial Lumens per Watt (NOM)	64.3

ELECTRICAL CHARACTERISTICS

Estimated Energy Cost per Year (NOM)	0.84
Voltage (NOM)	120.0
Wattage (NOM)	7.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	112.7 mm
------------------------------------	----------

PRODUCT INFORMATION


Product Code	11332
Description	LED7DA19/827
Standard Package	00-Case
Standard Package GTIN	10043168113325
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168113328



GE
Lighting

11332 - LED7DA19/827

GE LED A19 40w Replacement

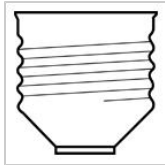

GENERAL CHARACTERISTICS

Lamp Type	Replacement Lamps - A-line
Bulb	A19
Base	Medium Screw (E26)
Additional Info	White, Omnidirectional
Bulb Shape	A-19
Color	White
Dimming Capability	Yes
Equivalent Wattage (NOM)	40.0 W
Lamp Type	A-19
Life in Years (NOM)	22.8
Rated Life (NOM)	25000.0 h

PHOTOMETRIC CHARACTERISTICS

Color Rendering Index (CRI) (NOM)	80.0
Color Temperature (NOM)	2700.0 K
Initial Lumens (NOM)	450.0
Nominal Initial Lumens per Watt (NOM)	64.3

ELECTRICAL CHARACTERISTICS

Estimated Energy Cost per Year (NOM)	0.84
Voltage (NOM)	120.0
Wattage (NOM)	7.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	112.7 mm
------------------------------------	----------

PRODUCT INFORMATION

Product Code	11332
Description	LED7DA19/827
Standard Package	00-Case
Standard Package GTIN	10043168113325
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168113328