




MC/AC CABLE TO FLANGE CLIP, BOTTOM MOUNT, 1/8"–1/4" FLANGE, 14-2 TO 10-3 MC/AC

CATALOG NUMBER

MAC224

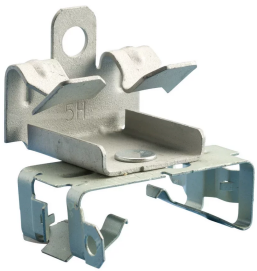

CERTIFICATIONS



FEATURES

Compliant with NEC® Article 300.4(d), allowing cable to be positioned a minimum of 1-1/4" from face of stud

Compliant with CEC Rule 12-618 for support of MC/AC cable

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

Flange Thickness: 1/8"

MC/AC Cable Size: 14-2 to 10-3

Outer Diameter: 0.6" Max

ADDITIONAL PRODUCT DETAILS

Assemblies allow for support from most main and substructures.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500




Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER



MC/AC CABLE TO FLANGE CLIP, BOTTOM MOUNT, 1/8"–1/4" FLANGE, 14-2 TO 10-3 MC/AC

CATALOG NUMBER

MAC224

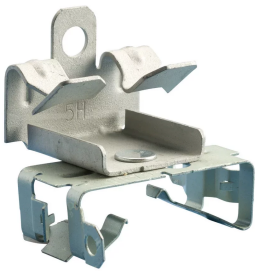

CERTIFICATIONS



FEATURES

Compliant with NEC® Article 300.4(d), allowing cable to be positioned a minimum of 1-1/4" from face of stud

Compliant with CEC Rule 12-618 for support of MC/AC cable

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

Flange Thickness: 1/8"

MC/AC Cable Size: 14-2 to 10-3

Outer Diameter: 0.6" Max

ADDITIONAL PRODUCT DETAILS

Assemblies allow for support from most main and substructures.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER