



MC/AC CABLE SUPPORT BRACKET, 14-3 TO 10-2 MC/AC, 4 CABLE

CATALOG NUMBER

MCS50



CERTIFICATIONS



FEATURES

Neatly isolates, supports and secures MC/AC cables

Properly spaces MC/AC cable to help eliminate bundling and NEC® & CEC derating issues

Results in a "neat and workmanlike" installation

PRODUCT ATTRIBUTES

MC/AC Cable Size: 14-3 to 10-2

Super Neutral Cable Size: 10-2

Material: Steel

Finish: Electrogalvanized

Cable Capacity: 4

Hole Size 1 (HS1): 1/4"


Hole Size 2 (HS2): 0.2"

Outer Diameter (OD): 0.430" - 0.56"

ADDITIONAL PRODUCT DETAILS

4Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).

DIAGRAMS

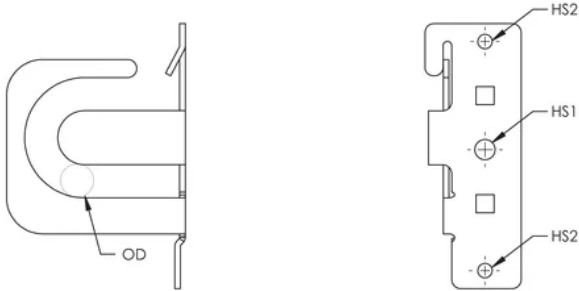

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.



MC/AC CABLE SUPPORT BRACKET, 14-3 TO 10-2 MC/AC, 4 CABLE

CATALOG NUMBER

MCS50



CERTIFICATIONS



FEATURES

Neatly isolates, supports and secures MC/AC cables

Properly spaces MC/AC cable to help eliminate bundling and NEC® & CEC derating issues

Results in a "neat and workmanlike" installation

PRODUCT ATTRIBUTES

MC/AC Cable Size: 14-3 to 10-2

Super Neutral Cable Size: 10-2

Material: Steel

Finish: Electrogalvanized

Cable Capacity: 4

Hole Size 1 (HS1): 1/4"


Hole Size 2 (HS2): 0.2"

Outer Diameter (OD): 0.430" - 0.56"

ADDITIONAL PRODUCT DETAILS

4Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).

DIAGRAMS

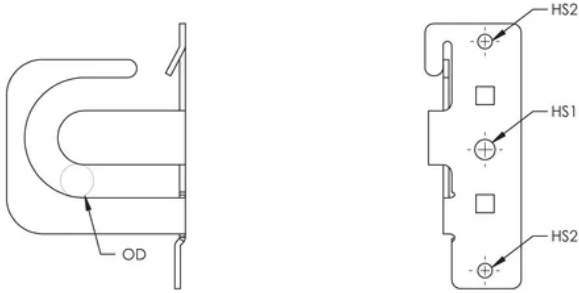

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER