




OUTLET BOXES

2 in. Deep with Lugs - Seven Threaded Outlets - 4-1/2 in. x 4-1/2 in.
N/A

D30

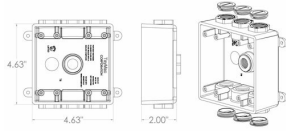

Catalog #: PDB77550GY

APPLICATIONS

For general use whenever weatherproof protection is required
N/A

PRODUCT FEATURES

- Durable high impact PVC construction
- Can be used with 1/2 in. or 3/4 in. conduit
- Includes 3/4 in. closure plugs and reducer bushings
- Includes gasket and mounting hardware
- Multi-lingual instructions in each package

UL LISTED

Marine

NEMA

3R Rated

NEC

2014 Compliant

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Number Of Outlets: 7
 Gangs: 2

PRODUCT MEASUREMENTS

Depth: 2 in.
 Outlet Size: 1/2 in. or 3/4 in.
 Cubic Inches (cm3): 26.5(434.3)
 Wt. Ea. (Lbs.): 0.733

PACKAGING


Package Type: Shrink
 Std. Pkg.: 6
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 73.30
 Ship Carton Length (in.): 13.00
 Ship Carton Width (in.): 6.13
 Ship Carton Height (in.): 6.13
 Ctn Weight (Lbs.): 4.40
 Pallet Qty: 756.00
 UPC Number: 092326130325
 I2of5: 40092326130323



OUTLET BOXES

2 in. Deep with Lugs - Seven Threaded Outlets - 4-1/2 in. x 4-1/2 in.
N/A

D30

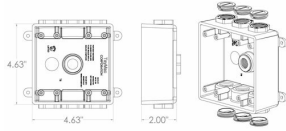

Catalog #: PDB77550GY

APPLICATIONS

For general use whenever weatherproof protection is required
N/A

PRODUCT FEATURES

- Durable high impact PVC construction
- Can be used with 1/2 in. or 3/4 in. conduit
- Includes 3/4 in. closure plugs and reducer bushings
- Includes gasket and mounting hardware
- Multi-lingual instructions in each package

UL LISTED

Marine

NEMA

3R Rated

NEC

2014 Compliant

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Number Of Outlets: 7
Gangs: 2

PRODUCT MEASUREMENTS

Depth: 2 in.
Outlet Size: 1/2 in. or 3/4 in.
Cubic Inches (cm3): 26.5(434.3)
Wt. Ea. (Lbs.): 0.733

PACKAGING

Package Type: Shrink
Std. Pkg.: 6
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 73.30
Ship Carton Length (in.): 13.00
Ship Carton Width (in.): 6.13
Ship Carton Height (in.): 6.13
Ctn Weight (Lbs.): 4.40
Pallet Qty: 756.00
UPC Number: 092326130325
I2of5: 40092326130323