


RAISE THE **BAR** ON MOBILE DEVICE CHARGING

Pass & Seymour® | Wiremold®

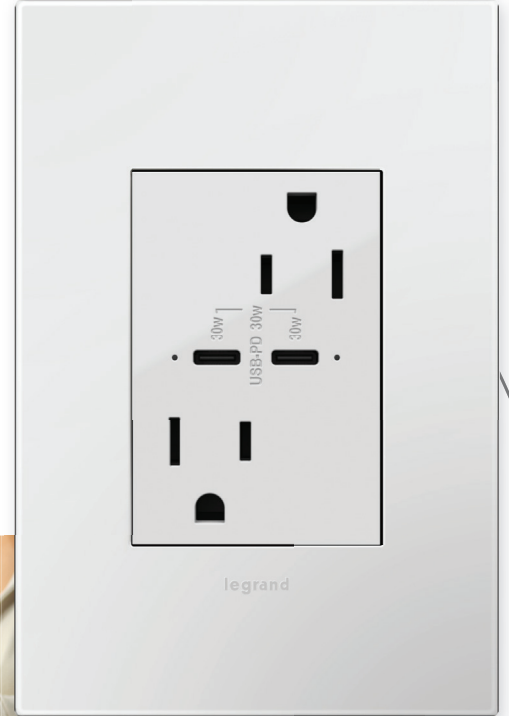

Deliver higher speeds.

Meet higher standards.

 **legrand®**

SUPERIOR CHARGING, WHEREVER IT'S NEEDED.

From bedroom to boardroom, university to hospital, we use our mobile devices to work, play and stay connected to those who matter most.

That's why Legrand offers an extensive selection of charging solutions to provide today's spaces with all the power modern life demands, enhanced with features for superior convenience, speed and ease.

Made for everywhere people go:

- Commercial Spaces
- Homes & Residential Properties
- Hospitals & Healthcare Facilities
- Hotels, Restaurants & Event Centers
- Office Spaces
- Outdoor Spaces
- Schools, Colleges & Universities



RAISE THE BAR WITH SUPREME CONVENIENCE.

Built-in charging has always been about convenience, enabling users to get the battery boost they need without locating that bulky adapter or sacrificing a plug.

Legrand takes charging to a whole new level with an expanding range of options that can do more and go anywhere.

GFCI USB Outlets

Commercial | Residential | Healthcare | Hospitality
Office | Outdoor | Education

Putting more within reach, Legrand's Tamper-Resistant GFCI USB Outlets provide self-testing ground fault protection and modern USB charging in a single solution. Extending the legacy of safety and reliability Legrand is known for, these devices enable you to add charging convenience anywhere and everywhere it is wanted – even in locations where GFCIs are required. Choose from USB Type-A/A, USB Type-A/C and USB Type-C/C port configurations.

Available from the radiant® Collection of designer switches and outlets.



dash™ SERIES SPOTLIGHT: CONFIGURABLE POWER FOR CUSTOMIZED CONVENIENCE

The future of power and connectivity meets next level-convenience with Legrand's dash Configurable Power Solutions. Comprised of modular cubes that provide seamless access to power, charging and more, the dash series even allows you to custom design your own solution to meet the unique connectivity needs of a commercial space.

dash Power Tower

Commercial | Hospitality | Office | Education


Adding convenient access to charging is easy with the free-standing dash Power Tower. This sleek and contemporary power solution features USB Type-A and C ports and seamlessly integrates into a variety of commercial environments. Includes a retractable 8-foot power cord for added design flexibility. Order from our standard, ready-to-ship options or create a customized design ranging from four to six cubes.



dash Furniture Power Center

Commercial | Hospitality | Office | Education

Take the convenience of furniture power to a new level with dash. Select from the standard offering or create a custom design tailored to your specific needs with configurations ranging from two to six cubes of power and USB Type-A/C charging. Trim plates available in several stunning, on-trend finishes to perfectly complement a surrounding space.

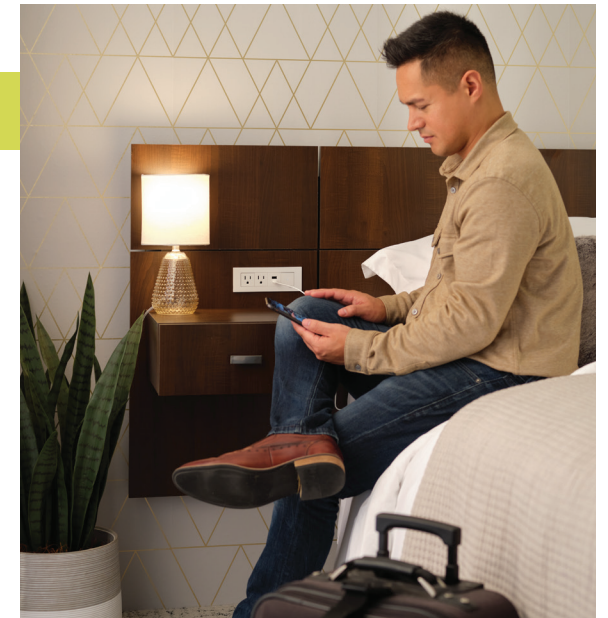

dash Desktop Power Center

Commercial | Hospitality | Office | Education

Provide guests, employees and other end-users with convenient access to power and data right at their work surface. Available in configurations from two to six cubes, the dash Desktop Power Centers accommodate a variety of connectivity options with modules for power, USB Type-A/C charging and data connectivity. Available with a range of versatile mounting options for a sleek, high-end design.



ModPower™ Sytem

Commercial | Office | Education

Meet the code-compliant modular power system designed to give users the freedom to easily add and reconfigure power and charging whenever and however is needed. Up to six modular units can be connected within a single system. Choose from in-surface and on-surface versions for increased flexibility.



Furniture Power Centers

Commercial | Hospitality | Office | Education

Add USB charging right where it's needed – directly into the furniture itself. From lobby armchairs to conference room tabletops, Legrand's variety of furniture power solutions combine sleek, modern design with the functionality of USB charging, traditional power and more. Quick and easy to install, furniture can be ready to recharge devices in no time. Choose from multiple configurations, styles and finish options to meet a space's charging needs while blending in with its décor.

Available from the **adorne®** and **radiant®** Collections of designer switches and outlets.



RAISE THE BAR WITH WIRELESS EASE.

For users wishing to ditch more than the adapter, Legrand offers advanced Qi-certified solutions that don't even need the power cords or cables. Stylishly designed and performance inspired – start charging like never before.

Wireless Charger

Residential

A ready-made charging station, this in-wall solution features a wireless charge pad and clear cradle to hold Qi-enabled smartphones perfectly in place while charging – without any cords or clutter. Installing in place of a single-gang outlet, the Wireless Charger also includes traditional power access and a built-in USB Type-A port.



Available from the **radiant®** Collection of designer switches and outlets.

Wireless Charging Puck

Commercial | Hospitality | Office | Education

Turn any desk, table or nightstand into a sleek wireless charger with the furniture-ready Wireless Charging Puck. After an easy installation, this Wiremold® solution sits flush against the surface for a truly seamless look. Provide speedy Qi-certified wireless charging for users looking to recharge their smartphones and tablets nearly anywhere that furniture can go.



What is Qi-Certified Charging?

Technology standards like Qi are used to ensure safe and effective compatibility across many device manufacturers. Qi-certified devices have been tested by the Wireless Power Consortium to confirm interoperability.

RAISE THE BAR WITH LEADING SPEEDS.

Speed matters. Legrand incorporates cutting-edge charging technologies to continually push the limits. Our USB outlets include the fastest options in the industry, with specialized solutions to add unrivaled charging speed to any space.

What is USB Type-C?

A newer – and increasingly popular – type of USB connection port, USB Type-C was designed to handle more power (for faster speeds) while boasting a smaller and conveniently reversible insert.

Ultra-Fast USB Outlets

Commercial | Residential | Healthcare | Office
Outdoor | Education

Thanks to a staggering 6 amps of charging power and the Smart Chip technology that maximizes speeds for each of their USB connections, the Ultra-Fast USB Outlets charge smartphones and tablets up to 40% faster. Choose from USB Type-A/C and USB Type-C/C port configurations.

Available from the **adorne®** and **radiant®** Collections of designer switches and outlets.



Ultra-Fast Plus Power Delivery USB Type-C/C Outlets

Commercial | Residential | Office
Outdoor | Education

This is how you get to a full battery faster. Combining the industry-leading amperage of our Ultra-Fast line with advanced Power Delivery, this solution employs intelligent charging to max out the fast-charging potential of the latest smartphones and tablets. The result? Charging speeds up to 2X faster. These outlets also include multilayered overcurrent protection to prevent damage to outlet or devices.

Available from the **adorne®** and **radiant®** Collections of designer switches and outlets.

What is Power Delivery?

Power Delivery is a technical standard that enables USB Type-C devices to effectively negotiate, then deliver/receive, the exact amount of power needed to safely maximize charging speed.

Check Your Charge:


The Ultra-Fast Plus Power Delivery USB Outlets also feature indicator lights for each of the included ports, allowing users to check charging status at a glance. The light shows as yellow while charging is in progress and changes to green once a device is sufficiently charged.



Base SKU	Product Description	Color/Finish Options
radiant		
R26USBPDX	radiant* 15A Tamper Resistant Ultra Fast Plus Power Delivery USB Type-C/C Outlet	-, BK, DBCC6, GCC6, GRY, I, LA, NICC6, W
TR20USBPDX	radiant* 20A Tamper Resistant Ultra Fast Plus Power Delivery USB Type-C/C Outlet	-, BK, DBCCV4, G, GRY, I, LA, NI, RED, W
R26USBAC6X	radiant* 15A Tamper-Resistant Ultra-Fast USB Type-A/C Outlet	BK, DBCCV4, G, I, LA, NICCV4, W
R26USBCC6X	radiant* 15A Tamper-Resistant Ultra-Fast USB Type-C/C Outlet	BK, DBCCV4, G, I, LA, NICCV4, W
WRR26USBAC6X	radiant* Outdoor Ultra-Fast USB Type-A/C Outlet	BK, I, LA, W
1597TRUSBAAX	radiant* 15A Tamper-Resistant Self Test GFCI USB Type-A/A Outlet	BK, DBC4, G4, GRY, I, LA, NIC4, W
2097TRUSBAAX	radiant* 20A Tamper-Resistant Self Test GFCI USB Type-A/A Outlet	-, BK, GRY, I, LA, RED, W
1597TRUSBACX	radiant* 15A Tamper-Resistant Self Test GFCI USB Type-A/C Outlet	-, BK, GRY, I, LA, W
2097TRUSBACX	radiant* 20A Tamper-Resistant Self Test GFCI USB Type-A/C Outlet	-, BK, DBC4, GRY, I, LA, RED, W
1597TRUSBCCW	radiant* 15A Tamper-Resistant Self Test GFCI USB Type-C/C Outlet	W
2097TRUSBCCW	radiant* 20A Tamper-Resistant Self Test GFCI USB Type-C/C Outlet	W
1597TRWRUSBACX	radiant* 15A Tamper-Resistant Outdoor Self Test GFCI USB Type-A/C Outlet	BK, GRY, I, W
2097TRWRUSBACX	radiant* 20A Tamper-Resistant Outdoor Self Test GFCI USB Type-A/C Outlet	BK, GRY, W
1597TRWRUSBCCW	radiant* 15A Tamper-Resistant Outdoor Self Test GFCI USB Type-C/C Outlet	W
2097TRWRUSBCCX	radiant* 20A Tamper-Resistant Outdoor Self Test GFCI USB Type-C/C Outlet	BK, W
R26USBACX	radiant* 15A Tamper-Resistant USB-Type A/C Outlet	BK, DBCCV4, G, I, LA, NICCV4, W
RWC826USBXCCV2	radiant Wireless Charger (Qi Wireless Charging Pad and USB Type-A Outlet)	BK, I, LA, W
TM826USBX	radiant* 15A Tamper-Resistant USB Type-A/A Outlet	BK, GCCV4, I, LA, NICC6, W
TM8USB4XCC6	radiant* Quad USB Charger (USB Only; USB Type-A/A/A/A)	BI, I, LA, NI, W
TM83USBWCCV4	Switch with USB Outlet Combination Device	W, BK
adorne		
ARTRUSB15PD30X4	adorne* 15A Tamper-Resistant Ultra-Fast Plus Power Delivery USB Type-C/C Outlet, Plus-Size	G, M, W
ARTRUSB20PD30X4	adorne* 20A Tamper-Resistant Ultra-Fast Plus Power Delivery USB Type-C/C Outlet, Plus-Size	G, M, W
ARUSB30PDX4	adorne* Ultra-Fast Plus Power Delivery USB Type-C/C Outlet Module	G, M, W
ARTRUSB156ACX4	adorne* 15A Tamper-Resistant Ultra-Fast USB Type-A/C Outlet, Plus-Size	G, M, W
ARTRUSB206ACX4	adorne* 20A Tamper-Resistant Ultra-Fast USB Type-A/C Outlet, Plus-Size	G, M, W
ARUSB2AC6X4	adorne* Ultra-Fast USB Type-A/C Outlet Module	G, M, W
ARUSB2AA6X4	adorne* Ultra-Fast USB Type-A/A Outlet Module	G, M, W
ARTRUSB153X4	adorne* USB Type-A/A Outlet, Plus-Size	G, M, W
ARUSBM4	adorne* USB Type-A Outlet, Half-Size	M
Hospital Grade		
TR15HUSBAC6X	15A 125V Hospital-Grade Tamper-Resistant Ultra-Fast USB Type-A/C Outlet	-, BK, GRY, I, RED, W
TR20HUSBAC6X	20A 125V Hospital-Grade Tamper-Resistant Ultra-Fast USB Type-A/C Outlet	-, BK, GRY, I, LA, RED, W
TR15HUSBCC6X	15A 125V Hospital-Grade Tamper-Resistant Ultra-Fast USB Type-C/C Outlet	-, BK, GRY, I, RED, W
TR20HUSBCC6X	20A 125V Hospital-Grade Tamper-Resistant Ultra-Fast USB Type-C/C Outlet	-, BK, GRY, I, LA, RED, W
2097HGTRUSBACX	radiant* 20A Hospital-Grade Tamper-Resistant Self Test GFCI USB Type-A/C Outlet	BK, GRY, I, LA, RED, W
TR15HUSBACX	15A 125V Hospital-Grade Tamper-Resistant USB Type-A/C Outlet	-, BK, GRY, I, RED, W
TR8300HUSBX	20A 125V Hospital-Grade Tamper-Resistant USB Type-A/A Outlet	-, BK, GRY, I, LA, RED, W
PTTR15HACUSBX	PlugTail* Hospital-Grade 15A 125V USB Type-A/C Outlet	-, BK, GRY, I, RED, W
PTTR20HACUSBX	PlugTail* 20A 125V Hospital-Grade USB Type-A/C Outlet	-, BK, GRY, I, LA, RED, W

Base SKU	Product Description	Color/Finish Options
Commercial		
TR15USBAC6X	15A 125V Tamper-Resistant Ultra-Fast USB Type-A/C Outlet	-, BK, GRY, I, LA, W
WRTR15USBAC6X	15A 125V Tamper-Resistant Weather-Resistant Ultra-Fast USB Type-A/C Outlet	-, BK, GRY, I, LA, W
TR20USBAC6X	20A 125V Tamper-Resistant Ultra-Fast USB Type-A/C Outlet	-, BK, G, GRY, I, LA, NI, RED, W
WRTR20USBAC6X	20A 125V Tamper-Resistant Weather-Resistant Ultra-Fast USB Type-A/C Outlet	-, BK, GRY, I, LA, W
TR15USBCC6X	15A 125V Tamper-Resistant Ultra-Fast USB Type-C/C Outlet	-, BK, GRY, I, LA, W
TR20USBCC6X	20A 125V Tamper-Resistant Ultra-Fast USB Type-C/C Outlet	-, BK, GRY, I, LA, W
TR15USBACX	15A 125V Tamper-Resistant USB Type-A/C Outlet	-, BK, GRY, I, LA, W
TR20USBACX	20A 125V Tamper-Resistant USB Type-A/C Outlet	-, BK, GRY, I, LA, NI, RED, W
TR20HUSBACX	20A 125V Tamper-Resistant USB Type-A/C Outlet	-, BK, GRY, I, LA, RED, W
TR5262USBX	15A 125V Fed Spec-Grade Tamper-Resistant USB Type-A/A Outlet	-, BK, GRY, I, LA, NI, W
TR5362USBX	20A 125V Fed Spec-Grade Tamper-Resistant USB Type-A/A Outlet	-, BK, GRY, I, LA, NI, RED, W
PTTR15ACUSBX	PlugTail* 15A 125V Commercial Spec-Grade USB Type-A/C Outlet	-, BK, GRY, I, LA, W
PTTR20ACUSBX	PlugTail* 20A 125V Commercial Spec-Grade USB Type-A/C Outlet	-, BK, GRY, I, LA, W
ModPower™ System		
MDSF10-X	Primary Unit, In Surface	White (WH), Magnesium (MG)
MDSA10-X	Primary Unit, On Surface	White (WH), Magnesium (MG)
MDCF3-X	Middle Unit, In Surface	White (WH), Magnesium (MG)
MDCA3-X	Middle Unit, On Surface	White (WH), Magnesium (MG)
MDEF3-X	End Unit, In Surface	White (WH), Magnesium (MG)
MDEA3-X	End Unit, On Surface	White (WH), Magnesium (MG)
MDCLIPS	10 Mounting Clip - Replacement	Black
MDBKT-X	On Surface Mounting Brackets - Replacement	White (WH), Black (BK)
MDJ36BK	Jumper Cable - 3 ft. between-unit Extender	Black
radiant Furniture Power Centers		
		Cord Length
RDZX	2 outlet, 2 USB-A port Unit	Black (BK), White (WH), Nickel (NI) 6 ft.
RDZCX	2 outlet, 1 USB-A & 1 USB-C port Unit	Black (BK), White (WH), Nickel (NI) 6 ft.
RDZX10	2 outlet & 2 USB-A port Unit	Black (BK), White (WH), Nickel (NI) 10 ft.
RDZCX10	2 outlet, 1 USB-A & 1 USB-C port Unit	Black (BK), White (WH), Nickel (NI) 10 ft.

 Color Designation



*Note: On pages 10 and 11, X indicates the part number's color identifier.

Base SKU	Product Description	Color/Finish Options
dash™ Power Tower		
P4HUHUWH	36" Power Tower with 4 Cubes (2 Outlet, 2 Combo USB A/C)	White
P4HUHUGR	36" Power Tower with 4 Cubes (2 Outlet, 2 Combo USB A/C)	Graphite
*	36" Power Tower with 5 Cubes (MTO)	White, Graphite
*	36" Power Tower with 6 Cubes (MTO)	White, Graphite

**All dash Power Tower products, regardless of value in Part Number row, can be configured to customer specifications. Please work with your Legrand Sales Representative on the configuration that fits your project.*

dash™ Desktop Power Center		
D2RU6XRWC	2- Cube dash DPC (1 outlet, 1 combo USB A/C)	White
D2RU6XRG	2- Cube dash DPC (1 outlet, 1 combo USB A/C)	Graphite
D3RUR6XRWC	3-Cube dash DPC (2 outlets, 1 combo USB A/C)	White
D3RUR6XRG	3-Cube dash DPC (2 outlets, 1 combo USB A/C)	Graphite
D4RRRU6XRWC	4-Cube dash DPC (3 outlets, 1 combo USB A/C)	White
D4RRRU6XRG	4-Cube dash DPC (3 outlets, 1 combo USB A/C)	Graphite
*	5-Cube dash DPC (MTO)	White, Graphite
*	6-Cube dash DPC (MTO)	White, Graphite

**All dash DPC products, regardless of value in Part Number row, can be configured to customer specifications. Please work with your Legrand Sales Representative on the configuration that fits your project.*

dash™ Furniture Power Center		
F2RU6PRWC	2-Cube dash FPC (1 outlet, 1 combo USB A/C)	White
F2RU6PRGC	2-Cube dash FPC (1 outlet, 1 combo USB A/C)	Graphite
F3RUR6PRWC	3-Cube dash FPC (2 outlet, 1 combo USB A/C)	White
F3RUR6PRGC	3-Cube dash FPC (2 outlets, 1 combo USB A/C)	Graphite
F4RRUS6NRWC	4-Cube dash FPC (2 outlets, 1 combo USB A/C, 1 switch)	White
F4RRUS6NRGC	4-Cube dash FPC (2 outlets, 1 combo USB A/C, 1 switch)	Graphite
*	5-Cube dash FPC (MTO)	White, Graphite
*	6-Cube dash FPC (MTO)	White, Graphite
TRIM2-X	Trim for 2-Cube dash FPC	Stainless Steel (ST), Bronze (BZ), Brass (BR)
TRIM3-X	Trim for 3-Cube dash FPC	Stainless Steel (ST), Bronze (BZ), Brass (BR)
TRIM4-X	Trim for 4-Cube dash FPC	Stainless Steel (ST), Bronze (BZ), Brass (BR)
TRIM5-X	Trim for 5-Cube dash FPC	Stainless Steel (ST), Bronze (BZ), Brass (BR)
TRIM6-X	Trim for 6-Cube dash FPC	Stainless Steel (ST), Bronze (BZ), Brass (BR)

designed to be better.®



Electrical Wiring Systems
 60 Woodlawn Street
 West Hartford, CT 06110
 1.877.BY.LEGRAND (295.3472)
www.legrand.us

Canada
 1.800.723.5175; 905.738.9195
www.legrand.ca

FOLLOW US

