




The HALO® RL Canless LED Downlight series includes sizes 4" and 6" and does not require a can for installation. This series provides ultimate personalization with 5 Selectable CCT, a Dim-to-Warm setting, and selectable lumens. During installation select the perfect color temperature for your space with 5 color temperatures between warm (2700K) to daylight (5000K) or a dim-to-warm setting. The dim-to-warm setting begins at 3000K and dims smoothly to 1800K, creating a rich, warm glow resembling candlelight or the sun on the horizon. Depending on your ceiling height or desired light level choose one of the selectable lumen enabled fixtures. The RL Canless LED Downlight is designed for remodel or new construction when paired with the new construction mounting frame.

## Product Features


- Baffle Trim with regressed lens
- Canless Direct Mount – does not require recessed housing or junction box
- Can be installed in 1/2" to 1-1/4" thick ceilings
- 5-color selectable CCT: 2700K, 3000K, 3500K, 4000K, 5000K, plus D2W
  - Dim-to-warm technology included: use your dimmer to warm color temperature from 3000K to 1800K
- Selectable Lumen: RL4LS: 600/900 Lumens  
RL6LS: 900/1200 Lumens
- 120V input, dimmable down to 5% with select phase cut dimmers
- Air-tite, wet location listed, IC rated



LEARN MORE

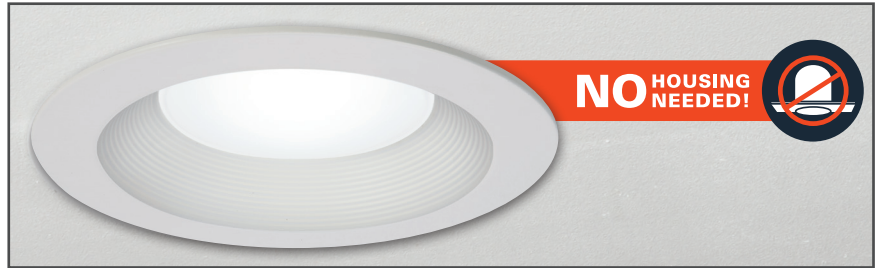

## Personalize Your Lighting

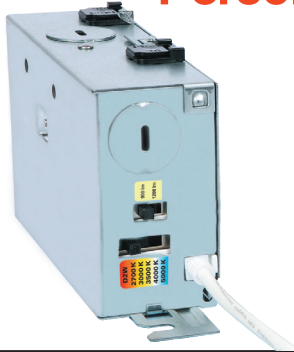

Select the perfect color temperature for your space with 5 color temperatures between warm (2700K) to daylight (5000K) or a dim-to-warm setting.



Choose between 2 lumen options (900-1200) depending on your ceiling height or desired light level.



**dim-to-warm**  
set the mood

**3000K 1800K**

The dim-to-warm setting begins at 3000K and dims smoothly to 1800K, creating a rich, warm glow resembling candlelight or the sun on the horizon.

Catalog Number	Material Number	Description	UPC	Accessories		
				Extension Cable	Mounting Frame	Designer Trims
RL4LS9FSD2W1EWHDM	13601499	4" Canless Downlight, 600/900 Selectable lumens, 90 CRI, 120V 60Hz, LE & TE phase cut 5% dimming, Selectable D2W, 2700, 3000, 3500, 4000, or 5000K CCT	080083258901	HLB06FSEC 6 ft. cable	HL4RSMF 4" round and square mounting frame	RL4TRMWHB Matte White, Baffle RL4TRMWBB Matte Black, Baffle RL4TRMSNB Satin Nickel, Baffle RL4TRMTBZB Tuscan Bronze, Baffle RL4TRMWH Splay RL4TRMBB Matte Black, Splay RL4TRMSN Satin Nickel, Splay RL4TRMTBZ Tuscan Bronze, Splay
RL6069FSD2W1EWHDM	13601552	6" Canless Downlight, 600 lumens, 90 CRI, 120V 60Hz, LE & TE phase cut 5% dimming, Selectable D2W, 2700, 3000, 3500, 4000, or 5000K CCT	080083258963	HLB12FSEC 12 ft. extension cable HLB20FSEC 20 ft. extension cable	HL6RSMF 6" round and square mounting frame	N/A
RL6LS9FSD2W1EWHDM	13601553	6" Canless Downlight, 900/1200 Selectable lumens, 90 CRI, 120V 60Hz, LE & TE phase cut 5% dimming, Selectable D2W, 2700, 3000, 3500, 4000, or 5000K CCT	080083258987			



Cooper Lighting Solutions  
1121 Highway 74 South  
Peachtree City, GA 30269  
P: 770-486-4800  
cooperlighting.com

Canada Sales  
5925 McLaughlin Road  
Mississauga, Ontario L5R 1B8  
P: 905-501-3000  
F: 905-501-3172

© 2023 Cooper Lighting Solutions  
All Rights Reserved  
Publication No. BR51878523  
February 2023

Product availability, specifications, and compliances are subject to change without notice.