




L.H. Dottie Company
 6131 Garfield Avenue
 Commerce, California 90040
 Call: 323-725-1000 • Fax: 323-721-0000

"Building a Better Brand"

Item # RN3, (RN3) Three-in-One Roof Jack Flashing

1/2" - 3/4" - 1" Roof Flashings Three-in-One

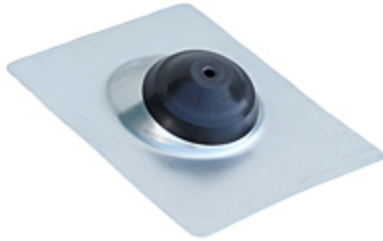

Product Specifications | Packaging Specifications

Product Specifications

| | |
|------------------------|-----------------------------|
| Category Number | 5250 |
| UPC Code | 781002103509 |
| Sort | 1751 |
| Style/Type | Three-in-One |
| Material | Steel |
| Collar Material | Elastomer |
| Thickness | 24 gauge |
| Pipe Size | 1/2 in. 3/4 in. 1 in. |

Packaging Specifications

| | |
|----------------------|--------------------|
| Package Type | Industructo Carton |
| Unit Quantity | 12 |

| | |
|--|-------------|
| Carton Quantity | 12 |
| Unit (UM) | Each |
| Package Length | 17.30 in. |
| Package Width | 9.40 in. |
| Package Height | 9.60 in. |
| Package Weight | 11.3000 lb. |
| United Nations Standard Products & Services Code (UNSPSC) | 30151602 |




L.H. Dottie Company
 6131 Garfield Avenue
 Commerce, California 90040
 Call: 323-725-1000 • Fax: 323-721-0000

"Building a Better Brand"

Item # RN3, (RN3) Three-in-One Roof Jack Flashing

1/2" - 3/4" - 1" Roof Flashings Three-in-One

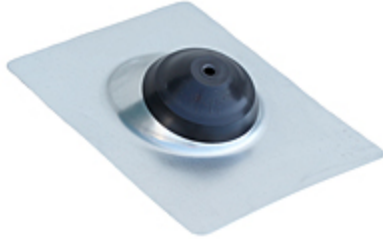

Product Specifications | Packaging Specifications

Product Specifications

| | |
|------------------------|-----------------------------|
| Category Number | 5250 |
| UPC Code | 781002103509 |
| Sort | 1751 |
| Style/Type | Three-in-One |
| Material | Steel |
| Collar Material | Elastomer |
| Thickness | 24 gauge |
| Pipe Size | 1/2 in. 3/4 in. 1 in. |

Packaging Specifications

| | |
|----------------------|--------------------|
| Package Type | Industructo Carton |
| Unit Quantity | 12 |

| | |
|--|-------------|
| Carton Quantity | 12 |
| Unit (UM) | Each |
| Package Length | 17.30 in. |
| Package Width | 9.40 in. |
| Package Height | 9.60 in. |
| Package Weight | 11.3000 lb. |
| United Nations Standard Products & Services Code (UNSPSC) | 30151602 |