




Residential Dimmers & Fan Speed Controls Rotary R TradeMaster® Series



Pass & Seymour



Features	
<ul style="list-style-type: none"> ■ Slimmer design – the trimmest rotary dimmers, 1/4" less depth than the leading competitor's models. ■ Easy-to-grip knob with soft, contemporary curves goes with any décor. Interchangeable with older-style knobs. ■ Excellent RFI/EMI filtering performance – won't impact sensitive electronic devices. ■ Pre-stripped leads speed termination. 	<ul style="list-style-type: none"> ■ No de-rating of 600 watt models in multi-gang applications. ■ Leaves more room in the box for faster, easier installation. ■ Makes small adjustments in lighting levels easier. ■ Illuminated models are easy to find in the dark.

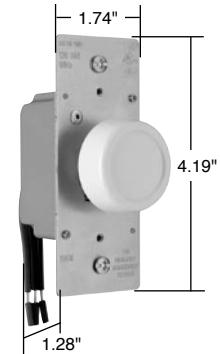

R600PWV



R1000WV

Catalog Number		Description	Ratings	Color
Single Pole	Three-Way			
600W Incandescent RFI Rotary Dimmers				
R600IV R600WV R600LAV		Non-Preset	120V 600W	Ivory White Light Almond
R600PIV R600PWV R600PLAV	R603PIV R603PWV R603PLAV	Preset	120V 600W	Ivory White Light Almond
1000W Incandescent RFI Rotary Dimmers				
R1000IV R1000WV R1000LAV		Non-Preset	120V 1000W	Ivory White Light Almond
R1000PIV R1000PWV R1000PLAV	R1003PIV R1003PWV R1003PLAV	Preset	120V 1000W	Ivory White Light Almond

Available in VisionPak™ only.

Catalog Number	Description	Color
Rotary Replacement Knobs		
RRKIV RRKWV RRKLAV	Plain Replacement Knob	Ivory White Light Almond
RRKCLGV RRKIGV RRKWGV RRKLAGV	Deluxe Replacement Knob	Clear Ivory White Light Almond

De-Rating Chart for R Series			
Catalog Number	Maximum Load	Multi-Gang De-Rating	
		2 Gang	3 Gang
R600, R600P	600W	No De-Rating Required	
R1000	1000W	750W	700W
R1000P	1000W	900W	800W
R1003P	1000W	900W	800W


All devices listed on this page conform to NEMA WD-1 and WD-6. UL Listed and CSA Certified.

Devices & Wall Plates Color Selection Chart




Pass & Seymour

Devices & Plastic Wall Plate Colors

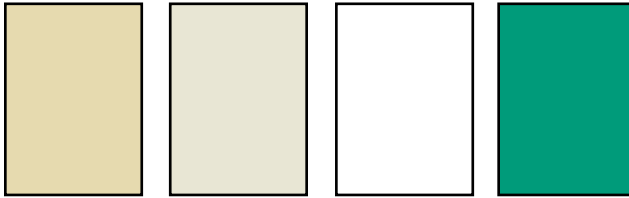


Ivory Light Almond White Green

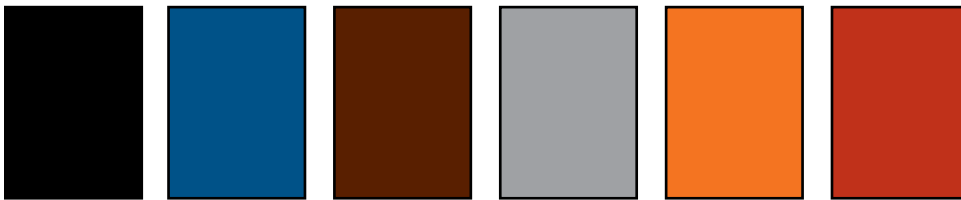

Black Blue Brown Gray Orange Red


See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

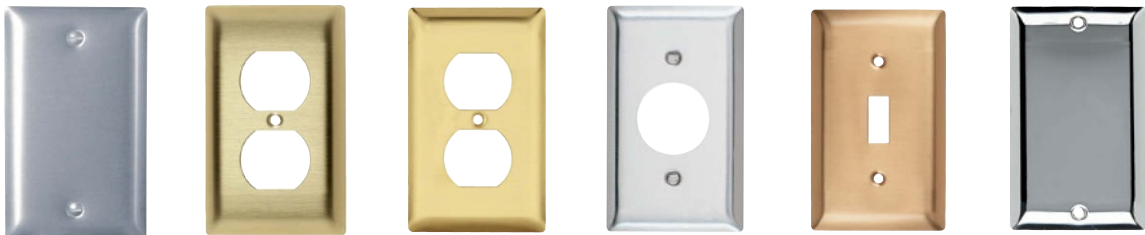

Metal Finish Aluminum Brass (Brushed) Polished Brass Stainless Steel Brushed Bronze Chrome

Custom Metal Wall Plates Paint Finish Colors

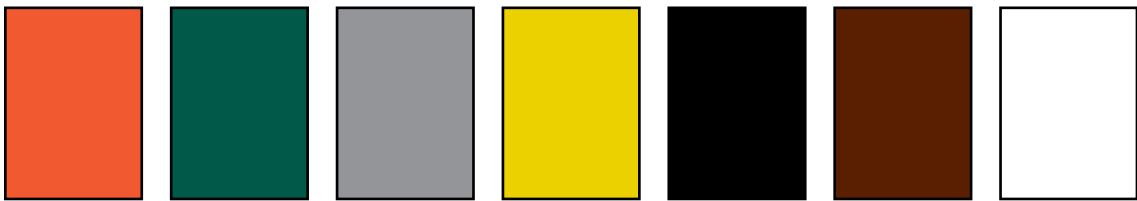

Paint Color Orange Green Gray Yellow Glossy Black Brown White



Paint Color Primer Red Pink Flat Black Ivory Light Almond Blue

To order custom metal wall plates, see Pages Q-43 – Q-45.

For additional colors consult factory.




Residential Dimmers & Fan Speed Controls Rotary R TradeMaster® Series



Pass & Seymour



- | Features | |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <ul style="list-style-type: none"> ■ Slimmer design – the trimmest rotary dimmers, 1/4" less depth than the leading competitor's models. ■ Easy-to-grip knob with soft, contemporary curves goes with any décor. Interchangeable with older-style knobs. ■ Excellent RFI/EMI filtering performance – won't impact sensitive electronic devices. ■ Pre-stripped leads speed termination. | <ul style="list-style-type: none"> ■ No de-rating of 600 watt models in multi-gang applications. ■ Leaves more room in the box for faster, easier installation. ■ Makes small adjustments in lighting levels easier. ■ Illuminated models are easy to find in the dark. |

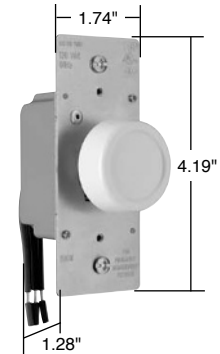

R600PWV



R1000WV

Catalog Number		Description	Ratings	Color
Single Pole	Three-Way			
600W Incandescent RFI Rotary Dimmers				
R600IV R600WV R600LAV		Non-Preset	120V 600W	Ivory White Light Almond
R600PIV R600PWV R600PLAV	R603PIV R603PWV R603PLAV	Preset	120V 600W	Ivory White Light Almond
1000W Incandescent RFI Rotary Dimmers				
R1000IV R1000WV R1000LAV		Non-Preset	120V 1000W	Ivory White Light Almond
R1000PIV R1000PWV R1000PLAV	R1003PIV R1003PWV R1003PLAV	Preset	120V 1000W	Ivory White Light Almond

Available in VisionPak™ only.

Catalog Number	Description	Color
Rotary Replacement Knobs		
RRKIV RRKWV RRKLAV	Plain Replacement Knob	Ivory White Light Almond
RRKCLGV RRKIGV RRKWGV RRKLAGV	Deluxe Replacement Knob	Clear Ivory White Light Almond

De-Rating Chart for R Series			
Catalog Number	Maximum Load	Multi-Gang De-Rating	
		2 Gang	3 Gang
R600, R600P	600W	No De-Rating Required	
R1000	1000W	750W	700W
R1000P	1000W	900W	800W
R1003P	1000W	900W	800W

All devices listed on this page conform to NEMA WD-1 and WD-6. UL Listed and CSA Certified.

Devices & Wall Plates Color Selection Chart



Pass & Seymour

Devices & Plastic Wall Plate Colors

Ivory	Light Almond	White	Green		
Black	Blue	Brown	Gray	Orange	Red

See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

Aluminum	Brass (Brushed)	Polished Brass	Stainless Steel	Brushed Bronze	Chrome

Custom Metal Wall Plates Paint Finish Colors

Orange	Green	Gray	Yellow	Glossy Black	Brown	White
Primer	Red	Pink	Flat Black	Ivory	Light Almond	Blue

To order custom metal wall plates, see Pages Q-43 – Q-45.

For additional colors consult factory.