



**SELECTABLE LUMENS.
TUNABLE COLOR TEMPERATURE.
FLEXIBLE MOTION/DUSK-TO-DAWN CONTROL.**



The Next Generation of Motion & Security Floodlighting is here! The SEC Series is designed to give homeowners a smarter, more flexible way to light and protect their property.

Available in 1-, 2-, and 3-head configurations with matte black or white finishes, these fixtures upgrade dated outdoor lights with modern LED efficiency, selectable brightness, and tunable white color temperatures.

With three operating modes—motion-activated, dusk-to-dawn, or a combination of both—and a 240° motion sensor that detects movement up to 45 feet away, the SEC Series delivers targeted, dependable outdoor security lighting that's built to last up to 50,000 hours and backed by a 5-year limited warranty.

Product Features

- Single, Twin & Triple head integrated LED Security Floodlights
- Choose from motion, dusk-to-dawn, or motion + dusk-to-dawn modes
- **Motion Sensor:** 240° coverage; up to 45 ft detection range
- **Brightness Control:** Selectable 25–100% light output
- **Brightness (Lumens):** Up to 1500 lm (1-head); 2500 lm (2-head); 3500 lm (3-head)
- **CCT:** 5-position selectable white (2700K, 3000K, 4000K, 5000K, 6500K)
- **Heads & Aiming:** Adjustable heads for targeted coverage of driveways, yards, and entrances
- **Mounting:** Tool-less plug-in or hardwired to standard outdoor junction boxes, wall or eave installation
- Wet location-listed; IP65 rated for outdoor use
- Available in matte black and white finishes
- 50,000 hrs of maintenance-free operation
- 5-year warranty



LEARN MORE

MULTIPLE WAYS TO MOUNT:



EAVE MOUNT




WALL MOUNT



MODES OF OPERATION



Fixture on @ 100% all night

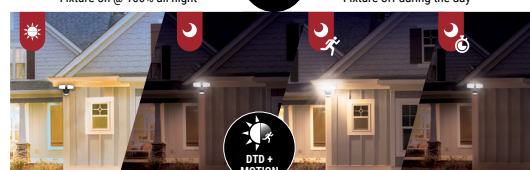

Fixture off during the day



Fixture off during the day

At dusk, no motion: Fixture on @30%

At dusk, with motion: Fixture on @ 100 %

After time out: Fixture dims back to 30%

ORDER INFORMATION

Catalog Number	Description	Material no.	UPC	Case Qty	Case Dimensions (in.)			Weight (lbs)
					L	W	H	
SEC1HSHWMBLK	120V SEL1500 5CCT 27TO65 MOTION 1H BLK	13694571	080083303731	2	370	310	185	0.42
SEC2HSHWMBLK	120V SEL 2500 5CCT 27TO65 MOTION 2H BLK	13696669	080083304103	2	370	360	185	0.53
SEC3HSHWMBLK	120V SEL 3500 5CCT 27TO65 MOTION 3H BLK	13696680	080083304127	2	480	370	185	0.64
SEC2HSPUGMBLK	ACPLUG SEL 2500 5CCT 27TO65 MOTION 2H BLK	13696681	080083304141	2	370	360	185	0.74
SEC1HSHWMWH	120V SEL1500 5CCT 27TO65 MOTION 1H WH	13696690	080083304325	2	370	310	185	0.42
SEC2HSHWMWH	120V SEL 2500 5CCT 27TO65 MOTION 2H WH	13696691	080083304349	2	370	360	185	0.53
SEC3HSHWMWH	120V SEL3500 5CCT 27TO65 MOTION 3H WH	13696692	080083304363	2	480	370	185	0.64
SEC2HSPUGMWH	ACPLUG SEL 2500 5CCT 27TO65 MOTION 2H WH	13696693	080083304387	2	370	360	185	0.74



*for Plug&Cord version only



Cooper Lighting Solutions
1121 Highway 74 South
Peachtree City, GA 30269
P: 770-486-4800
cooperlighting.com

Canada Sales
5925 McLaughlin Road
Mississauga, Ontario L5R 1B8
P: 905-501-3000
F: 905-501-3172

© 2025 Cooper Lighting Solutions
All Rights Reserved
Publication No. BR51876525
December 2025

Product availability, specifications, and compliances are subject to change without notice.