
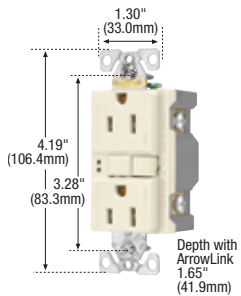


## Specification grade GFCIs


### Specification grade ground fault circuit interrupter receptacles

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC; 20A, 125V/AC  
NEMA 5-15, 5-20

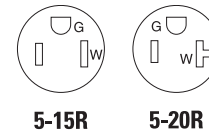

SGF15

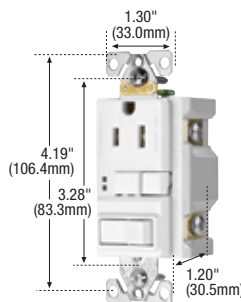



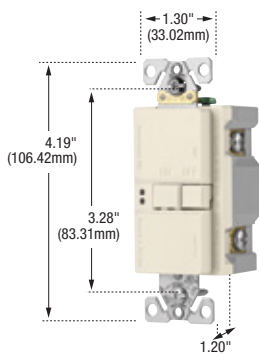







SGFS15



SGFD20

#### Specification grade GFCIs

Rating							
A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	Duplex GFCI, back & side wire	A, B, BK, GY, LA, V, W	<input type="checkbox"/> SGF15__		
			Duplex GFCI, mid-size wallplate, back & side wire	A, LA, V, W	<input type="checkbox"/> SGF15__-M		
			Duplex GFCI, back & side wire	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF15F__		
20	125	5-20R	Duplex GFCI, back & side wire	A, B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF20__		
			Duplex GFCI, back & side wire	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF20F__		

Includes standard size unbreakable wallplate unless otherwise noted  
Consult factory customer service representative for additional packaging options









#### Specification grade combination GFCI receptacle & switch

Rating					
A	V/AC	NEMA	Description	Color suffix	Catalog no.
15	125	5-15R	GFCI receptacle with feed-through single-pole switch (rated 1800W @ 120V/AC, 60Hz)	A, LA, V, W	<input type="checkbox"/> SGFS15__-MSP

#### Specification grade blank face GFCI

Rating					
A	V/AC	Description	Color suffix	Catalog no.	
20	125	Blank face (dead front) GFCI, rated as 1.5HP motor control switch, back & side wire	A, BK, LA, V, W	<input type="checkbox"/> SGFD20__	

#### Accessories for GFCIs

Description	Color suffix	Catalog no.		
GFCI 7/8" extension ring, cULus Listed	BLK, LA, V, W	<input type="checkbox"/> GFER__		
Metal self-closing horizontal 1-Gang weather protective cover, decorator opening		<input type="checkbox"/> S1966		
While-in-use metal weather protective standard depth 1-Gang cover, vertical mount		<input type="checkbox"/> WIUMV-1		



GFER



S1966



WIUMV-1



WIUMH-1


#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)

<b>A</b>	<b>B</b>	<b>BK/BLK</b>	<b>GY</b>	<b>LA</b>	<b>RD</b>	<b>V</b>	<b>W</b>
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Red)	(Ivory)	(White)

**Specification information:** Specification grade GFCI: H-18

**Compliances, specifications and availability are subject to change without notice.**

 ArrowLink option available. Add "MOD" suffix to standard catalog number (example SGF15W, SGF15WMOD). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page H-4



 
RoHS compliant - Page Q-32

## Specification grade GFCIs

### Specification grade ground fault circuit interrupter receptacles

#### Product description












2-pole, 3-wire grounding  
 15A, 125V/AC; 20A, 125V/AC  
 NEMA 5-15, 5-20



5-15R

5-20R

#### Specification grade GFCIs

Rating		A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	125	5-15R	125	5-15R	Duplex GFCI, back & side wire	A, B, BK, GY, LA, V, W	<input type="checkbox"/> SGF15__			
					Duplex GFCI, mid-size wallplate, back & side wire	A, LA, V, W	<input type="checkbox"/> SGF15__-M			
					Duplex GFCI, back & side wire	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF15F__			
20	125	5-20R	125	5-20R	Duplex GFCI, back & side wire	A, B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF20__			
					Duplex GFCI, back & side wire	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF20F__			

Includes standard size unbreakable wallplate unless otherwise noted  
 Consult factory customer service representative for additional packaging options








#### Specification grade combination GFCI receptacle & switch


Rating		A	V/AC	NEMA	Description	Color suffix	Catalog no.
15	125	5-15R	125	5-15R	GFCI receptacle with feed-through single-pole switch (rated 1800W @ 120V/AC, 60Hz)	A, LA, V, W	<input type="checkbox"/> SGFS15__-MSP

#### Specification grade blank face GFCI


Rating		A	V/AC	Description	Color suffix	Catalog no.
20	125		125	Blank face (dead front) GFCI, rated as 1.5HP motor control switch, back & side wire	A, BK, LA, V, W	<input type="checkbox"/> SGFD20__

#### Accessories for GFCIs


Description	Color suffix	Catalog no.		
GFCI 7/8" extension ring, cULus Listed	BLK, LA, V, W	<input type="checkbox"/> GFER__		
Metal self-closing horizontal 1-Gang weather protective cover, decorator opening		<input type="checkbox"/> S1966		
While-in-use metal weather protective standard depth 1-Gang cover, vertical mount		<input type="checkbox"/> WIUMV-1		

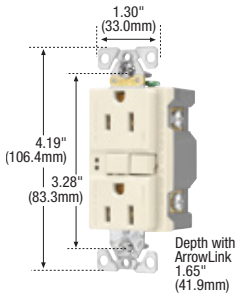

SGF15

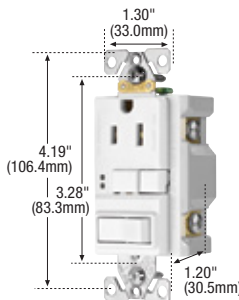

SGFS15

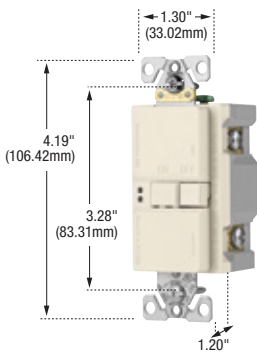

SGFD20



GFER



S1966



WIUMV-1



WIUMH-1


#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)

<b>A</b>	<b>B</b>	<b>BK/BLK</b>	<b>GY</b>	<b>LA</b>	<b>RD</b>	<b>V</b>	<b>W</b>
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Red)	(Ivory)	(White)

**Specification information:** Specification grade GFCI: H-18

**Compliances, specifications and availability are subject to change without notice.**

 ArrowLink option available. Add "MOD" suffix to standard catalog number (example SGF15W, SGF15WMOD). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page H-4



RoHS compliant - Page Q-32