

REV.	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	2020-04-12 08:00:00 EST	CHANGE CONDUCTOR RANGE #6	220408018936	BAU	LBR



Y644-HSXT DIELESS HYPRESS™

SPECIFICATIONS


- . Dieless system, eliminates the need to purchase and maintain dies.
- . Patented rapid advance pump for faster crimps.
- . Pressure relief "pop-off" valve provides audible indication that crimp is complete.
- . Handle trigger drain for convenient ram retraction.
- . 355° head rotation for versatile tool positioning in tight areas.
- . Easy inspection and positive identification is provided with embossment of the BURNDY® logo with every crimp.
- . Comfort grip handles help ease fatigue with continuous use.
- . Supplied with high impact plastic carrying case.
- . Five year warranty and two years on all tools repaired by an Authorized BURNDY® Tool Repair Center.

Output Force : 11 tons (22,000 lbs.)
 Weight : 15 lbs. (5.6 kg)
 Length : 23.2" (589.3 mm)
 Height : 3.00" (76.2 mm)
 Width : 7.04" (178.8 mm)

CONDUCTOR RANGE : #6 - 900 kcmil AL
 #4 - 1000 kcmil Cu
 #2 - 777 kcmil Cu flex

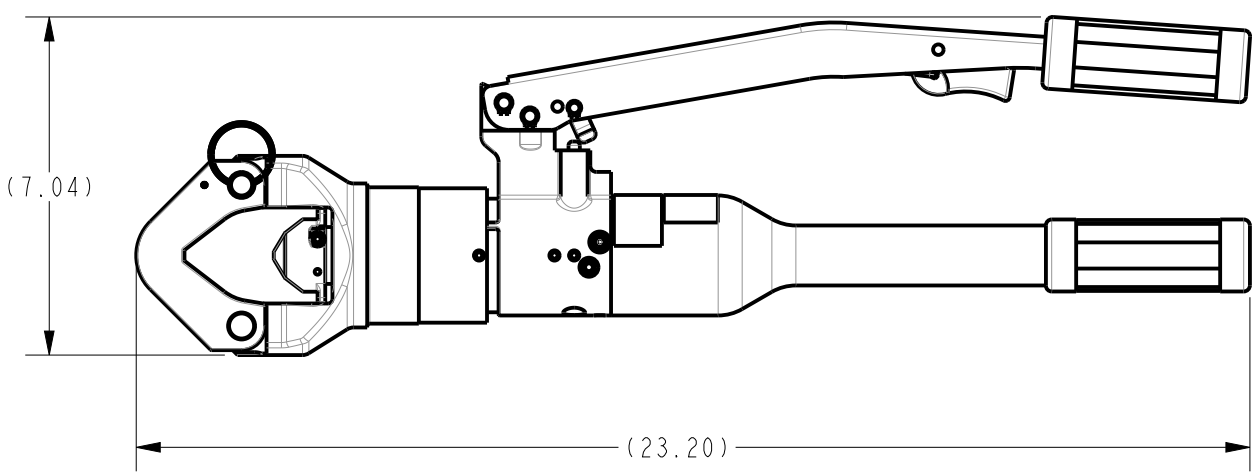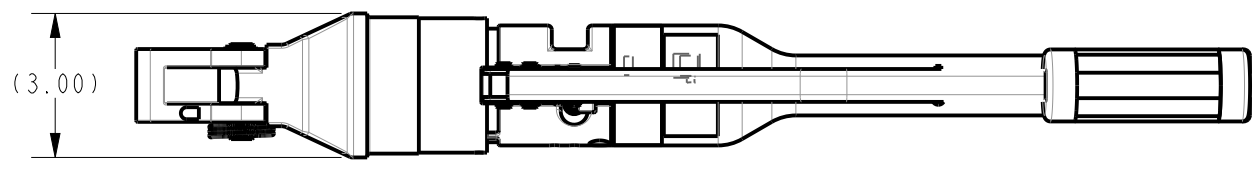

FEATURES

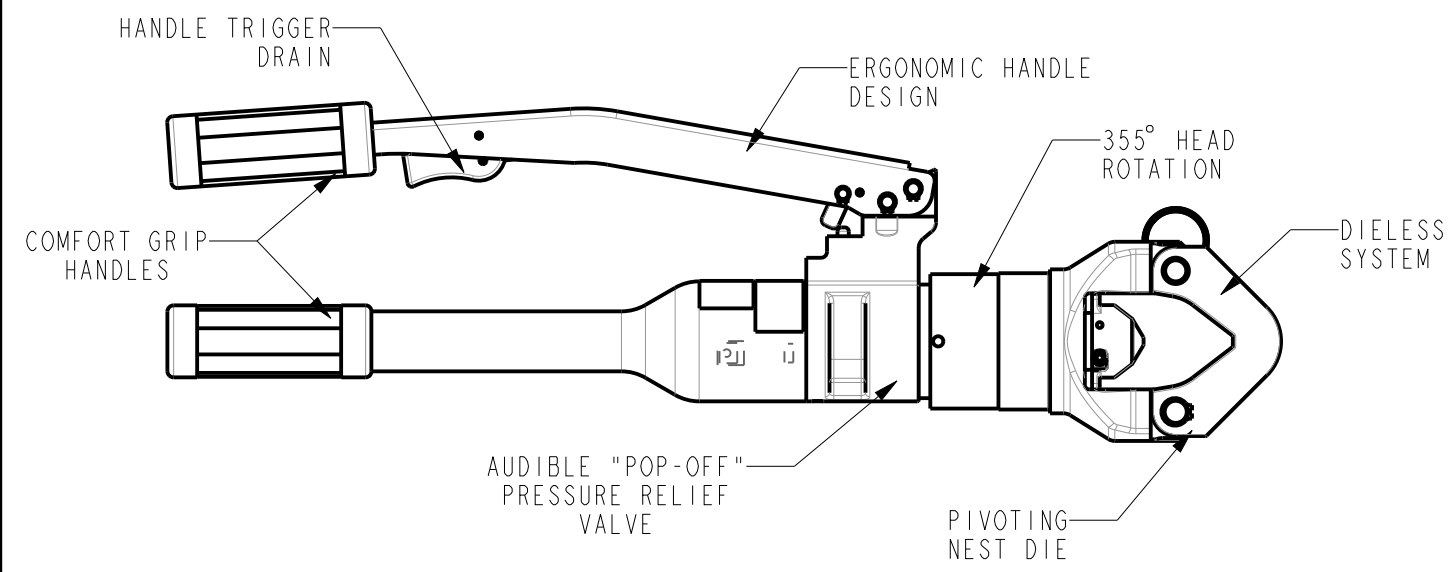

TO ORDER BURNDY® PRODUCTS CALL
 UNITED STATES:
 1-800-346-4175 (LONDONDERRY, NH)
 CANADA:
 1-800-361-6975 (QUEBEC)
 1-800-387-6487 (ALL OTHER PROVINCES)
 FOR PRODUCT INFO: <http://www.burndy.com>

Y644HSXT SELF CONTAINED TOOL		ITEM NO: 10074289	
CAT. NO: Y644HSXT		DRAWN BY: T. FAUCHER 04/13/2007	
CHECKER: M. CHIASSON 04/13/2007		DSN APPVL: J. LEFAVOUR 04/19/2007	
MFG APPVL: --		QA APPVL: J. BRODEUR 04/19/2007	
MKT APPVL: B. POIRIER 05/17/2007		PROJ FAM: TOOLS, HYDRAULIC	
PROJECT #: --	SIZE B	DRAWING NO 10074292	REV C
DOCUMENT TYPE: Sales	REL LEVEL: Released	SCALE: 1:4	
		SHEET 1 OF 1	

REV: CREO 05/20/21